

## Han-Modular Flexbox hood 4 entries

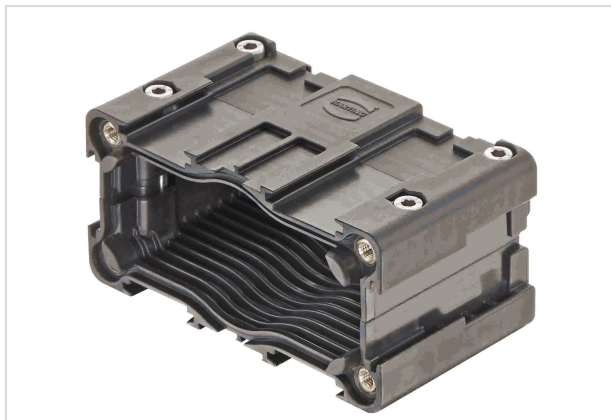


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 000 8014
Specification	Han-Modular Flexbox hood 4 entries
HARTING eCatalogue	<a href="https://b2b.harting.com/09140008014">https://b2b.harting.com/09140008014</a>

### Identification

Category	Hoods/Housings
Series of hoods/housings	Han-Modular® Flexbox
Type of hood/housing	Hood

### Version

Version	Top entry
Cable entry	4x

### Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP54
Clamping range	4 ... 16 mm

### Material properties

Material (hood/housing)	Polyamide (PA) Fibre-glass reinforced
Colour (hood/housing)	RAL 9005 (jet black)
Material (seal)	NBR
Colour (seal)	RAL 9005 (jet black)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e



Pushing Performance

## Material properties

REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

## Specifications and approvals

Specifications	IEC 61984 EN 45545-1 R22: HL1, HL2
----------------	---------------------------------------

## Commercial data

Packaging size	1
Net weight	112.4 g
Country of origin	China
European customs tariff number	85389099
eCl@ss	27440202 Shell for industrial connectors