
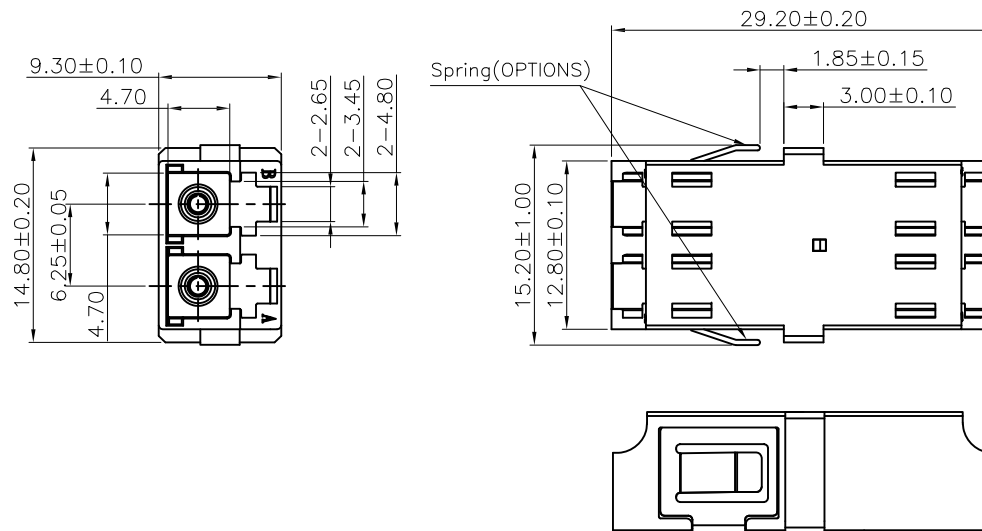


APPROVED: _____

DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-		RELEASED	9/8/20	
A		UPDATE DRAWING	11/4/20	LH/JL

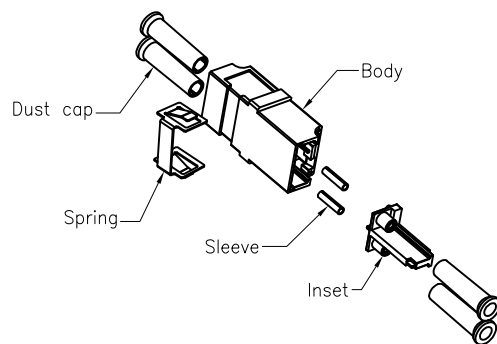

OPLD2BNNC1NA	PEI Aquatic Blue	W/O
OPLD2BNNC1PA	PEI Aquatic Blue	W/
OPLC2BNNC1NA	PBT Beige 7501U	W/O
OPLA2BNNC1NA	PBT Green 7737C	W/O
OPLC2BNNC1PA	PBT Beige 7501U	W/
OPLA2BNNC1PA	PBT Green 7737C	W/
OPLB2BNNC1NA	PEI Blue 2184C	W/O
OPLB2BNNC1PA	PEI Blue 2184C	W/
Part name	Material, Color	EMI

SPECIFICATIONS:

Material:

Housing: See Chart, rated UL 94V-0, Color: See Chart

Cap: PP, rated UL 94V-0, Color: White

Spring: SUS

Sleeve: Zirconia Ceramic

Electrical:

Standards of IEC 61754-20, YD/T 1272.1-2003

Repeatability: 1000 min times

Insertion loss: 0.2dB max

Interchangeability: 0.2dB

Temperature Rating:

Operating temperature: -40°C to +85°C

Environmental:

Lead free, RoHS compliant.



UNLESS OTHERWISE SPECIFIED
ALL DIMENSIONS ARE MILLIMETERS
TOLERANCES: EXCEPT AS NOTED
MM ANGLE
X. ± 0.35 X. ± 2°
.X ± 0.30 .X ± 1°
.XX ± 0.25 .XX ± 0.5°
.XXX ± 0.15 .XXX ± 0.5°

APPROVALS		DATE
DRAWN	OW	9/8/20
CHECKED	JL	9/8/20
APPROVED		

ADAM
TECH
INTERCONNECTS

909 Rahway Avenue,
Union, NJ 07083
Phone: 908-687-5000
Fax: 908-687-5710

TITLE
OPTICAL LC ADAPTERS, APC&PC&MM, 2 PORTS
SHORT EARS, WITH LC DUST CAP

SIZE X	PART NO. OPLX2BNNC1XA	REV. A
REF: S00005C	SCALE: NTS	SHEET 1 OF 1