

Actuator

45-
2N39.1010.000



<https://eao.com/p/45-2N39.1010.000>

Your product:



45-2N39.1010.000

Actuator

FRONT

Front dimension:	Ø 29,5 mm
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Design:	raised
---------	--------

OPERATING-/INDICATION PART

Lever colour:	Black
Lever material:	plastic

MECHANICAL CHARACTERISTIC

Weight:	0.015 kg
Switching action:	Momentary
Mechanical lifetime:	1 Mio. cycles of operation
Operating frequency:	1 800/h

AMBIENT CONDITION

IP front protection:	IP66, IP67, IP69K
Operating temperature:	– 25 °C ... + 70 °C
Storage temperature:	– 40 °C ... + 80 °C
Vibration resistance:	According to IEC 60068-2-6: 10 ... 500 Hz: 5 g

Climate resistance:

During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

Shock resistance:

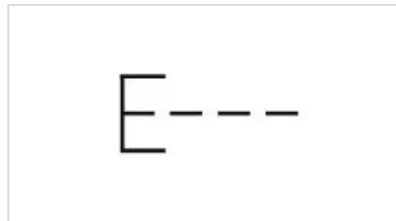
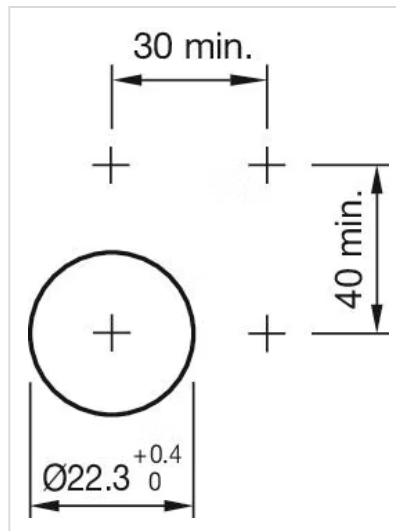
According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

OTHER**Housing material:**

Plastic

Short Description:

Actuator, Ø 29,5 mm, Black, Black, Plastic, Momentary, IP66, IP67, IP69K

Wiring diagrams:**Mounting cut-outs:****Dimension drawings:**

