


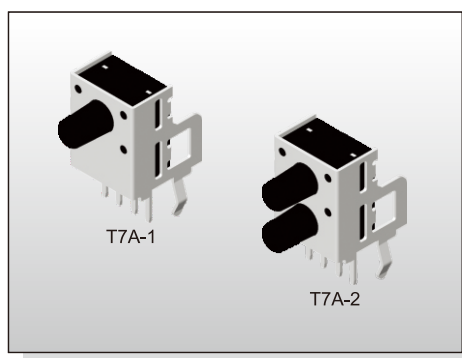

FEATURES

- ※Double switch
- ※Two Circuit


APPLICATION

- ※Audio, OA equipment
- ※Instrumentation
- ※Setup box

SPECIFICATION

Contact Rating	50mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	180±50gf
Travel	0.20mm
Operating Life	100,000 cycles
Operating Temp.	-20°C ~ +70°C
Storage Temp.	-30°C ~ +80°C

CIRCUIT

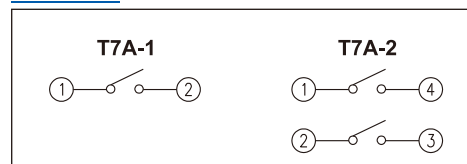

PACKAGE

<Bag>
400 pcs

HOW TO ORDER

T 7 A - 1 4 K Q P

1=Single Stem
2=Double Stem

Stem High:
3.80mm


Package:
Bulk Pack

Halogen Free


Stem Color:
Black

Operating Force:
180gf

T7A-1

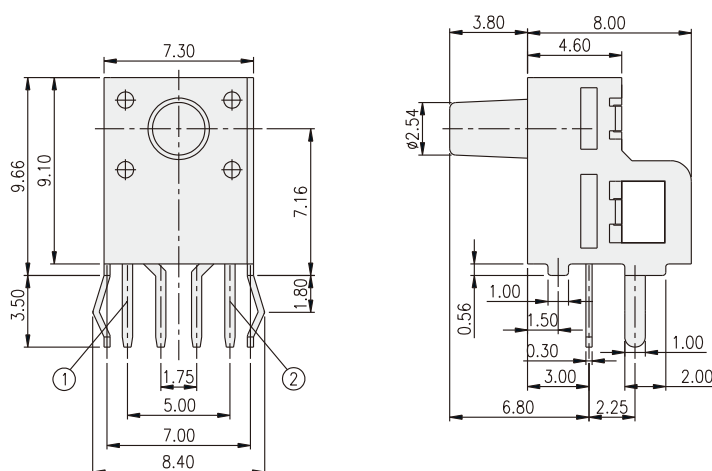

T7A-2

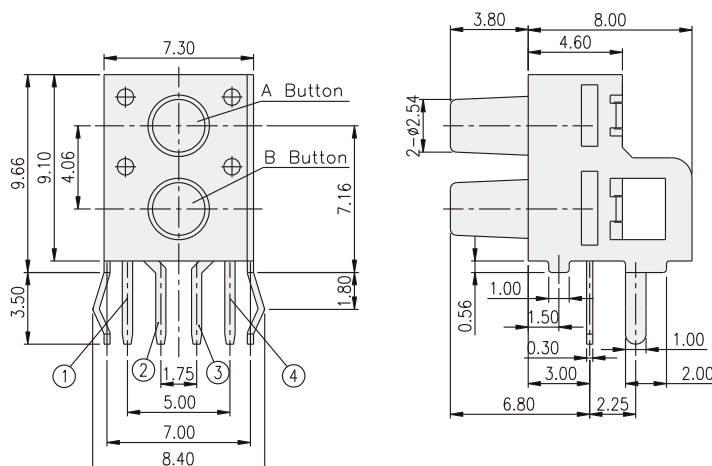

Button	Connected Terminal
A	T1, T4
B	T2, T3