

## IO-Link Touch Stainless Steel

84-ADKS-C10-04B0



<https://eao.com/p/84-ADKS-C10-04B0>

Your product:

---



## 84-ADKS-C10-04B0

### IO-Link Touch Stainless Steel

#### FRONT

Front dimension:	Ø 30 mm
Front form:	round
Front bezel material:	Plastic

#### MOUNTING

Design:	flush
---------	-------

#### OPERATING-/INDICATION PART

Lens illumination:	illuminative
Lens shape:	flush
Lens material:	Plastic
Lens optics:	transparent

#### ELECTRICAL CHARACTERISTICS

Operating voltage:	8,4 - 32,00 V DC
--------------------	------------------

#### MECHANICAL CHARACTERISTIC

Terminal:	Connector M12
Weight:	0.015 kg
Switching system:	Capacitive
Operating force:	No actuating force necessary

## AMBIENT CONDITION


IK front protection:	IK08
IP front protection:	IP69K
Operating temperature:	– 30 °C ... + 65 °C
Climate resistance:	Relative humidity, max. 95%, non-condensing

## CERTIFICATE


Approbations:	CSA, EHEDG
Conformities:	CE, UKCA

## OTHER


Short Description:	IO-Link Touch Stainless Steel, Ø 30 mm, flush, illuminative, Plastic, transparent, round, Plastic, Connector M12, IP69K, IK08, START (C10)
Housing colour:	Black
Housing material:	Plastic
Symbol:	START (C10)
Component layouts:	

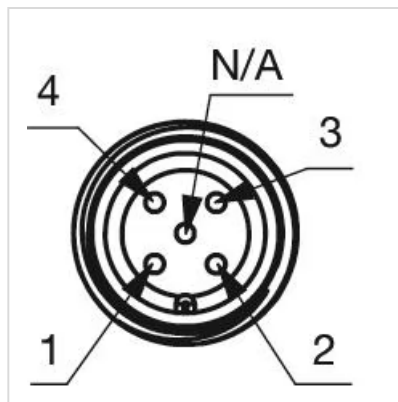

## Wiring diagrams:

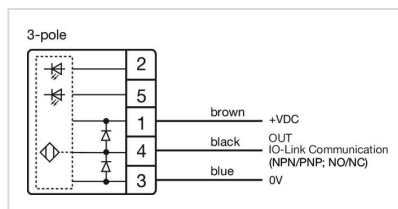

## Dimension drawings:

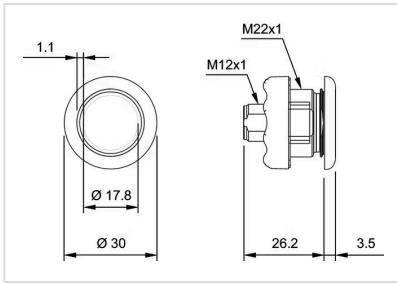

**Mounting cut-outs:**

