


# Actuator

704.064.2

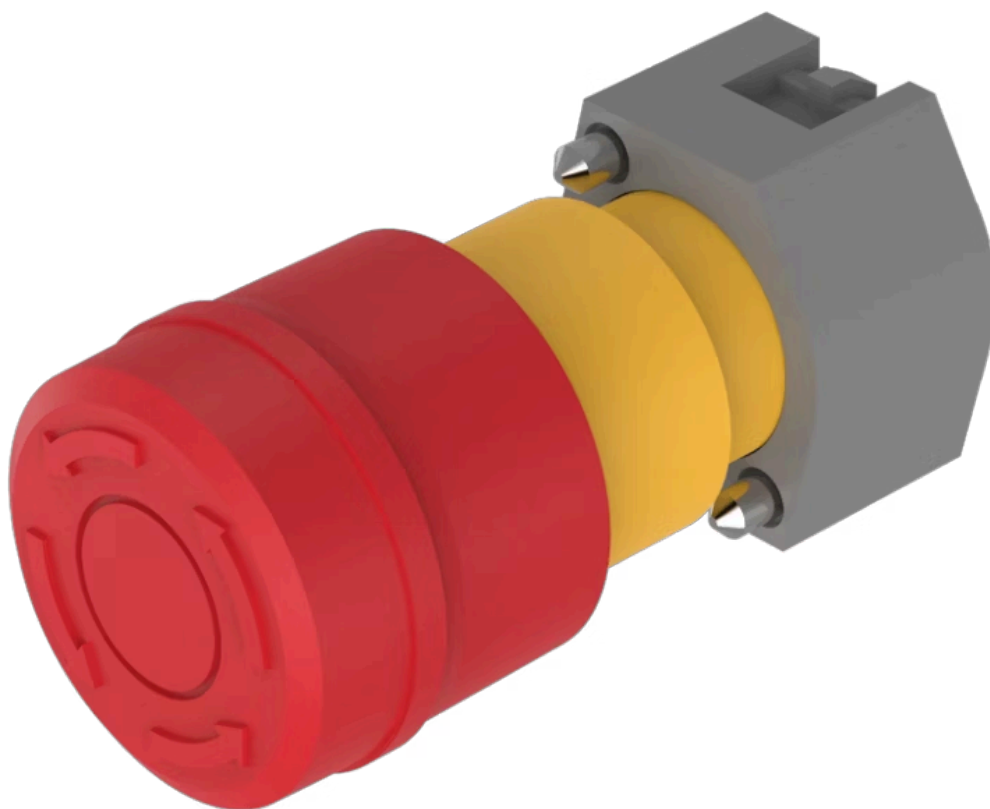

<https://eao.com/p/704.064.2>

Your product:

---



## 704.064.2 Actuator

### FRONT

**Front dimension:** Ø 37 mm

### MOUNTING

**Design:** raised

### OPERATING-/INDICATION PART

**Lens material:** Plastic

**Lens optics:** opaque

**Lens colour:** Red

**Lens illumination:** non illuminative

**Lens shape:** mushroom-head

### ELECTRICAL CHARACTERISTICS

**Standards:** The switches comply with the “Standards for low-voltage switching devices” DIN EN 60947-1

### MECHANICAL CHARACTERISTIC

**Weight:** 0.055 kg

**Operating Travel:** ca. 5.8 mm ± 0.2 mm

**Mechanical lifetime:** ≤50 000 cycles of operation

**Switching action:** Maintained

**Operating force:** 8 N

## AMBIENT CONDITION

**Storage temperature:** – 40 °C ... + 85 °C

**Operating temperature:** – 40 °C ... + 55 °C

**IP Protection:** IP65 front side

## OTHER

**Marking:** Arrows

**Short Description:** Actuator, Ø 37 mm, mushroom-head, non illuminative, Red, Plastic, opaque, Maintained


**Housing colour:** Yellow

**Housing material:** Plastic


**max. number of switching elements:** 2

**Hints:** Shaft yellow


**Mounting cut-outs:**

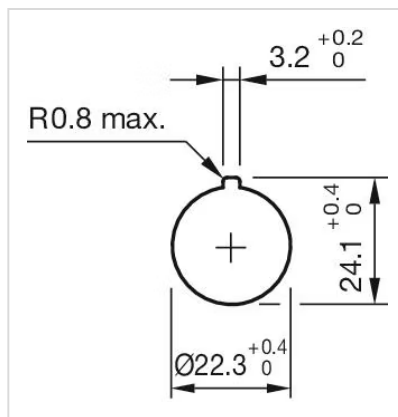

**Wiring diagrams:**

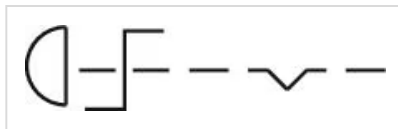

**Dimension drawings:**

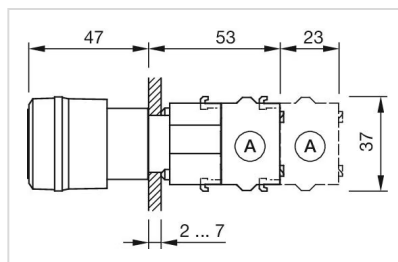

A = Screw terminal