

SUMMARY

Wires

Low voltage 13



Image is for illustrative purpose only

Series	RR
Termination type	Male crimp
IP rating	50
AWG wire size	32.00 - 28.00
Cable Ø	1.00 - 4.00 mm
Status	active

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	FGG*: Straight plug, key (G) or key (A), with cable collet
Keying	3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)
Housing Material	Crastin® PBT (Polybutylene terephthalate), blue
Weight	3.77 g

Performance

Configuration	RR.313 : 13 low voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated Current	



Specifications

Contact Type: Crimp
Test voltage (kV rms) Contact-contact: 0.6

Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

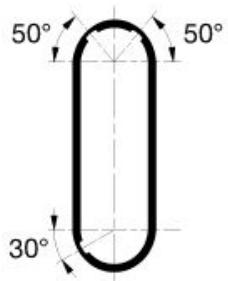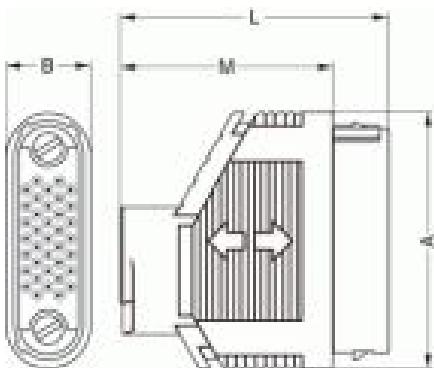

Dimensions

	A	B	L
mm.	37	12.5	39
in.	1,46	0,49	1,54

RECOMMENDED BY LEMO

Tools

Crimp Tool:	DPC.91.701.V
Crimp settings:	AWG/Selector = 28-30-32/4-3-3
Positionner:	DCE.91.050.0VC
Extractor:	DCF.91.050.2LT
Replacement contact:	FGG.00.554.ZZC

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.