


强能电气有限公司

防磁波电缆固定头

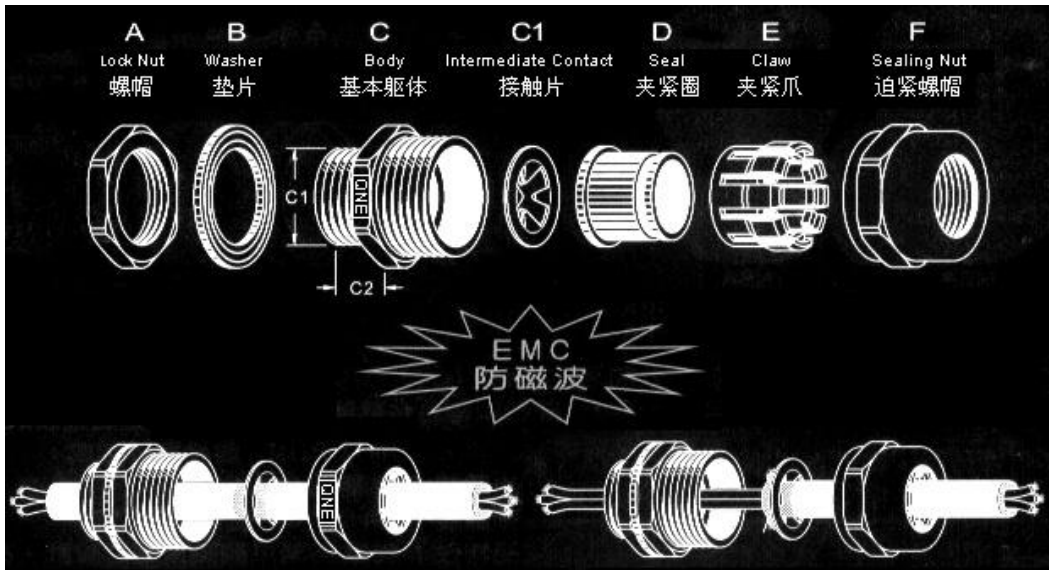

强能型号 标准螺牙	线缆范围 mm	螺纹外径 mm	螺纹长度 mm	扳手尺寸 螺母/螺帽	单价/只	
PG7	4-8	12.5	8	17/17	3.64	
PG9	4-8	15.2	8	18/18	3.93	
PG11	5-10	18.6	9	22/22	5.06	
PG13.5	6-12	20.4	9.5	24/24	5.80	
PG16	9-14	22.5	9.5	25/25	6.68	
PG21	13-18	28.3	12	30/30	9.68	
PG29	18-25	37	12.5	40/40	16.92	
PG36	24-30	47	15	50/50	28.01	
PG42	31-41	54	15	59/59	39.37	
PG48	35-45	59.3	17	67/65	61.68	
M12	4-8	12	8	17/17	3.64	
M16S	4-8	16	9	18/18	3.93	
M16	5-10	16	9	22/22	5.06	
M20S	6-12	20	9.5	24/24	5.80	
M20	9-14	20	9.5	25/25	6.68	
M25	13-18	25	12	30/30	9.68	
M32	18-25	32	12.5	40/40	16.92	
M40	24-30	40	15	50/50	28.01	
M50	31-41	50	15	59/59	39.37	
M63	35-45	63	17	67/65	61.68	

备注：除了以上型号，如需要加厚小孔线缆范围的，请另外咨询我们。谢谢！

- 1) 以上价格不含税和运费，开票另加 12%
- 2) 材质：优质黄铜镀镍；三元乙丙耐候橡胶
尼龙 PA66（UL 认证材料）；
- 3) 报价有效期为 2 个月
- 4) 电话：0577-61679080