


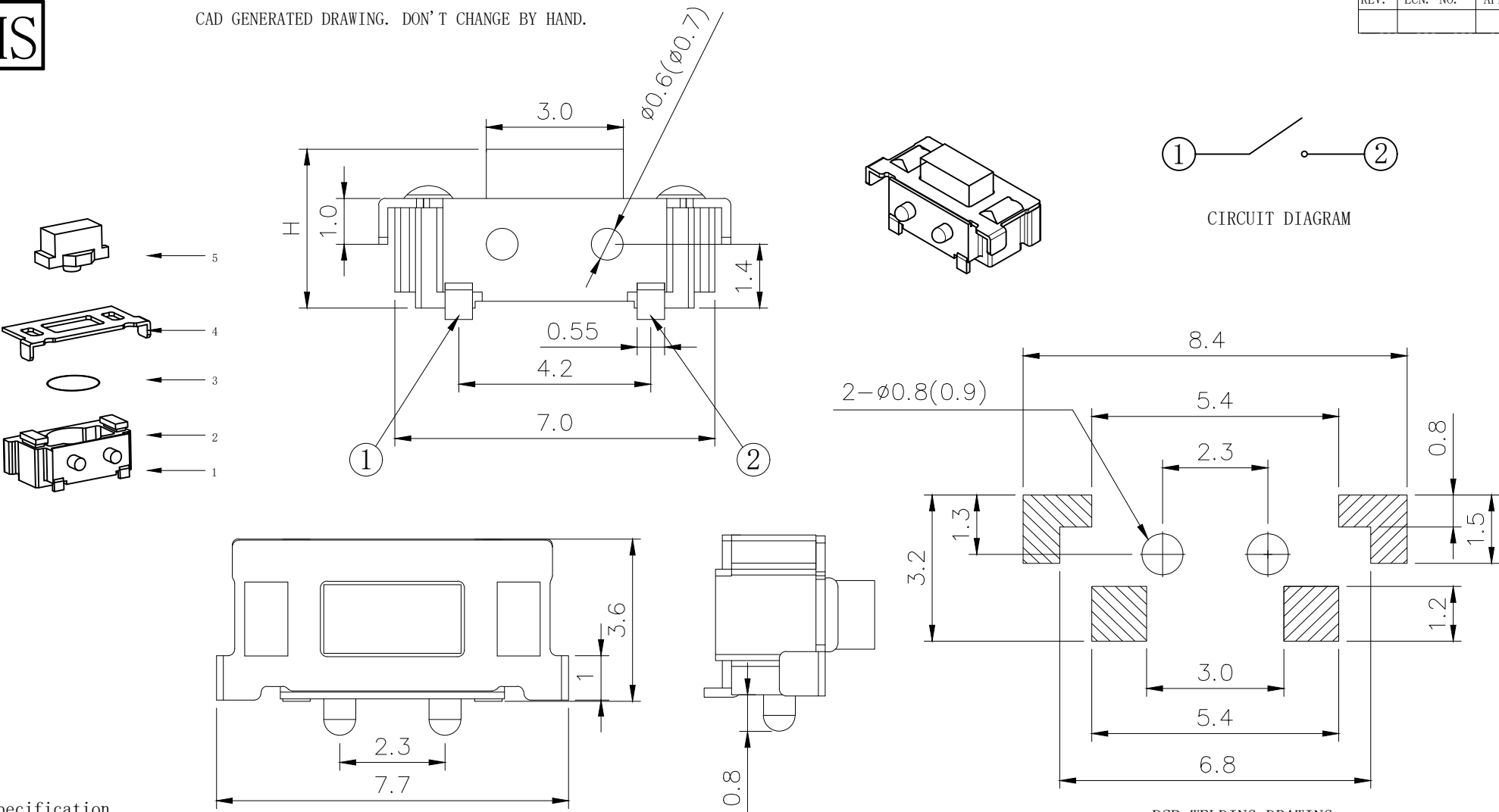

 
Specification

Operating Life	100,000
Contact rating	50mA@12V DC.
Insulation resistance	100MΩ min.
Contact resistance	100mΩ max. initial.
Dielectric Strength	250 V AC(1mn)
Travel	0.2±0.1mm
Storage Temperature	- 30° C to 80° C

Mechanical

E	Button	PPA/Silicone	1	Black/Blue
D	COVER	Phosphor copper	1	Silver
C	DOVE	Stainless Steel	1	Plated Ag
B	HOUSING	PPA	1	Black
A	Cards	Phosphor copper	1	Plated Ag
ITEM	DESCRIPTION	MATERIAL	QTY	FINISH/COLOR

P/N	Operating Force (gf)	Height (mm)	Button Shape (G, J, T)	Leads (G, J, T)	Ground pin (0, 1)	Pegs Option (0, 1)
YTS1C001	3: 250±50	A: 3.5 B: 3.8 C: 3.2	B(Black) U(Blue)	G	1 (Ground pin)	1 (Pegs)
	2: 180±50					
	1: 120±50					

X. ±0.50	X. ° ±2°	UNITS mm		深圳市怡远科技有限公司 SHENZHEN YIYUAN TECHNOLOGY CO.,LTD			
.X ±0.30	.X ° ±1°						
.XX ±0.10	.XX ° ±0.5°	MAT'L 	PART NO. YTS1C001		TITLE: TACTILE SWITCH 6x3mm		
.XXX ±0.05							
THESE DRAWINGS AND SPECIFICATIONS ARE THE PROPERTY OF YIYUAN TECHNOLOGY CO.,LTD AND SHALL NOT BE REPRODUCED. COPIED OR USED IN ANY MANNER WITHOUT THE PRIOR WRITTEN CONSENT OF YIYUAN TECHNOLOGY CO.,LTD Email at info@yiyuanswitches.com		FINISH 	APPD: ROGER		DWG NO. : YTS1C001		
		Q' TY 	CHKD: ROC				
				DR: BILLY WANG 2020/08/21			
					1/1	1/1	A1

Packaging:
Reel of 2,000 pieces.