
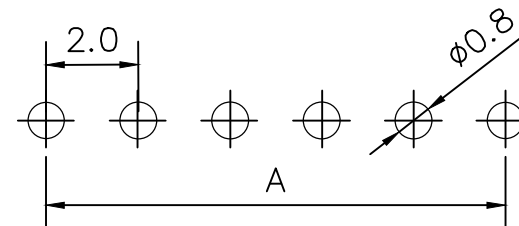


G

Current Rating: 1.0 Amps
Withstanding Voltage: AC 500V
Insulation Resistance: 1000M Ω Min
Contact Resistance: 20m Ω Max
Operation Temperature: -40°to+105°
Insulator Material: Polyester
Contact Material: Brass
Standard: PA6T
Contact Plating: Gold Flash
Max.Processing Temp: 200°C for 30-60seconds
(255°C for 5seconds)

2	接触	铜	镀金	
1	基座	PA6T	本色	
序 号	品 名	材 质	电镀/颜色	备 注

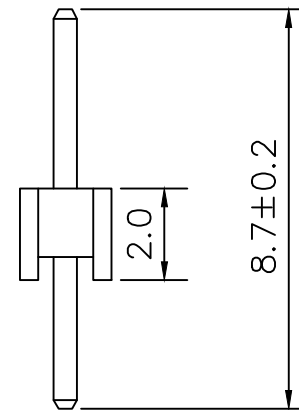