


PXM6011/03P/ST/0709/SN Datasheet



Product Name // Inline Cable Connector PXM6011 Series 3
Contact Plug Screw Termination (contacts supplied fitted)
7mm-9mm Cable (Yellow Gland) Metal Body With Braid
Termination

[View Product Page](#)

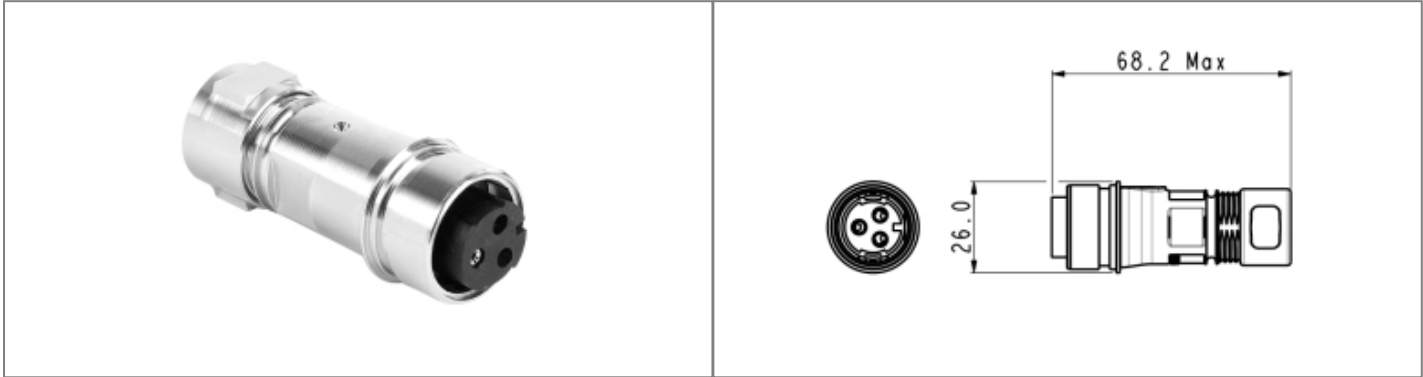

// Product Description:	
- Inline Cable Connectors - Water and dustproof to IP66, IP68, IP69K when mated with compatible connector 30 degree push twist locking, tamperproof lock prevents accidental un-mating - Plug 3 Contacts - Screw contacts supplied fitted	- Metal Body With Braid Termination - Cable acceptance 7mm-9mm diameter - Gland Pack PXP6088 available separately to accomodate all sizes - PXM6082 Sealing Cap available separately to maintain IP rating of unmated connectors - Mate with PXM6010 Series Flex Connectors

// General Information:	
Product Display Title:	Inline Cable Connectors
Product Family:	Circular Power Connectors
Product Series:	6000 Series Buccaneer
Approvals:	UL
Body Colour:	Metallic Grey
Body Material:	Brass
Body Material Type:	Metal Body With Braid Termination
Contact Type:	Plug Contact
Coupling Type:	Push-Twist
Current Max:	16A, 11A
Diameter Over Coupling Ring Mm:	32mm
Function:	Inline Cable Connector
Insulation Resistance:	>10 ⁶ MΩ @500V DC
Ip Rating:	IP66, IP68, IP69K
Max Cable Entry Size:	9mm
Min Cable Entry Size:	7mm
Max Contact Accomodation Awg:	14AWG
Min Contact Accomodation Awg:	14AWG
Max Contact Accomodation Mm2:	2.5mm2
Min Contact Accomodation Mm2:	2.5mm2
Max Operating Temperature:	+120°C
Min Operating Temperature:	-40°C
Number Of Contacts:	3 Contacts
Rohs Compliant:	Yes
Salt Spray Corrosion Test:	EN60068-2-11 Test Ka Salt Mist
Voltage Max:	277V

// Product PDF Links

6000 Series power connectors...

6000 Series metal body power...

// Product 3D CAD Model Links

PXM6011/03P/ST/0709/SN3D CAD Model