

# UC-17P1N8A90DU - Coupler connector



1606513

<https://www.phoenixcontact.com/us/products/1606513>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



M23, Coupler connector, series: UC, straight, shielded: yes, Screw locking mechanism, No. of pos.: 17, Direction of rotation: Standard, contact connection type: Pin, Crimp connection, cable diameter range: 2 mm ... 14.5 mm, coding: N, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1242148

## Commercial data

Item number	1606513
Packing unit	20 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Sales key	AB31
Product key	ABRAIG
GTIN	4046356260022
Weight per piece (including packing)	96.05 g
Weight per piece (excluding packing)	90.03 g
Customs tariff number	85366990
Country of origin	DE

# UC-17P1N8A90DU - Coupler connector



1606513

<https://www.phoenixcontact.com/us/products/1606513>

## Technical data

### Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

### Connector

#### Insulating body

Note	Order information: Order crimp contacts Ø 1 mm separately
Coding	N
Connection method	Crimp connection
Contact switching type	Pin
Application	Signal
Number of positions	17
Direction of rotation	Standard
Connection profile	17
Contact diameter	1 mm
Rated current	8 A
Rated voltage	48 V AC 74 V DC
Rated surge voltage	1.5 kV
Overvoltage category	III
Degree of pollution	3

#### Housing

Housing material	Metal
Type of locking	Screw locking mechanism
Pg screw connection	none
Degree of protection (plugged in)	IP67
Thread type	M23

#### Seal

External cable diameter	2 mm ... 14.5 mm
Seal material	NBR

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (storage/transport)	15 °C ... 25 °C
Permissible humidity (storage/transport)	50 % ... 65 %

# UC-17P1N8A90DU - Coupler connector


1606513

<https://www.phoenixcontact.com/us/products/1606513>



## Drawings

Schematic diagram

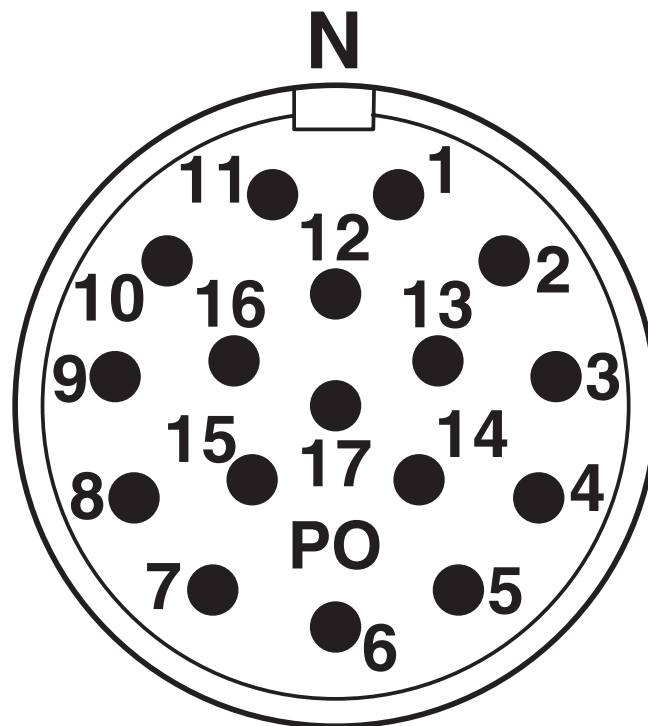

Connector pin assignment

# UC-17P1N8A90DU - Coupler connector



1606513

<https://www.phoenixcontact.com/us/products/1606513>

## Classifications

### ECLASS

ECLASS-11.0	27440390
ECLASS-13.0	27440390
ECLASS-12.0	27440390

### ETIM

ETIM 9.0	EC004746
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# UC-17P1N8A90DU - Coupler connector



1606513

<https://www.phoenixcontact.com/us/products/1606513>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	19ffd7f3-4613-4267-9b77-5b40d3384052

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)