



Identification & Labeling > Printers, Software & Accessories > Printing Software



EU RoHS Compliance: **Compliant**

EU ELV Compliance: **Compliant**

Features

Product Type Features

|           |                                                                          |
|-----------|--------------------------------------------------------------------------|
| Processor | IBM compatible PC - 1GHz or higher 32 bit (x86) or 64bit (x64) processor |
|-----------|--------------------------------------------------------------------------|

Configuration Features

|                  |            |
|------------------|------------|
| Operating System | Windows 10 |
|------------------|------------|

Other

|                    |           |
|--------------------|-----------|
| EU RoHS Compliance | Compliant |
| EU ELV Compliance  | Compliant |

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

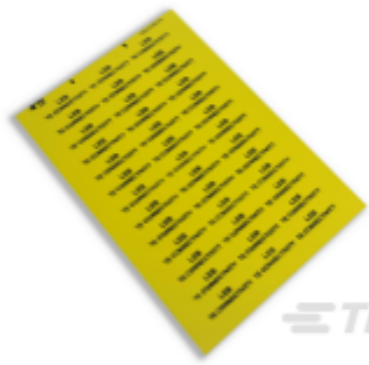
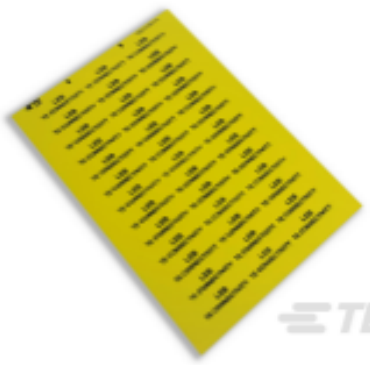
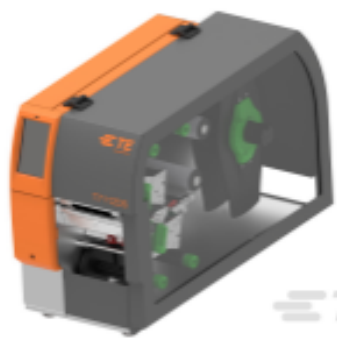
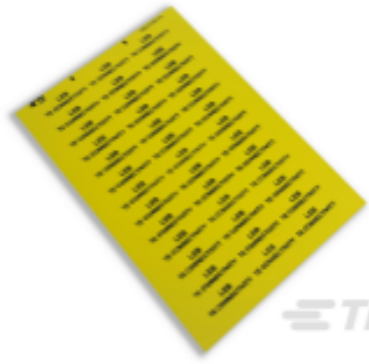
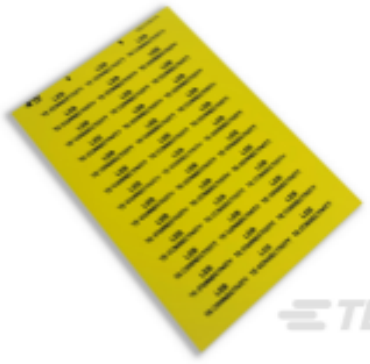
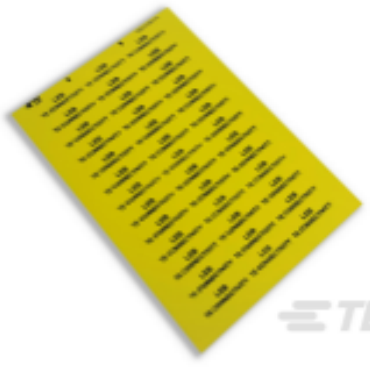
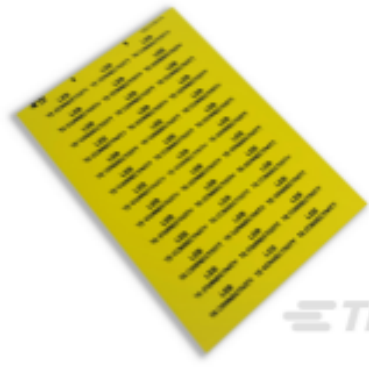
|                                               |                                                                                                                                 |
|-----------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------|
| EU RoHS Directive 2011/65/EU                  | Compliant                                                                                                                       |
| EU ELV Directive 2000/53/EC                   | Compliant                                                                                                                       |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold                                                                                         |
| EU REACH Regulation (EC) No. 1907/2006        | Current ECHA Candidate List: JUNE 2024 (241)<br>Candidate List Declared Against: JUNE 2024 (241)<br>Does not contain REACH SVHC |
| Halogen Content                               | Out of Scope - excluded from Halogen requirements                                                                               |
| Solder Process Capability                     | Not applicable for solder process capability                                                                                    |

Product Compliance Disclaimer



This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts


|                                                                                                                                 |                                                                                                                              |                                                                                                                                         |                                                                                                                                                            |
|---------------------------------------------------------------------------------------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <br>TE Part # 7-1768033-9<br>LEB-1325P-8      | <br>TE Part # 7-1768033-3<br>LEB-1318P-9   | <br>TE Part # CAT-T3437-L49<br>LEB Polyester Labels | <br>TE Part # CAT-T3437-L779<br>Metalized Polyester Labels - LM Series |
| <br>TE Part # 1-2186576-1<br>T7112DS-PRINTER | <br>TE Part # 2-1768034-8<br>LEB-2540P-9  | <br>TE Part # 1-2186527-1<br>T2212-PRINTER         | <br>TE Part # 1-2186528-1<br>T2212-SWARE-PRINTER                      |
| <br>TE Part # 3-1768033-2<br>LEB-0820PF-4    | <br>TE Part # 2-1768034-7<br>LEB-2540P-8A | <br>TE Part # 6-1768033-4<br>LEB-0920PF-4          | <br>TE Part # 1-2186500-1<br>T3212-PRINTER                            |
| <br>TE Part # 1-2186502-1<br>T3224-PRINTER   | <br>TE Part # 4-1768033-3<br>LEB-0851S-8A | <br>TE Part # 7-1768033-2<br>LEB-1318P-8A          | <br>TE Part # 1768033-7<br>LEB-0615P-9                                |




TE Part # 1768033-8  
LEB-0615PF-4



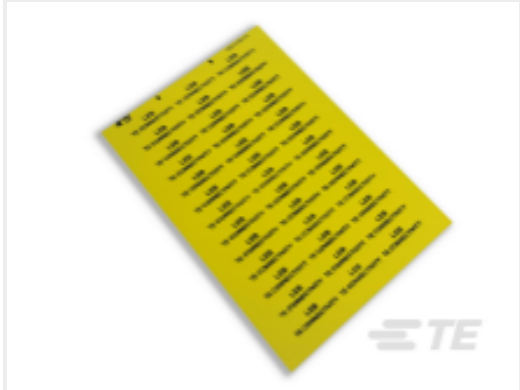TE Part # 1-2186577-1  
T7112DS-SWARE-PRINTER



TE Part # 4-1768034-3  
LEB-5320P-8A

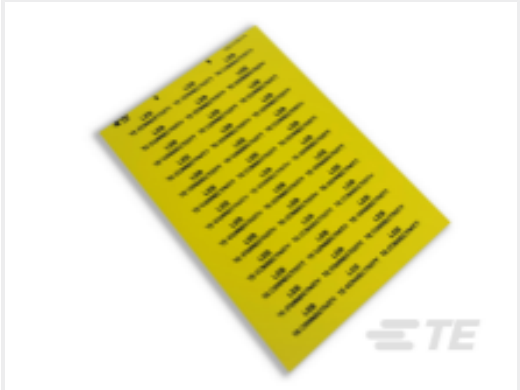

TE Part # 8-1768033-3  
LEB-1325S-8A

Also in the Series | WinTotal



Printing Software(2)

Customers Also Bought



TE Part #EC1066-000  
06181929



TE Part #EC1057-000  
06181920



TE Part #EC1040-000  
06181903



TE Part #1-2186527-1  
T2212-PRINTER

TE Part #ZPF000000000026696  
941 D 20 A 121-91 PN

TE Part #ZPF000000000026745  
941 D 21 A 19-7 PN

TE Part #EC8941-000  
ETM-0-064050-B

TE Part #374Z-05834  
Speed sen DSD 1820.19P27HW 3EST-214-487

TE Part #9-1414778-5  
RESOLVER V23401-D4010-C101

TE Part #9-1768415-6  
LBG-U-03290/EET2067



Documents

Product Drawings

WINTOTAL-7-DONGLE

English

Datasheets & Catalog Pages

PRINTER FAQ

English