



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: DEC 2010 (44) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

<div>TE Part # 493831-3</div> <div>HSG ASSY 76P PIN CONTACT</div>	<div>TE Part # 1599186-4</div> <div>HSG ASSY 76 POSN SOCKET CONT</div>	<div></div> <div>TE Part # 1599186-1</div> <div>HSG ASSY 76 POSN SOCKET CONT</div>	<div>TE Part # 493835-1</div> <div>OUTER PERIPHERAL SEAL 76P</div>
---	--	---	--

Customers Also Bought



TE Part #HD10-9-1939PE-B022
REC, 9P, BLK, E, PANEL, J1939, TYPE 1



TE Part #776429-2
AS16,PLUG ASSY,ST,03P,N SEAL, CODE B



TE Part #3-1418390-1
4 POS AMP MCP 2.8 REC HSG




TE Part #1718489-1
AMP MCP 1.5 RECEPT HSG 18 POS



TE Part #185792-1
180 DEG CAP FOR CORRUGTD TUBE



TE Part #DRC26-24SA
PLG, 24P, BLK, N, A

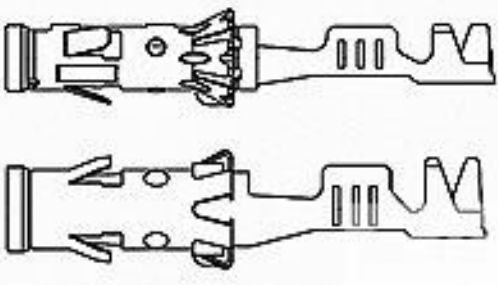

TE Part #929975-8
2,5MM SOCKET CONTACT SWS



TE Part #493577-2
ASSY 10 WAY JPT REC



TE Part #2050832-2
COVER FOR 3P SENSOR CONNECTOR



TE Part #2345388-1
2POS,AMP MCP 2.8,REC HSG ASSY, SLD,COD 1

Documents

Product Drawings

HSG ASSY 76 POS PIN CONTACT

English

CAD Files

Customer View Model

ENG_CVM_CVM_1599185-1_B.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1599185-1_B.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1599185-1_B.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.