

# HC-STA-D07-BCLFS-PLR-BK - Protective cover



1419270

<https://www.phoenixcontact.com/us/products/1419270>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Protective cover D7, for single locking latch, material: PA, protective cover material: PA, height: 29.4 mm, seal: yes, Standard, with lanyard, for socket inserts



## Commercial data

Item number	1419270
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF66
Product key	BF7AZC
Catalog page	Page 514 (C-2-2019)
GTIN	4055626160214
Weight per piece (including packing)	8.9 g
Weight per piece (excluding packing)	8.5 g
Customs tariff number	85389099
Country of origin	CN

# HC-STA-D07-BCLFS-PLR-BK - Protective cover



1419270

<https://www.phoenixcontact.com/us/products/1419270>

## Technical data

 
### Notes

General	For use on the panel mounting base
---------	------------------------------------

### Product properties

Product type	Protective cover
Housing type	Protective cover
Application	Standard
Type	D7
Type	for supporting base element with single locking latch
Retaining cord present	yes
Seal present	yes

### Dimensions

Dimensional drawing	
Width	34.2 mm
Height	29.4 mm
Length	26.5 mm
Diameter	25 mm

### Material specifications

Color	black (RAL 9005)
Material Protective cover	PA
Flammability rating according to UL 94	V0 (Polyamide housing)
Seal material	NBR
Housing material	PA
Material, protective cover	PA

### Mechanical properties

#### Mechanical data

Locking type	Pin
--------------	-----

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP66
Ambient temperature (operation)	-20 °C ... 100 °C

### Mounting

Assembly note	Plastic protective cover for short-term protection
---------------	--

# HC-STA-D07-BCLFS-PLR-BK - Protective cover


1419270

<https://www.phoenixcontact.com/us/products/1419270>



## Drawings

Dimensional drawing

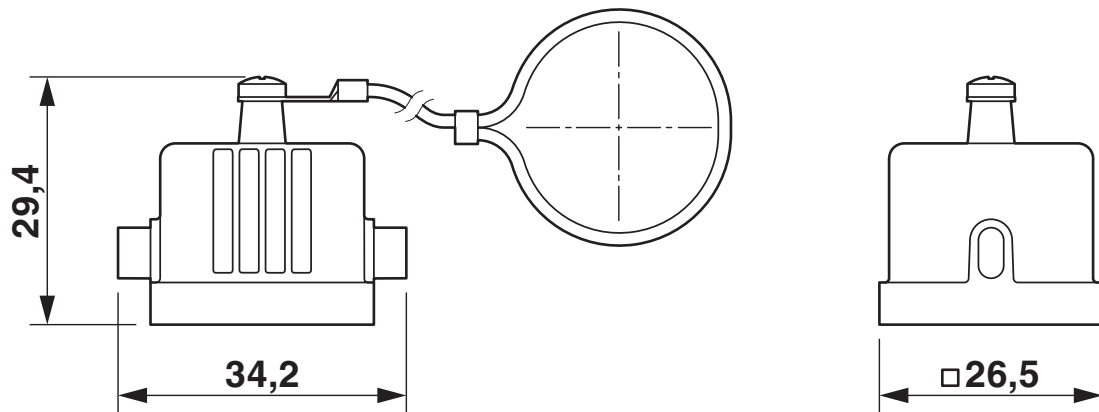

Dimensional drawing

# HC-STA-D07-BCLFS-PLR-BK - Protective cover



1419270

<https://www.phoenixcontact.com/us/products/1419270>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1419270>

### **DNV**

Approval ID: TAE000037S

# HC-STA-D07-BCLFS-PLR-BK - Protective cover



1419270

<https://www.phoenixcontact.com/us/products/1419270>

## Classifications

### ECLASS

ECLASS-11.0	27440208
ECLASS-12.0	27440208
ECLASS-13.0	27440208

### ETIM

ETIM 9.0	EC002314
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# HC-STA-D07-BCLFS-PLR-BK - Protective cover



1419270

<https://www.phoenixcontact.com/us/products/1419270>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)