

SMA-A0204FTDX33R

✓ ACTIVE

Neohm | Neohm SMA-A

TE Internal #: 8-2176315-1

Surface Mount Precision Resistor, Thin Film, 0204, .4 W, 33 ohm, 1 %, ±50 ppm/°C, Metal Electrode Leadless Face (MELF), 2 Terminations, Neohm SMA-A

[View on TE.com >](#)



Passive Components > Resistors > Surface Mount Resistors



Resistor Type: Precision Resistor

Element Type: Thin Film

Package Size Code: 0204

Power Rating: .4 W

Resistance Value: 33 Ω

Features

Dimensions

|                  |                 |
|------------------|-----------------|
| Product Diameter | 1.4 mm[.055 in] |
| Product Length   | 3.5 mm[.138 in] |

Usage Conditions

|                             |              |
|-----------------------------|--------------|
| Operating Temperature Range | -55 – 155 °C |
| Temperature Coefficient     | ±50 ppm/°C   |

Electrical Characteristics

|                             |           |
|-----------------------------|-----------|
| Operating Voltage           | 200 V     |
| Power Rating                | .4 W      |
| Resistance Value            | 33 Ω      |
| Resistance Class            | Up to 1kΩ |
| Passive Component Tolerance | 1 %       |

Product Type Features

|               |                    |
|---------------|--------------------|
| Resistor Type | Precision Resistor |
| Element Type  | Thin Film          |

|                   |      |
|-------------------|------|
| Package Size Code | 0204 |
|-------------------|------|

Configuration Features

|                     |   |
|---------------------|---|
| Number of Resistors | 1 |
|---------------------|---|

Termination Features

|                                         |                                      |
|-----------------------------------------|--------------------------------------|
| Surface Mount Resistor Termination Type | Metal Electrode Leadless Face (MELF) |
| Number of Terminations                  | 2                                    |

Packaging Features

|                  |                |
|------------------|----------------|
| Packaging Method | Taped & Reeled |
|------------------|----------------|

Other

|                    |           |
|--------------------|-----------|
| EU RoHS Compliance | Compliant |
| EU ELV Compliance  | Compliant |

Product Compliance

For compliance documentation, visit the product page on TE.com>


|                                               |                                                                                                                                 |
|-----------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------|
| EU RoHS Directive 2011/65/EU                  | Compliant                                                                                                                       |
| EU ELV Directive 2000/53/EC                   | Compliant                                                                                                                       |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold                                                                                         |
| EU REACH Regulation (EC) No. 1907/2006        | Current ECHA Candidate List: JUNE 2024 (241)<br>Candidate List Declared Against: JUNE 2024 (241)<br>Does not contain REACH SVHC |
| Halogen Content                               | Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free                                             |
| Solder Process Capability                     | Reflow solder capable to 260°C                                                                                                  |

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>




Compatible Parts

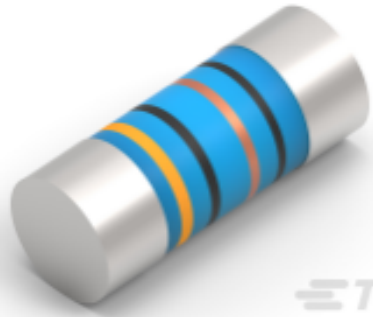


TE Part # 9-2176315-8  
MELF SMA-A 1M0 1% 50PPM 0204 0.4 W

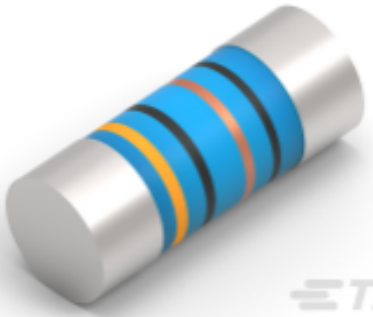


TE Part # 6-2176314-9  
MELF SMA-A 10R 1% 50PPM 0102 0.3 W

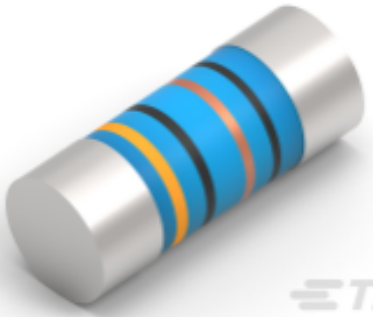

TE Part # 2176316-5  
MELF SMA\_A 220R 0.1% 15PPM 0207 1W

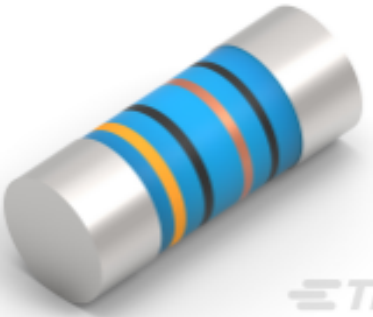

TE Part # 9-2176316-4  
MELF SMA-A 330K 1% 50PPM 0207 1W

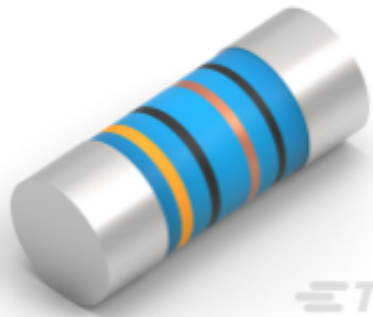

TE Part # 3-2176315-2  
MELF SMA\_A 39K 0.1% 15PPM 0204 0.4W

Also in the Series | [Neohm SMA-A](#)



[Surface Mount Resistors\(270\)](#)

Customers Also Bought



TE Part #338068-4  
MICRO-MATCH FTE, 4P



TE Part #7-2176231-7  
3522 15K 1% 3W



TE Part #1565994-4  
RITS HDR ASSY R/A SMT TYPE 4P WITH BOSS



TE Part #5-2176397-6  
3502 200R 1%








TE Part #5-2301995-4  
RJ45 JACK INT.MAG. 1GB LED 1X1  
VERT.




TE Part #2-1416010-3  
RE034005



TE Part #2-1416010-6  
RE034012

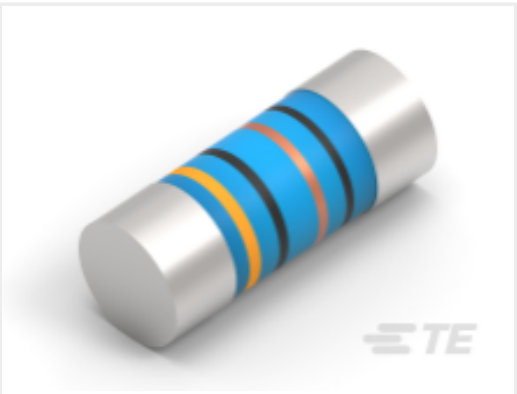

TE Part #7-2176316-0  
MELF SMA\_A 47K 1% 50PPM 0207 1W

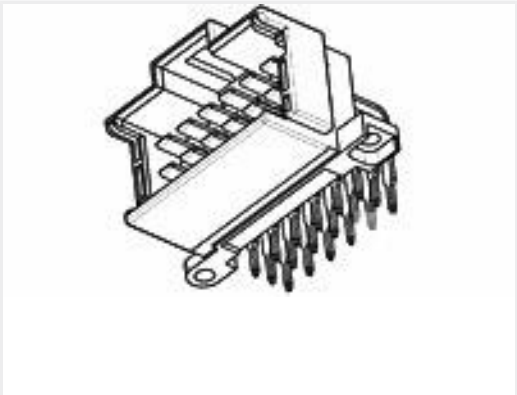

TE Part #9-966140-6  
MESSERLEISTE 21P



TE Part #5-1814400-2  
SMA R/A PCB Skt GZD

Documents

Product Drawings

MELF SMA-A 33R 1% 50PPM 0204 0.4W

English

CAD Files

3D PDF

3D

Customer View Model

ENG\_CVM\_CVM\_8-2176315-1\_BA.2d\_dxf.zip

English

Customer View Model

ENG\_CVM\_CVM\_8-2176315-1\_BA.3d\_igs.zip

English

Customer View Model

ENG\_CVM\_CVM\_8-2176315-1\_BA.3d\_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

SMA-A-1017

English