




Connectors > Connector Accessories > Connector Caps & Covers

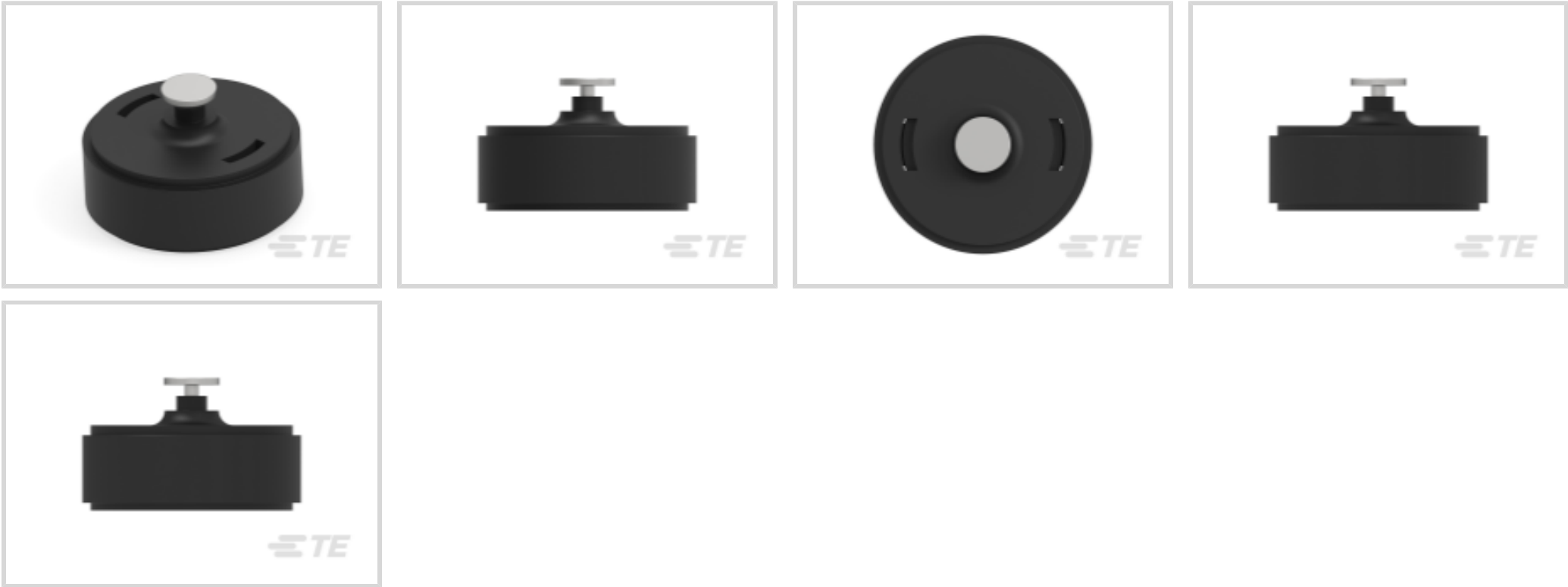

Connector Cover Type: **Sealing Cap**
Primary Product Color: **Black**
Primary Product Material: **Thermoplastic**
Operating Temperature (Max): **105 °C [221 °F]**
Operating Temperature Range: **-55 – 105 °C [-67 – 221 °F]**

Features

Housing Features

Compatible With Connector Shape	Circular
---------------------------------	----------

Industry Standards

UL Flammability Rating	UL 94V-1
------------------------	----------

Mechanical Attachment

Component Retention Feature	Metal Bead Chain
-----------------------------	------------------

Operation/Application

Compatible With Connector Shell Size	11
--------------------------------------	----

Packaging Features

Packaging Method	Bag
Packaging Quantity	100

Body Features

Seal Material	Elastomer
Primary Product Color	Black
Primary Product Material	Thermoplastic



Product Type Features

Connector Cover Type	Sealing Cap
----------------------	-------------

Usage Conditions

Operating Temperature (Max)	105 °C[221 °F]
Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1977880-1
SLD CPC RCPT ASSY, 11-4, REV SEX, UV RESIS

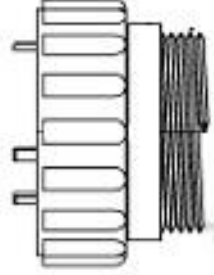

TE Part # 206516-1
CPC PLUG ASSEMBLY SIZE 11-4




TE Part # 205838-1
CPC PLUG ASSEMBLY SIZE 11-8



TE Part # 1977878-1
SLD CPC PLUG ASY, 11-4, STD SEX, UV RESIST



TE Part # 788155-2
SLD CPC RCPT ASSY, 11-4, REV SEX

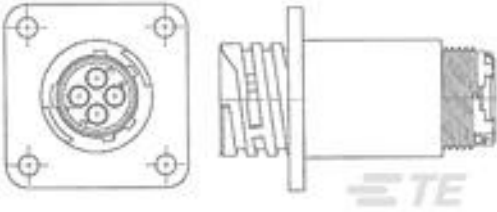

TE Part # 788154-2
SLD CPC RCPT ASSY, 11-4, REV SEX



TE Part # 206434-1
CPC PLUG ASSEMBLY SIZE 11-8



TE Part # 206061-2
CPC RECPT ASSEMBLY SIZE 11-4



TE Part # 206060-1
CPC PLUG ASSEMBLY SIZE 11-4



TE Part # 788153-2
SLD CPC PLUG ASSY, 11-4, REV SEX



TE Part # 207485-1
CPC PLUG ASSEMBLY SIZE 23-16



TE Part # 206430-3
CPC RECPT ASSEMBLY SIZE 11-4



TE Part # 796095-2
SLD CPC RCPT ASY, 11-4, STD SEX



TE Part # 796096-2
SLD CPC RCPT ASY, 11-4, STD SEX



TE Part # 796094-2
SLD CPC PLUG ASY, 11-4, STD SEX



TE Part # 1977876-1
SLD CPC RCPT ASY, 11-4, STD SEX, UV RESIST



TE Part # 206153-2
CPC RECPT ASSEMBLY SIZE 11-4



TE Part # 206485-1
CPC PLUG ASSEMBLY SIZE 11-9



TE Part # 206429-1
CPC PLUG ASSY, 11-4, REV SEX

Also in the Series | [AMP CPC](#)



Connector Backshells(1)



Connector Caps & Covers(16)



Connector Contacts(6)



Connector Seals & Cavity Plugs(35)



Connector Strain Relief(60)



Insertion & Extraction Tools(1)



Power Contacts(6)

Customers Also Bought



TE Part #CAT-C339-SB19B
Wirewound Resistor: Vertical Mount




TE Part #206425-1
17-3 RECPT. REV SEX




TE Part #213856-4
CPC RECPT ASSEMBLY SIZE 23-37



TE Part #206036-2
CPC RECEPTACLE SIZE 17-3

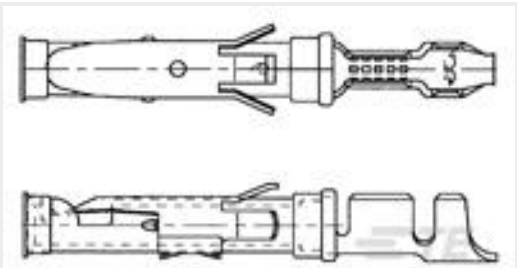


TE Part #163092-1
062 SOC.ASS. TYP3+

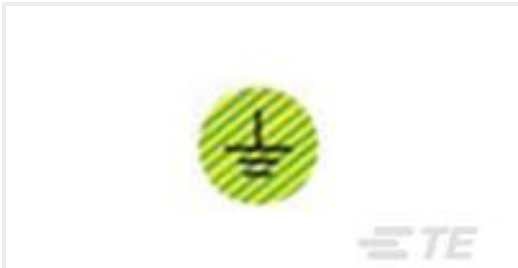


TE Part #6-1768034-2
LKZ12B4



TE Part #C37234-000
HM-381191-5-8A

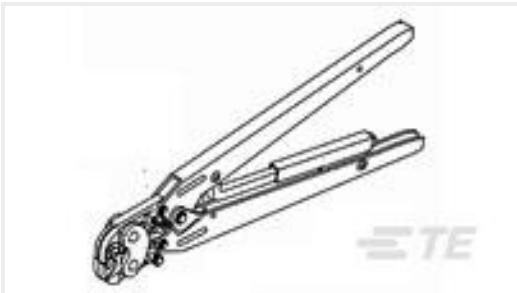

TE Part #525691
DAHT PG PIDG 16-14 ASSY

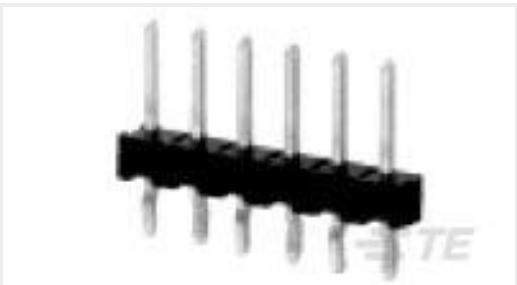

TE Part #5-146261-4
08 MODII HDR DRST B/A .100CL LF

Documents



Product Drawings

SEALING CAP ASSY,SZ 11,CPC

English

CAD Files

Customer View Model

ENG_CVM_CVM_208800-1_F.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_208800-1_F.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_208800-1_F.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMP Circular Connectors for Commercial Signal & Power Applications Continued

English

Instruction Sheets

Instruction Sheet (U.S.)

English

Agency Approvals

CSA Certificate

English

CSA Certificate

English