



Connectors > Connector Accessories > Connector Strain Relief



Strain Relief Accessory Type: Cable Clamp Kit

Primary Product Material: Nylon

Primary Product Color: Black

Compatible With Connector Shell Size: 11

Cable Entry Diameter: 11.51 mm [.453 in]

Features

Housing Features

Compatible With Connector Shape	Circular
Body Orientation	Right Angle

Product Type Features

Strain Relief Accessory Type	Cable Clamp Kit
------------------------------	-----------------

Body Features

Primary Product Material	Nylon
Primary Product Color	Black

Operation/Application

Compatible With Connector Shell Size	11
Shielded	No

Dimensions

Cable Entry Diameter	11.51 mm[.453 in]
----------------------	-------------------

Mechanical Attachment

Thread Size	3/4-20 UNEF-2B
-------------	----------------



Packaging Features

Packaging Method	Bag
Packaging Quantity	1

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JAN 2024 (240) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



 TE Part # 1445829-1 REC,11-5,FRE HNG,SM INS,STD KE	 TE Part # 1445822-1 REC,11-7,FLNG MT,SM INS,STD KE	 TE Part # 1445821-3 REC,11-8,FLNG MT,LG INS,STD KE	 TE Part # 1445820-1 PLUG,11-5,SM INS,STD KEY
 TE Part # 1445825-1 RECPT,11-9,FREE HNG,STD KEY	 TE Part # 1445817-3 PLUG,11-8,LG INS,STD KEY	 TE Part # 1445823-1 REC,11-6,FLNG MT,SM INS,STD KE	 TE Part # 1445824-3 REC,11-5,FLNG MT,LG INS,STD KE
 TE Part # 1445826-1 REC,11-8,FRE HNG,SM INS,STD KE	 TE Part # 1445826-3 REC,11-8,FRE HNG,LG INS,STD KE	 TE Part # 1445828-1 REC,11-6,FRE HNG,SM INS,STD KE	 TE Part # 1445816-3 RECPT,11-9,FLNG MT,STD KEY
 TE Part # 1445816-1 RECPT,11-9,FLNG MT,STD KEY	 TE Part # 1445823-3 REC,11-6,FLNG MT,LG INS,STD KE	 TE Part # 1445818-3 PLUG,11-7,LG INS,STD KEY	 TE Part # 1445822-3 REC,11-7,FLNG MT,LG INS,STD KE
 TE Part # 1445829-3 REC,11-5,FRE HNG,LG INS,STD KE	 TE Part # 1445807-3 PLUG,11-9,LG INS,STD KEY	 TE Part # 1445820-3 PLUG,11-5,LG INS,STD KEY	 TE Part # 1445827-1 REC,11-7,FRE HNG,SM INS,STD KE

Also in the Series | AMP CPC



Connector Backshells(1)



Connector Caps & Covers(16)



Connector Contacts(6)



Connector Seals & Cavity Plugs(35)



Connector Strain Relief(60)



Insertion & Extraction Tools(1)



Power Contacts(6)


Customers Also Bought



TE Part #CAT-H3399-CH8172
Heavy Duty Sealed Connector Series Housings



TE Part #2-1355668-2
JPT EDS BUGH,ASSY2P

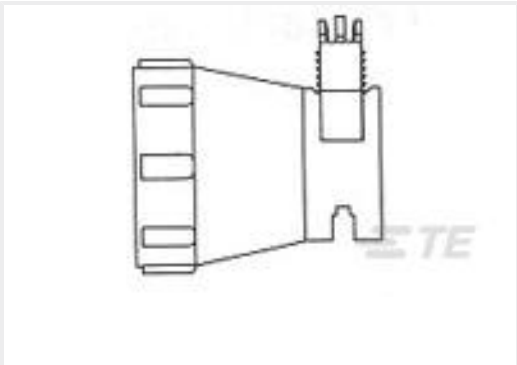

TE Part #1445856-1
STR RELIEF ASY,STRAIGHT SZ 11



TE Part #1622795-5
YR1 0.1% 4K02




TE Part #7-1676914-3
YR1 0.1% 60K4




TE Part #2-963860-1
TAB 2.8x0.8 CONTACT CF SRC Sn



TE Part #OTX-418-HH-LR8-MS
Remote MS 418MHz OOK AM 8Btn HH TX FCC

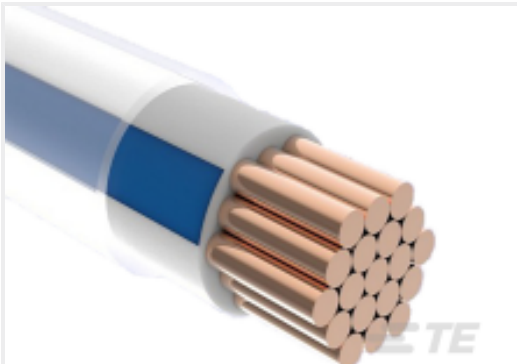

TE Part #9024723001
ACW0219-1.00-9(NS)

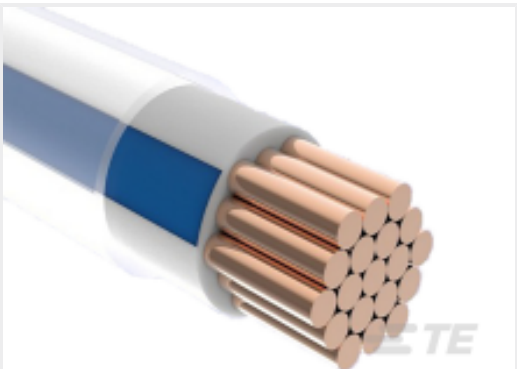

TE Part #4569203001
ACW0219-0.50-9(NS)

Document



Product Drawings

R/A CABLE CLAMP KIT,SZ 11, MINI CPC

English

CAD Files

Customer View Model

ENG_CVM_1546746-4_C.3d_igs.zip

English

Customer View Model

ENG_CVM_1546746-4_C.3d_stp.zip

English

Customer View Model

ENG_CVM_1546746-4_C.2d_dxf.zip

English

3D PDF

English

Customer View Model

ENG_CVM_CVM_1546746-4_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1546746-4_C.3d_stp.zip

English

Customer View Model

ENG_CVM_CVM_1546746-4_C.2d_dxf.zip

English

3D PDF

3D

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

1-1773902-9_CPC_Catalog

English

1-1773902-9_CPC_Catalog

1-1773902-9_CPC_Catalog

German

1-1773902-9_CPC_Catalog

Japanese

AMP Circular Connectors for Commercial Signal & Power Applications Continued

English