



Terminals & Splices > Ring Terminals



Ring Terminal Product Type: Closed Ring Tongue Terminal

Wire Size: 133000 CMA

Tongue Thickness: 4 mm [.15 in]

Features

Packaging Features

Packaging Quantity	300
Packaging Method	Bag

Product Type Features

Ring Terminal Product Type	Closed Ring Tongue Terminal
Sealable	No
Wire Insulation Support Retention Type	Crimp Barrel

Contact Features

Barrel Type	Closed
Terminal Orientation	Straight
Terminal Plating Material	Tin
Contact Underplating Material	Nickel

Dimensions

Wire Size	133000 CMA
Tongue Thickness	4 mm[.15 in]
Product Length	50 mm[1.96 in]
Barrel Inside Diameter	12.2 mm[.48 in]



Usage Conditions

Operating Temperature Range	-40 – 140 °C[-40 – 284 °F]
-----------------------------	----------------------------

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts




TE Part # 7-2359763-7
CRIMP TOOLING KIT

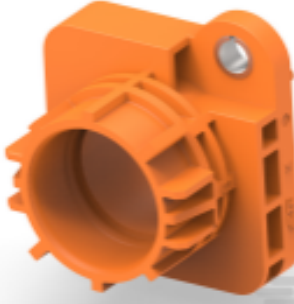

TE Part # 2-2443905-1
PROP,IPT-HD-1P-ASSY-50-95MM2-CODE-B

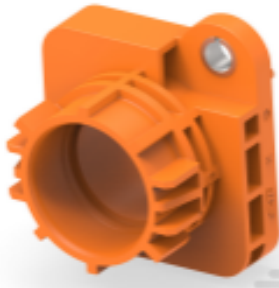

TE Part # 7-2443905-1
PROP,IPT-HD-1P-ASSY-50-95MM2-CODE-G

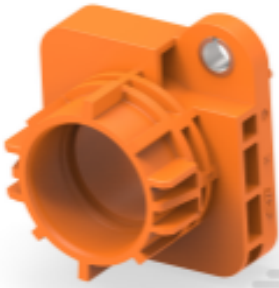


TE Part # 5-2443905-1
PROP,IPT-HD-1P-ASSY-50-95MM2-CODE-E




TE Part # 2443905-1
PROP,IPT-HD-1P-ASSY-50-95MM2




TE Part # 8-2443905-1
PROP,IPT-HD-1P-ASSY-50-95MM2-CODE-H

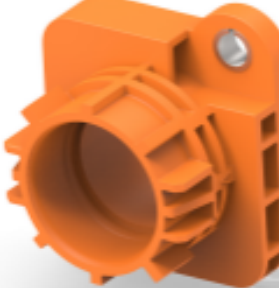


TE Part # 1-2443905-1
PROP,IPT-HD-1P-ASSY-50-95MM2-CODE-A

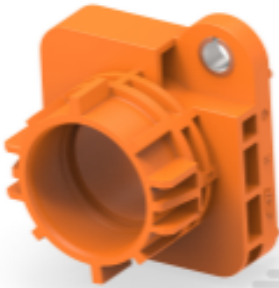

TE Part # 4-2443905-1
PROP,IPT-HD-1P-ASSY-50-95MM2-CODE-D

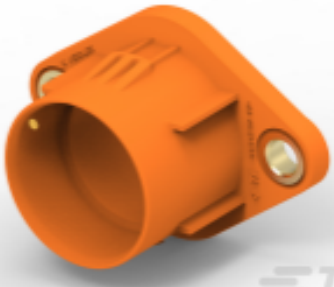


TE Part # 2371019-2
1POS,IPT,RING TONGUE HSG ASSY, SLD

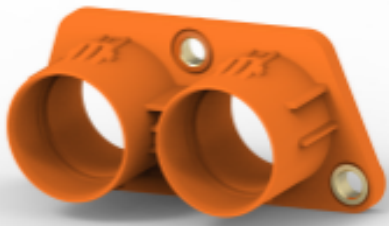

TE Part # 2371017-2
2POS,IPT,RING TONGUE HSG ASSY, SLD




TE Part # 2371019-1
1POS,IPT,RING TONGUE HSG ASSY, SLD

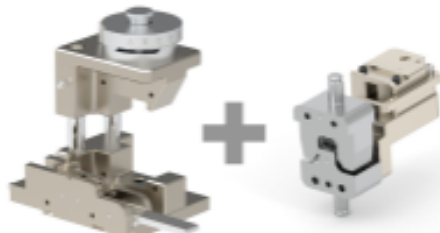


HV APPLICATOR
REPRESENTATION ONLY. DIE SET MAY VARY.


TE Part # 9-2359763-1
APPLIC IPT STAMPING T 70MM2

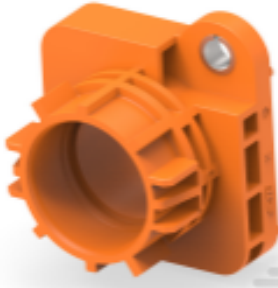

TE Part # 3-2443905-1
PROP,IPT-HD-1P-ASSY-50-95MM2-CODE-C

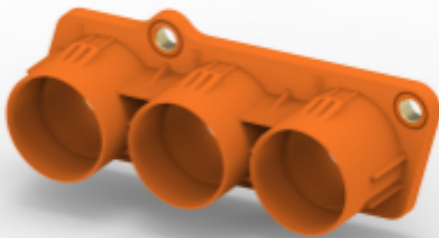

TE Part # 2355146-2
3POS,IPT,RING TONGUE HSG ASSY, SLD

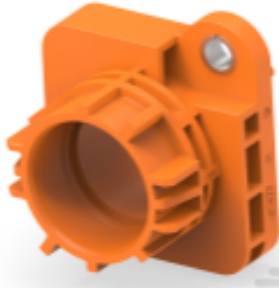

TE Part # 6-2443905-1
PROP,IPT-HD-1P-ASSY-50-95MM2-CODE-F



TE Part # 2371017-1
2POS,IPT,RING TONGUE HSG ASSY, SLD



TE Part # 2355146-1
3POS,IPT,RING TONGUE HSG ASSY, SLD

Also in the Series | **IPT-HD**



Automotive Connector Caps & Covers (46)



Automotive Connector EMC Shielding (12)



Automotive Housings(23)



Automotive Terminals(1)



Connector Seals & Cavity Plugs(5)



Ring Terminals(3)

Customers Also Bought



TE Part #2365737-2
RING TONGUE TRMNL,95MM2 WIRE FOR IPT



TE Part #2371035-1
3POS,DIA 4MM,SOC HSG ASSY,SLD, COD A



TE Part #1670144-3
MCON 1.2 CB REC SRC AG



TE Part #2203990-1
13P UNSEALED PLUG, ASSY, KEY A




TE Part #2327375-1
26POS,MCON 1.2,REC HSG ASSY,SLD, COD A



TE Part #2355148-1
SLEEVE,IPT 3P SHIELDING




TE Part #2355150-2
SLEEVE,IPT 3P SHIELDING

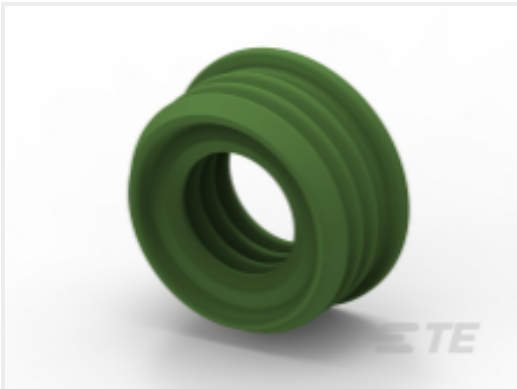

TE Part #2355151-1
SWS,COAX



 TE Part #2355153-1
COVER,IPT 3P



TE Part #1-1823212-8
MAGNET P212

Documents



Product Drawings

RING TONGUE TRMNL,70MM2 WIRE FOR IPT

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2365737-1_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_2365737-1_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2365737-1_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

HIVONEX CONNECTORS & CHARGING SOLUTIONS

English

Product Specifications

Application Specification

English

Application Specification

English