

1977881-1

✓ ACTIVE

AMP | AMP CPC

TE Internal #: 1977881-1

4 Position Circular Power Connector, Housing, 600 VDC, Wire-to-Wire, Sealable, Wire & Cable, Plug, Reverse Gender, Pin, Signal, Black, AMP CPC

[View on TE.com >](#)

Connectors > Power Connectors > Circular Power > Circular Power Connectors



Number of Positions: 4

Connector Product Type: **Housing**

Operating Voltage: 600 VDC

Connector System: **Wire-to-Wire**

Sealable: **Yes**

Features

Packaging Features

Packaging Quantity	100
Packaging Method	Bag

Mechanical Attachment

Mating Alignment Type	Keyed
Mating Retention Type	Threaded Coupling
Thread Size	5/8-24 UNEF-2A
Mating Alignment	With
Polarization Code	A
Mating Retention	With
Panel Mount Feature	Without

Housing Features

Body Orientation	Straight
Housing Color	Black
Housing Material	Nylon 6/6 (UV Resistant)

Circular Connector Shell Size

11

Product Type Features

Connector Seal & Plug Type	Wire Entry Seal
Connector Product Type	Housing
Connector System	Wire-to-Wire
Sealable	Yes
Connector & Contact Terminates To	Wire & Cable
Connector & Housing Type	Plug
Circular Connector Shell Type	All Plastic

Configuration Features

Reverse Numbering	Without
Number of Positions	4
Number of Power Positions	0
Number of Signal Positions	4

Electrical Characteristics

Operating Voltage	600 VAC
-------------------	---------

Contact Features

Reverse Gender	Yes
Contact Type	Pin
Contact Protection	With

Usage Conditions

Operating Temperature Range	-55 – 105 °C [-67 – 221 °F]
Fluid Resistance	Immersion

Operation/Application

Circuit Application	Signal
Shielded	No

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on [TE.com](https://te.com)>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts






TE Part # 2407269-4
CAP, CPC, SIZE 11 PLUG, YELLOW




TE Part # 1977879-1
SLD CPC RCPT ASSY,11-4,REV SEX,
UV RESIS


Also in the Series | AMP CPC

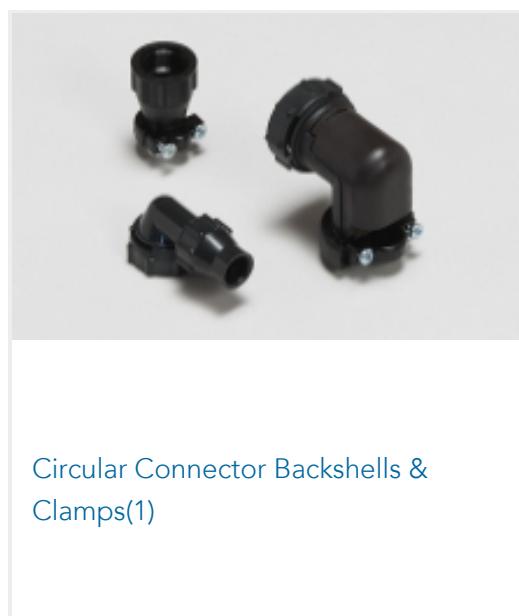


Circular Connector Backshells & Clamps(1)

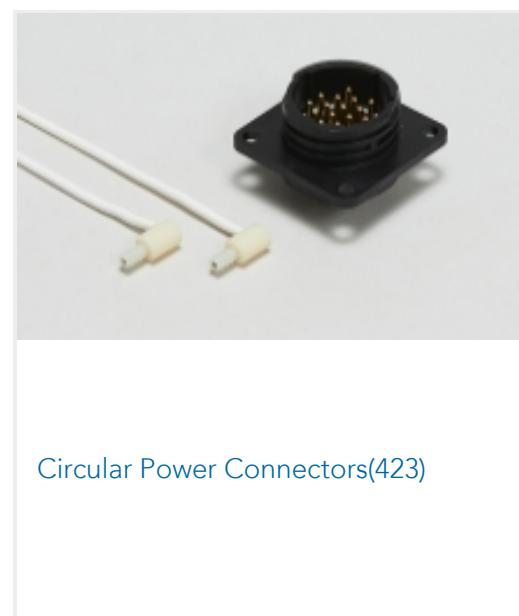


Circular Power Connectors(423)

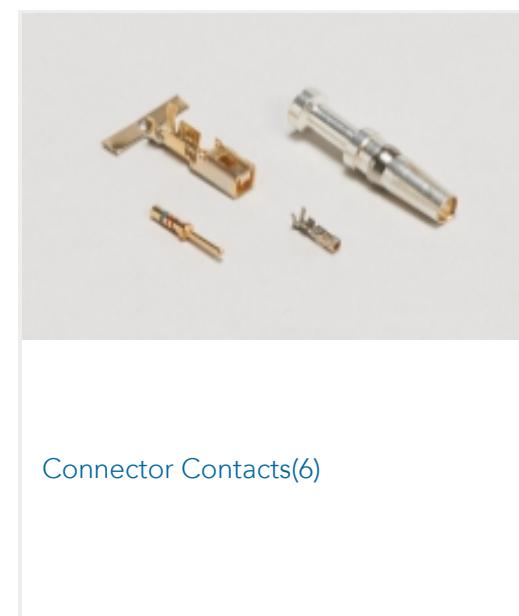


Connector Contacts(6)

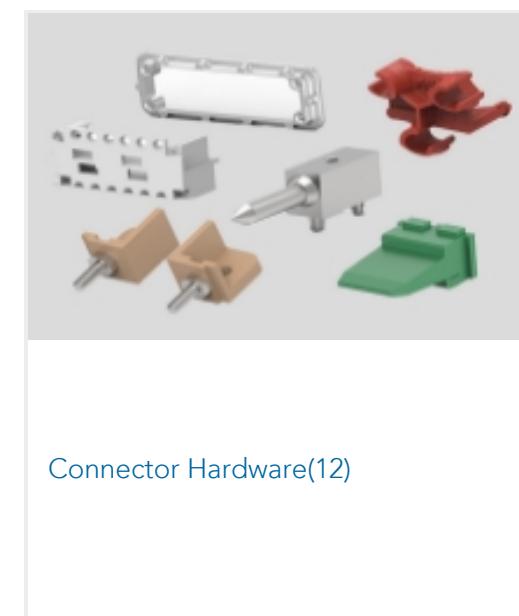

Connector Hardware(12)

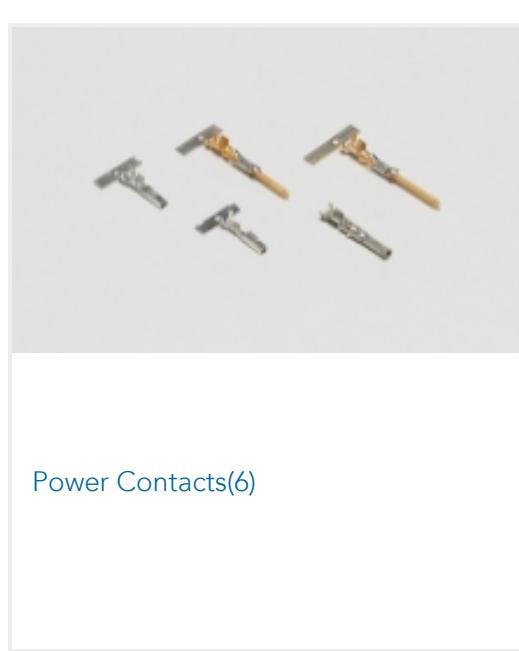

Power Contacts(6)

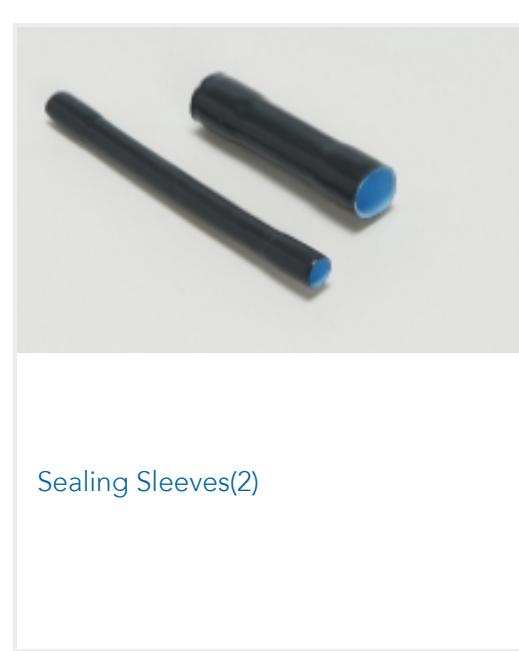

Sealing Sleeves(2)

Customers Also Bought



TE Part #206430-3
CPC RCPT ASSEMBLY SIZE 11-4



TE Part #206903-2
SEALING CAP ASSY,SZ 11,CPC



TE Part #60617-5
CMNL SOK AUBR L/P



TE Part #60618-5
CMNL PIN AUBR L/P



TE Part #81665-3
ECONOSEAL, FLANGE GASKET



TE Part #330620
INSUL BUSHING BNC BLKHD PHEN



TE Part #20017782-00
LS309-32 Liquid Level Sensor



TE Part #1SNK506020R0000
ZS6-BL



Documents

Product Drawings

[SLD CPC PLUG ASSY,11-4,REV SEX, UV RESIS](#)

English

CAD Files

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_1977881-1_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1977881-1_A.3d_jgs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1977881-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

[Product Specification](#)

English