


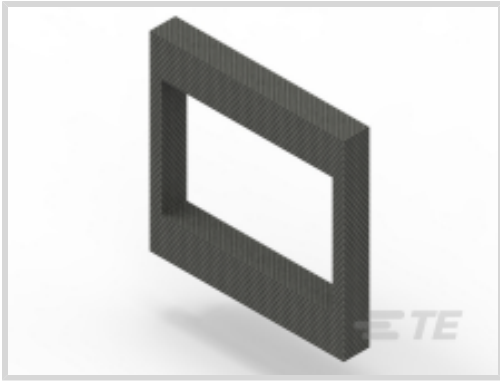

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Not Yet Reviewed
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-C11-H50111
QSFP-Four SFP+ I/O Cable Assembly
30 AWG




TE Part # 2110819-1
QSFP+ Enh EVERCLEAR PT Conn



TE Part # 2202165-5
QSFP TO QSFP, 26AWG, FDR, 5.0
METER



TE Part # 2202165-4
QSFP TO QSFP, 26AWG, FDR, 4.0
METER

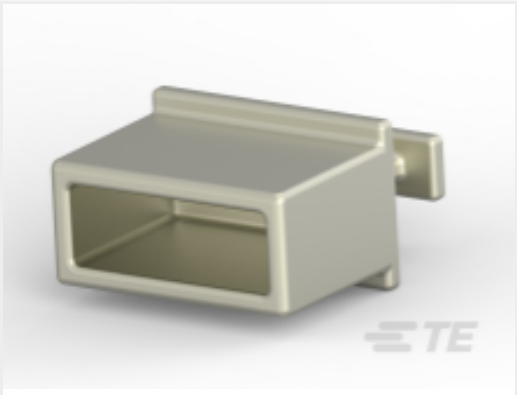

TE Part # 1888810-2
EMI/Dust Cover,XFP And QSFP



TE Part # 2053453-5
C/A, QSFP TO 4XSFP+, 4.0M




TE Part # CAT-C11-H5011142
QSFP to QSFP I/O Cable Assembly: 33
AWG



TE Part # 1-2053638-6
C/A, QSFP, 0.5M, P1-P2,
UNEQUALIZED


Also in the Series | **QSFP/QSFP+**

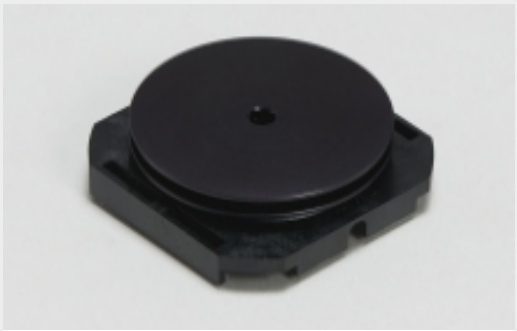

Heat Sinks(1)



Light Pipes(8)

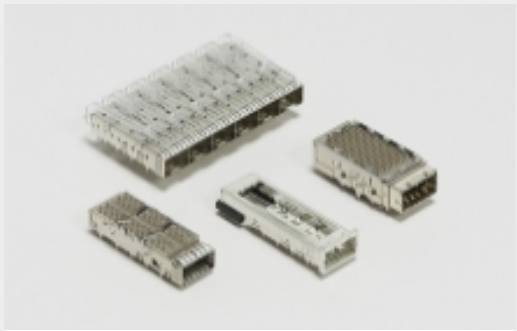

Pluggable IO Connectors & Cages(154)

Customers Also Bought



TE Part #1367147-1
SFP COVER, UNPLATED



TE Part #2110819-1
QSFP+ Enh EVERCLEAR PT Conn



TE Part #5-1618388-5
LEV200H5ANA=RELAY, SPST-NO



TE Part #7-1625999-4
HSC100 68K 5%



TE Part #1-1623929-6
CFR200 5% 1K5



TE Part #CAT-AL6-KSPR2975
Power Relay, 75A, Standard,
Monostable, DC



TE Part #K1060611
Relay 29-311-12A



TE Part #K1131955
RELAY 500A 24V S-FL LK 29-511-12A



Documents

Product Drawings

[EMI Gasket, QSFP/XFP 1x1](#)

English

CAD Files

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_2132186-2_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2132186-2_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2132186-2_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.