


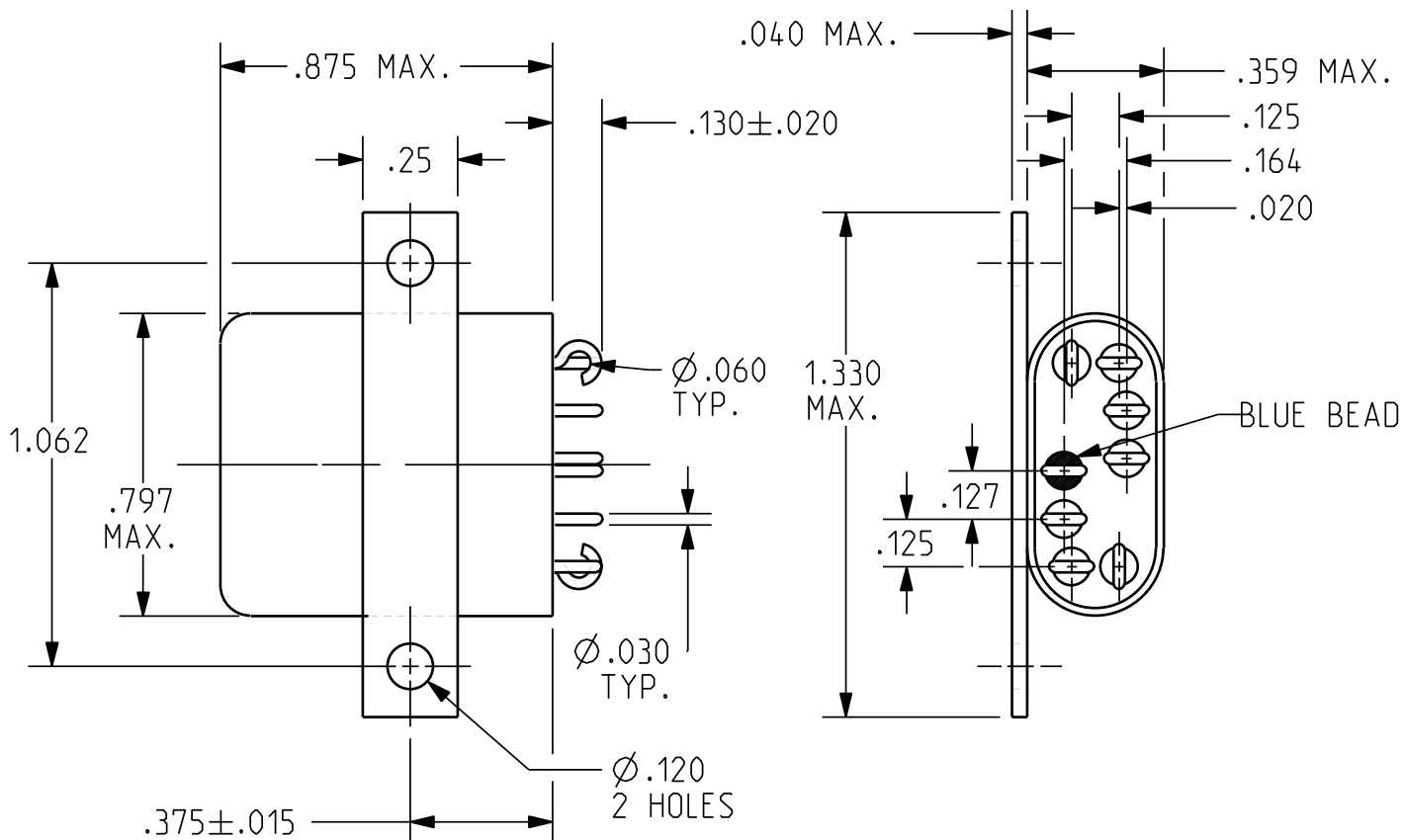

REV. A

DCO 144162

COIL: @ 25°C

RESISTANCE 552 OHMS $\pm$ 10%

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 13.5 VDC

MUST RELEASE 7.0 VDC MAX., 1.5 VDC MIN.

ENVIRONMENT:

VIBRATION 10 Hz TO 2000 Hz @ 20 g's

SHOCK 50 g's 11 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 6 MS MAX.

RELEASE 5 MS MAX., BOUNCE 2.5 MS

DIELECTRIC 1000 VAC (700 VAC - OPEN CONTACTS)

CUSTOMER DATA SHEET

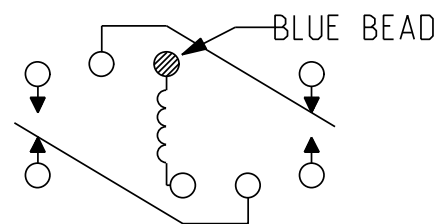

TERMINAL VIEW

CONTACT RATING: 2 AMPS 28 VDC
RESISTIVE 100,000 OPERATIONS

DR. B.D. 08MAR2006
PBB 3/16/01

CK. 3/8/06 J.M.B.

tyco
Electronics

©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CII STD.

CUST. NO. REV.

TYCO NUMBER
2-1617011-7

CII PART NUMBER

3SAE5041K1