

HC-STA-D07-BAWS-PL-BK - Housing



1419266
<https://www.phoenixcontact.com/us/products/1419266>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Panel mounting base D7, with single locking latch, material: PA, height: 27.9 mm, cable gland: none, Standard, angled

Commercial data

Item number	1419266
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF56
Product key	BF7APD
Catalog page	Page 516 (C-2-2019)
GTIN	4055626160177
Weight per piece (including packing)	18.2 g
Weight per piece (excluding packing)	18 g
Customs tariff number	85389099
Country of origin	CN

HC-STA-D07-BAWS-PL-BK - Housing



1419266

<https://www.phoenixcontact.com/us/products/1419266>

Technical data


Notes

General	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
---------	---

Product properties

Product type	Housing with locking latch
Housing type	Panel mounting base
Product family	HC-STA-D07
Application	Standard
Type	D7
Shielded	no
Pg screw connection	none

Dimensions

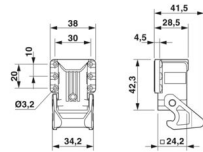Dimensional drawing	
Width	38 mm
Height	27.9 mm
Length	24.2 mm
Hole diameter	3.2 mm

Installation dimensions

Width of the assembly cutout	21 mm
Length of the assembly cutout	21 mm

Material specifications

Flammability rating according to UL 94	V0 (Housing)
	V0 (Interlock)
Seal material	NBR
Housing material	PA
Locking latch material	PA

Mechanical properties

Mechanical data

Locking type	Latch
--------------	-------

Connection data

Tightening torque	0.5 Nm ... 0.8 Nm (For M3 mounting screws on the panel-mount base)
-------------------	--

HC-STA-D07-BAWS-PL-BK - Housing

1419266

<https://www.phoenixcontact.com/us/products/1419266>




Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
Impact strength	IK06
Ambient temperature (operation)	-40 °C ... 125 °C

Drawings

Dimensional drawing

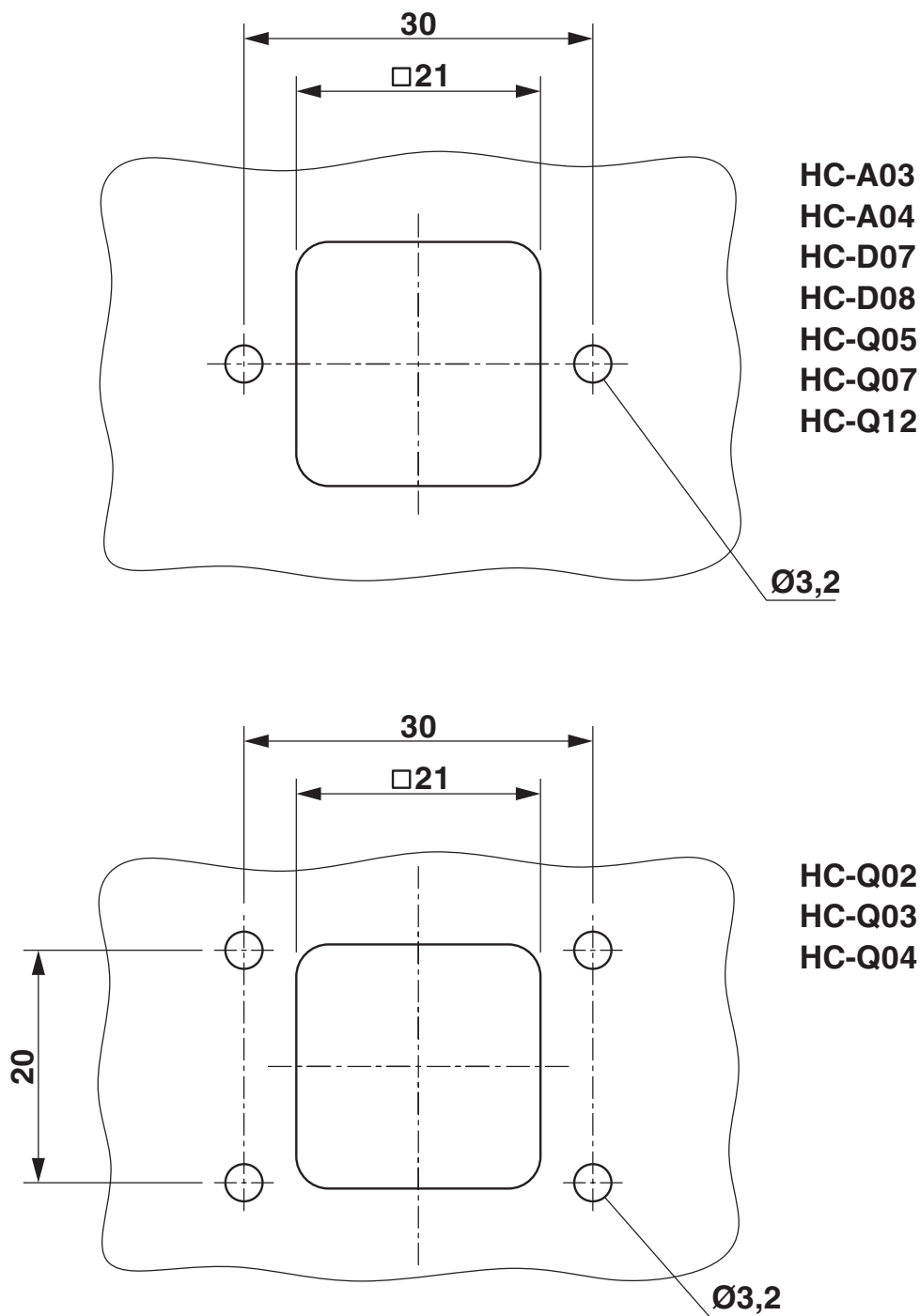

Mounting cutout


HC-STA-D07-BAWS-PL-BK - Housing

1419266

<https://www.phoenixcontact.com/us/products/1419266>



Dimensional drawing

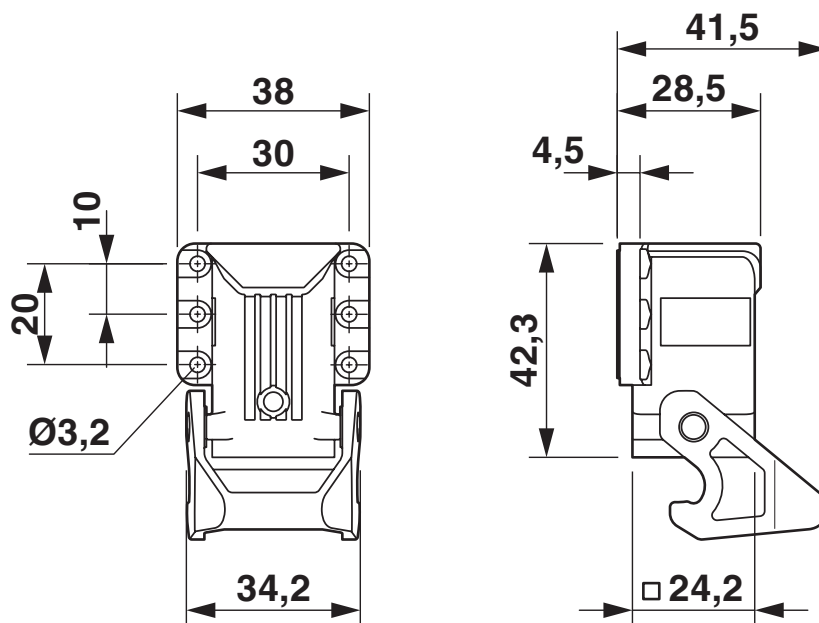

Dimensional drawing

HC-STA-D07-BAWS-PL-BK - Housing

1419266

<https://www.phoenixcontact.com/us/products/1419266>



Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1419266>

DNV

Approval ID: TAE000037S

HC-STA-D07-BAWS-PL-BK - Housing

1419266

<https://www.phoenixcontact.com/us/products/1419266>



Classifications

ECLASS

ECLASS-11.0	27440202
ECLASS-12.0	27440202
ECLASS-13.0	27440202

ETIM

ETIM 9.0	EC000437
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------