

HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Strain relief clamps contact inserts of series: B-, BB-, D 40, D 64, DD and HV, straight cable exit



Commercial data

Item number	1685327
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BF61
Product key	BF7ABZ
Catalog page	Page 662 (C-2-2019)
GTIN	4017918197001
Weight per piece (including packing)	14.86 g
Weight per piece (excluding packing)	13.57 g
Customs tariff number	73269098
Country of origin	CN

HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>



Technical data

Product properties

Product type	Mounting material
--------------	-------------------

Dimensions

Dimensional drawing	
Clamping range of the strain relief clip	9.00 mm ... 19.00 mm

Material specifications

Material	Steel, galvanized
----------	-------------------

Cable/line

External cable diameter	9 mm ... 19 mm
-------------------------	----------------

Mounting

Assembly note	Suitable for HC-DD... / HC-B... / HC-BB... / HC-BBB... / HC-D40... / HC-D64...
---------------	--


HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>



Drawings

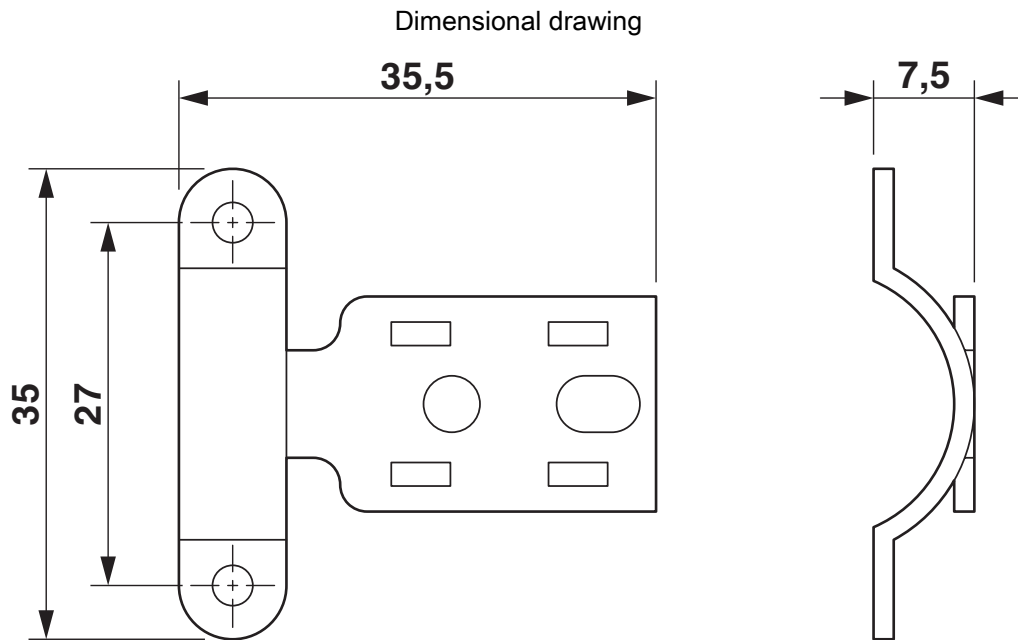

Dimensional drawing

HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>



Classifications

ECLASS

ECLASS-11.0	27440192
ECLASS-12.0	27440192
ECLASS-13.0	27440192

ETIM

ETIM 9.0	EC002943
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com