

HC-B24-HCWD-PLR-BK - Protective cover



1346552

<https://www.phoenixcontact.com/us/products/1346552>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Protective cover B24, with double locking latch, protective cover material: PC, height: 25.4 mm, seal: yes



Commercial data

Item number	1346552
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF66
Product key	BF7AZC
GTIN	4063151660796
Weight per piece (including packing)	60.7 g
Weight per piece (excluding packing)	58.9 g
Customs tariff number	85389099
Country of origin	CN

HC-B24-HCWD-PLR-BK - Protective cover



1346552

<https://www.phoenixcontact.com/us/products/1346552>

Technical data

Notes

General Protective cover for sleeve housings for double locking latch

Product properties

Product type	Protective cover
Housing type	Protective cover
Type	B24
Seal present	yes

Dimensions

Dimensional drawing	
Width	56 mm
Height	25.4 mm
Length	124.5 mm
Diameter	26 mm



The diagram illustrates the dimensional drawing of a component. It shows a side view of the component with various dimensions labeled: total width is 151.2 mm, with a 124.5 mm section and a 26.7 mm section; height is 25.4 mm; length is 124.5 mm; and diameter is 26 mm. A small detail view shows a hole with a diameter of 04.3 mm and a distance of 43.8 mm from the bottom edge.

Material specifications

Material Protective cover	PC
Flammability rating according to UL 94	V0
Seal material	NBR
Material, protective cover	PC

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
Ambient temperature (operation)	-40 °C ... 125 °C
Resistance to UV radiation	yes

Mounting

Assembly note	Double eyelet for mounting on a cable / below screw head
	Plastic protective cover for short-term protection

HC-B24-HCWD-PLR-BK - Protective cover




1346552

<https://www.phoenixcontact.com/us/products/1346552>

Drawings

Dimensional drawing

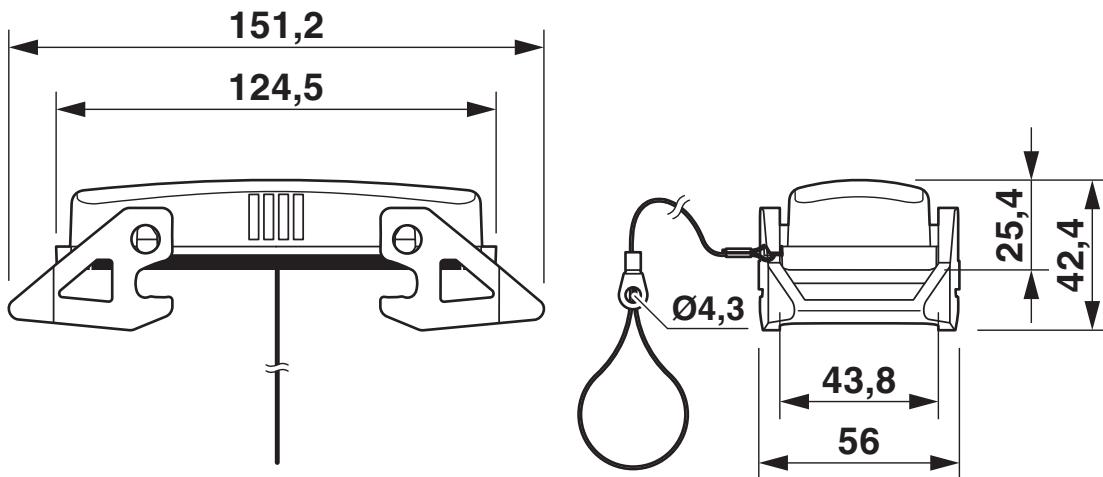

Dimensional drawing

HC-B24-HCWD-PLR-BK - Protective cover

1346552

<https://www.phoenixcontact.com/us/products/1346552>



Approvals

ⓘ To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1346552>

DNV

Approval ID: TAE000037S

Classifications

ECLASS

ECLASS-11.0	27440208
ECLASS-12.0	27440208
ECLASS-13.0	27440208

ETIM

ETIM 9.0	EC002314
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

HC-B24-HCWD-PLR-BK - Protective cover

1346552

<https://www.phoenixcontact.com/us/products/1346552>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com