



Connectors > D-Shaped Connectors > D-Sub Connectors > Crimp D-Sub Connectors > D-Sub Crimp: Plug, Signal, 26 Posn, Pin Size 22, Shell Size 2



Connector & Housing Type: **Plug**
Connector System: **Cable-to-Cable**
Number of Positions: **26**
Contact Size: **Size 22**
Connector Shell Size: **2**

[All D-Sub Crimp: Plug, Signal, 26 Posn, Pin Size 22, Shell Size 2 \(4\)](#)

Features

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Termination Features

Termination Method to Wire & Cable	Crimp
------------------------------------	-------

Body Features

Shell Plating Material	Tin
Insert Material	Glass-Filled Nylon

Packaging Features

Packaging Method	Package
Packaging Quantity	400

Housing Features

Shell Material	Steel
Centerline (Pitch)	2.28 mm[.09 in]



Operation/Application

Circuit Application	Signal
Shielded	Yes

Contact Features

Contact Options	Order Separately
Contact Size	Size 22

Product Type Features

Shell Material Configuration	Front Metal Shell
Connector & Contact Terminates To	Wire & Cable
Ground Feature Type	Grounding Indents
Connector & Housing Type	Plug
Connector System	Cable-to-Cable
Connector Shell Size	2
Sealable	No

Configuration Features

Number of Positions	26
---------------------	----

Mechanical Attachment

Mating Retention	With
Mating Retention Type	Clinch Nut, 4-40 UNC

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
-----------------------------	----------------------------

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241)



Candidate List Declared Against: JUNE 2024 (241)
Does not contain REACH SVHC

Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 5206471-1
CABLE CLAMP KIT, SZ 2



TE Part # CAT-038-DCRSS222
D-Sub Crimp Recpt Signal 26 Posn, Socket Size 22, Shell Size 2



TE Part # CAT-038-DCPPS222
D-Sub Crimp: Plug, Signal, 26 Posn, Pin Size 22, Shell Size 2

Customers Also Bought




TE Part #CAT-C8114-P2
CORCOM P SERIES MULTI-FUNCTION INLET FIL



TE Part #5227161-6
RTANG JK W/MTG PINS, BNC PCB



TE Part #1-1473562-4
RITS CONN. PLUG ASSY 4P RED

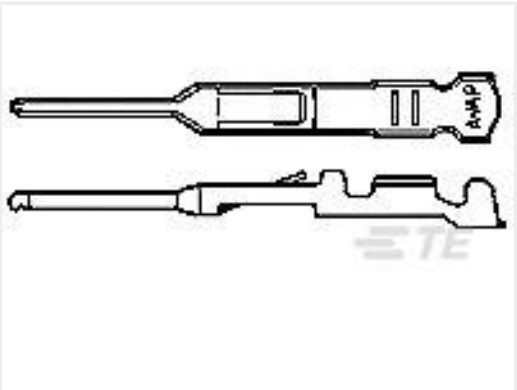

TE Part #170429-1
EIS REC CONT 26-20 AWG BR TN



TE Part #2316108-6
6P,2MM,REC,HSG,DR,CRIMP,PLAIN,BOX

TE Part #4-2316113-5
2MM,REC,CNT,CRIMP,24-28AWG,0.38UM,LP

TE Part #1-1827875-0
DYNAMIC 1200D HDR ASSY V
20PXBLACK GOLD

TE Part #1-171825-2
POST HDR ASSY VERT AMP EI CONN

TE Part #3-1734774-2
PCI EXP 2.3L 64 POS BLK 15u"

Documents

Product Drawings
PLUG ASSY,26P,HDP-22,CN
English

- CAD Files
- Customer View Model
ENG_CVM_CVM_5749717-1_O1.3d_igs.zip
English
- Customer View Model
ENG_CVM_CVM_5749717-1_O1.3d_stp.zip
English
- Customer View Model
ENG_CVM_CVM_5749717-1_O1.2d_dxf.zip
English
- 3D PDF
3D
3D PDF
English
- Customer View Model
ENG_CVM_5749717-1_O.2d_dxf.zip
English
- Customer View Model
ENG_CVM_5749717-1_O.3d_igs.zip
English
- Customer View Model
ENG_CVM_5749717-1_O.3d_stp.zip
English



By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMPLIMITE Subminiature D Connectors - Cable Connectors

English

AMPLIMITE Cable Connectors and Shielding Hardware Kits QRG

English

Product Specifications

Application Specification

English

Instruction Sheets

Instruction Sheet (U.S.)

English

Agency Approvals

CSA Certificate

English