



Passive Components > Resistors > Surface Mount Resistors > Thick Film Resistor: Current Sense



Resistor Type: **Current Sensing Resistor**

Element Type: **Thick Film**

Package Size Code: **2512**

Power Rating: **1 W**

Resistance Value: **.47 Ω**

[All Thick Film Resistor: Current Sense \(434\)](#)

Features

Product Type Features

Resistor Type	Current Sensing Resistor
Element Type	Thick Film
Package Size Code	2512

Configuration Features

Number of Resistors	1
---------------------	---

Electrical Characteristics

Power Rating	1 W
Resistance Value	.47 Ω
Resistance Class	Up to 1kΩ
Passive Component Tolerance	1 %

Termination Features

Surface Mount Resistor Termination Type	Solder
Number of Terminations	2

Dimensions

Product Height	.6 mm[.024 in]
Product Length	6.35 mm[.25 in]



Product Width	3.1 mm[.122 in]
---------------	-----------------

Usage Conditions

Temperature Coefficient	±100 ppm/°C
-------------------------	-------------

Packaging Features

Packaging Method	Taped & Reeled
------------------	----------------

Other

EU RoHS Compliance	Compliant with Exemptions
EU ELV Compliance	Compliant with Exemptions

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Reflow solder capable to 260°C

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

RL73H3AR47FTE

Surface Mount Current Sensing Resistor, Thick Film, 2512, 1 W, .47 ohm, 1 %, ±100 ppm/°C, Solder, 2 Terminations, Height .6 mm [.024 in], CGS RL73



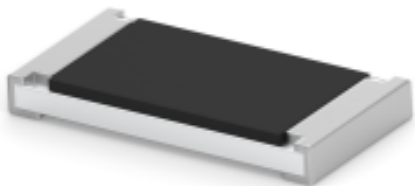

TE Part # CAT-C339-R529

Thick Film Resistor: Current Sense



TE Part # 6-1622824-1


RL73N 1J R10 5% 5K RL

Also in the Series | CGS RL73



Surface Mount Resistors(472)

Customers Also Bought

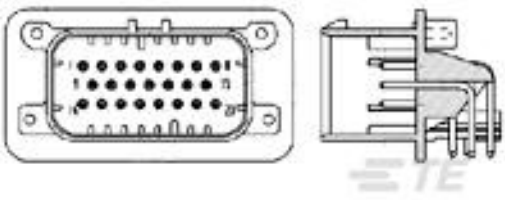

TE Part #770669-1

23POS,PIN DIA 1.3,HDR ASSY,90DEG, COD 1



TE Part #3-1393789-5

V23079A2001B301




TE Part #2176053-9

RLP73N 2A R11 1% 1K RL



TE Part #3-1415006-1

V23047-A1048-A501

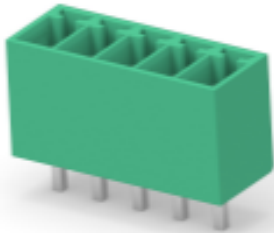

TE Part #2351886-5

5POS TB HDR 180 DEG, PITCH 3.5, TL 3.4mm



TE Part #1860995-1

RT16C01 PLASTIC RETAINING CLIP LOW




TE Part #1-2176177-6

CRGH0603 1% 2K7 0.2W



TE Part #1462043-4

IME06GR=IM RELAY 140mW 12V 2NO

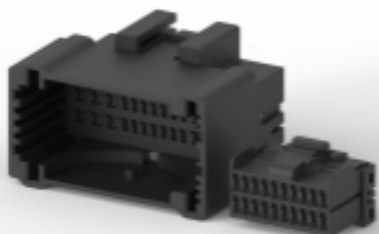

TE Part #CAT-M9194-CH8172

MULTILOCK, CONNECTOR HOUSING



Documents

Product Drawings

RL73H 3A R47 1% 4K RL

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-1622824-6_BA.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-1622824-6_BA.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1-1622824-6_BA.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

1309350_PASSIVE_COMPONENT

English

Standard Tantalum Capacitors - Type TYTS Series - Tyco Electronics Passives

English

8-1773459-4_POWER_FILTERING_AND_RESISTIVE_SOLUTIONS_FOR_ELEVATORS_AND_ESCALATORS

English

SMD Low Ohmic Current Sense Resistors - Type RL73 Series

English