



Connectors > Connector Accessories > Connector Caps & Covers



Connector Cover Type: **Sealing Cap**
Primary Product Color: **Black**
Primary Product Material: **Thermoplastic**
Operating Temperature (Max): **80 °C [176 °F]**
Operating Temperature Range: **-40 – 80 °C [-40 – 176 °F]**

Features

Housing Features

Compatible With Connector Shape	Circular
---------------------------------	----------

Industry Standards

UL Flammability Rating	UL 94V-1
------------------------	----------

Mechanical Attachment

Component Retention Feature	Plastic Strap
-----------------------------	---------------

Operation/Application

Compatible With Connector Shell Size	17
--------------------------------------	----

Packaging Features

Packaging Method	Box
Packaging Quantity	100

Body Features

Seal Material	Polychloroprene
Primary Product Color	Black
Primary Product Material	Thermoplastic



Product Type Features

Sealable	Yes
Connector Cover Type	Sealing Cap

Usage Conditions

Operating Temperature (Max)	80 °C[176 °F]
Operating Temperature Range	-40 – 80 °C[-40 – 176 °F]

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 206043-5
CPC RECPT ASSEMBLY SIZE 17-14



TE Part # 796272-1
SLD CPC RCPT ASSY,17-14,REV SX



TE Part # 206043-4
CPC RECPT ASSEMBLY SIZE 17-14



TE Part # 206044-1
CPC PLUG ASSEMBLY SIZE 17-14



TE Part # 206426-1
CPC PLUG ASSEMBLY SIZE 17-3



TE Part # 211768-1
CPC PLUG ASSEMBLY SIZE 17-9



TE Part # 796275-1
SLD CPC RCPT ASSY,17-16,STD SX



TE Part # 213889-2
CPC RECPT SEALED,SIZE 17-3



TE Part # 207445-2
SEALING CAP ASSY,SZ 17,CPC



TE Part # 206037-2
CPC PLUG ASSEMBLY SIZE 17-3



TE Part # 206036-4
CPC RECPT SEALED SIZE 17-16



TE Part # 206126-1
CPC PLUG ASSEMBLY SIZE 17-28



TE Part # 796276-1
SLD CPC RCPT ASSY,17-16,STD SX



TE Part # 796449-1
PLUG ASSY,CPC,17-14,REV SEX



TE Part # 796450-1
PLUG ASSY,CPC,17-9,REV SEX




TE Part # 213890-2
CPC RECPT SEALED SIZE 17-3



TE Part # 211766-1
CPC PLUG ASSEMBLY SIZE 17-9



TE Part # 206039-1
CPC PLUG ASSEMBLY SIZE 17-28

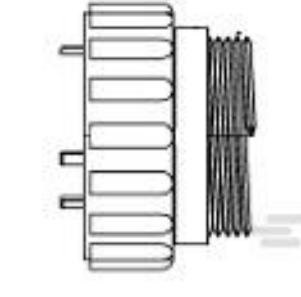

TE Part # 206554-1
CPC PLUG ASSEMBLY SIZE 17-16



TE Part # 796275-2
SLD CPC RCPT ASSY,17-16,STD SX

Also in the Series | [AMP CPC](#)



Connector Backshells(1)



Connector Caps & Covers(16)



Connector Contacts(6)



Connector Seals & Cavity Plugs(35)



Connector Strain Relief(60)



Insertion & Extraction Tools(1)




Power Contacts(6)


Customers Also Bought




TE Part #206486-1
CPC RECPT ASSEMBLY SIZE 11-9

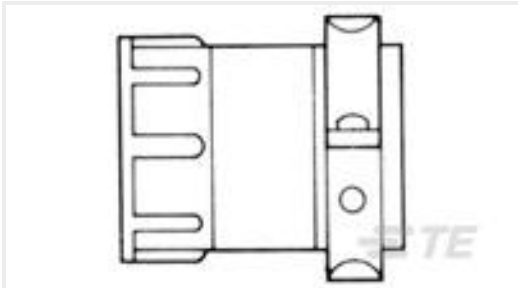

TE Part #206358-5
CABLE CLAMP ASY, SIZE 11

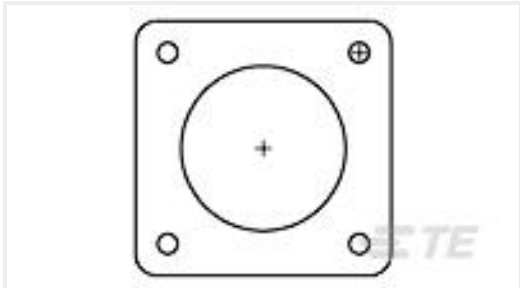


TE Part #81665-2
FLANGE GASKET CPC

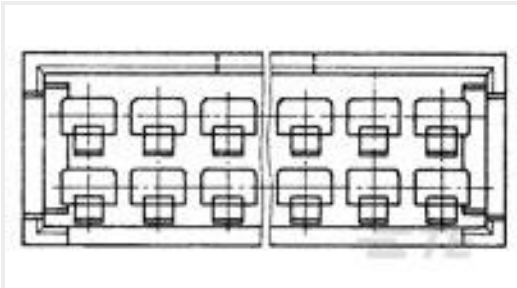


TE Part #280640
MOD II HSG



TE Part #ZPF000000000007366
983-OS 14-04 PN

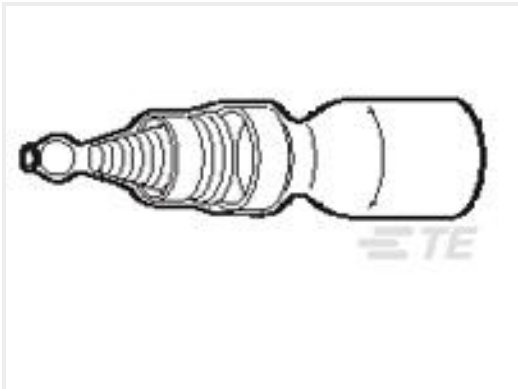

TE Part #705489-000
SGRS-1

 


TE Part #1393557-7
C42334A 386C 61=BKLEV 413 BUEG



TE Part #2267473-1
SIZE 11 PERIPHERAL SEAL, CPC



 TE Part #86513-000
FRS801-51 RHT/ANG LEVEL SENSOR



TE Part #ZPF000000000005356
910-6C 10-06 PN 01

Documents



Product Drawings

SEALING CAP ASSY, 17,CPC ROHS Compliant

English

CAD Files

Customer View Model

ENG_CVM_CVM_207445-3_N.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_207445-3_N.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_207445-3_N.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English

Instruction Sheets

Instruction Sheet (U.S.)

English

Agency Approvals

CSA Certificate

English

CSA Certificate

English