



Connectors > Power Connectors > Circular Power > Circular Power Connectors



Number of Positions: 9

Connector Product Type: **Housing**

Operating Voltage: **600 VDC**

Connector System: **Wire-to-Wire**

Sealable: **Yes**

Features

Dimensions

Compatible Insulation Diameter Range	1.65 – 2.54 mm[.065 – .1 in]
--------------------------------------	------------------------------

Packaging Features

Packaging Quantity	100
Packaging Method	Bag

Mechanical Attachment

Mating Retention Type	Threaded Coupling
Thread Size	3/4 - 20 UNEF-2A
Polarization Code	A
Mating Alignment Type	Keyed
Mating Alignment	With
Mating Retention	With
Panel Mount Feature	Without

Housing Features

Body Orientation	Straight
------------------	----------



Housing Color	Black
Housing Material	Nylon (UV Resistant)
Circular Connector Shell Size	13

Product Type Features

Connector Seal & Plug Type	Wire Entry Seal
Connector Product Type	Housing
Connector System	Wire-to-Wire
Sealable	Yes
Connector & Contact Terminates To	Wire & Cable
Connector & Housing Type	Plug
Circular Connector Shell Type	All Plastic

Configuration Features

Reverse Numbering	Without
Number of Positions	9
Number of Power Positions	0
Number of Signal Positions	9

Electrical Characteristics

Operating Voltage	600 VAC
-------------------	---------

Contact Features

Reverse Gender	No
Contact Type	Socket
Contact Protection	With

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
Fluid Resistance	Immersion

Operation/Application

Circuit Application	Signal
Shielded	No

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Other

--	--



EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 91538-1
CCII TYPE II PIN SKT 30-20 ASSY

TE Part # 164159-4
M-SRS PIN ASSY 3+

TE Part # 202726-1
CONTACT SOCKET ASSY.


TE Part # 91515-1
CCII TYPE III+ MNL PIN SKT 30-20 ASSY



TE Part # 1546348-2
R/A CABLE CLAMP KIT,SZ 13,CPC



TE Part # 66564-8
III+ PIN,24-20,30AU/FL,STRIP

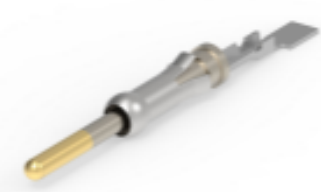

TE Part # 788085-1
TYPE III+ PIN ASSEMBLY,.062



TE Part # 66360-3
III+ SKT,18-14,15AU/FL,LP



TE Part # 3-66104-0
III+ SKT,24-20,TIN ,STRIP



TE Part # 66597-2
III+ PIN,18-14,30AU/FL,STRIP



TE Part # 66109-3
III+ SKT,26-24,15AU/FL,LP



TE Part # 1-66105-9
III+ SKT,24-20,TIN,LP



TE Part # 201334-1
CONTACT PIN ASSY.



TE Part # 66598-2
III+ SKT,18-14,30AU/FL,STRIP



TE Part # 164164-2
PIN ASS



TE Part # 193846-1
SKT ASSY.



TE Part # 796964-1
PIN ASSY,18-16 AWG,HI CURRENT



TE Part # 1-2407269-2
CAP, CPC, SIZE 11 RECP & 13 PLUG, BLACK



TE Part # 66425-7
III+ PIN,30-26,15AU/FL,STRIP



TE Part # 66393-7
III+ PIN,30-26,15AU/FL,STRIP

Also in the Series | AMP CPC




Circular Connector Backshells & Clamps(1)



Circular Power Connectors(423)




Connector Contacts(6)

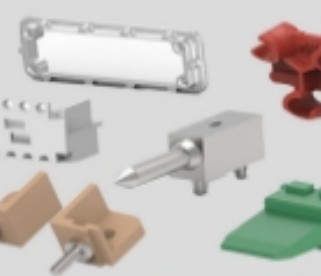

Connector Hardware(12)



Power Contacts(6)

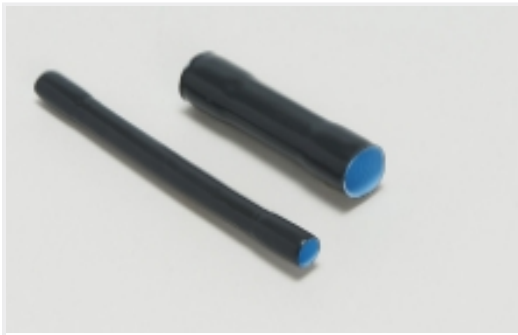

Sealing Sleeves(2)


Customers Also Bought



TE Part #205209-2
RECP ASSY SIZE 4



TE Part #5-166052-1
HDF20 SOCKET F CRIMP SIZE28-24

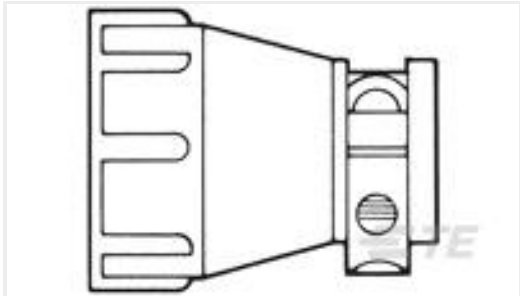

TE Part #206966-9
CABLE CLAMP KIT, BULK PKG



TE Part #38941-22L
CONTACTS



TE Part #696049-1
PG 8 RING #8




TE Part #CAT-P592-R472A
PIDG Ring Tongue Terminals



TE Part #669507-000
S02-10-R



TE Part #650075-000
D-436-37

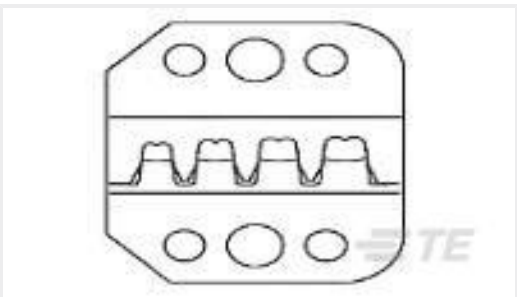

TE Part #58641-2
PROCRIMP DIE MOD IV

Documents

Product Drawings

SLD CPC PLUG ASSY,13-9,STD SEX, UV RESIS

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1977884-1_A.2d_dxf.zip

1977884-1

9 Position Circular Power Connector, Housing, 600 VDC, Wire-to-Wire, Sealable, Wire & Cable, Plug, Socket, Signal, Black, All Plastic, AMP CPC



English

Customer View Model

[ENG_CVM_CVM_1977884-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1977884-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Connector, Circular Plastic

English

Product Specification

English