




Connectors > Connector Accessories > Connector Caps & Covers > Female Socket Connectors: Strain Relief

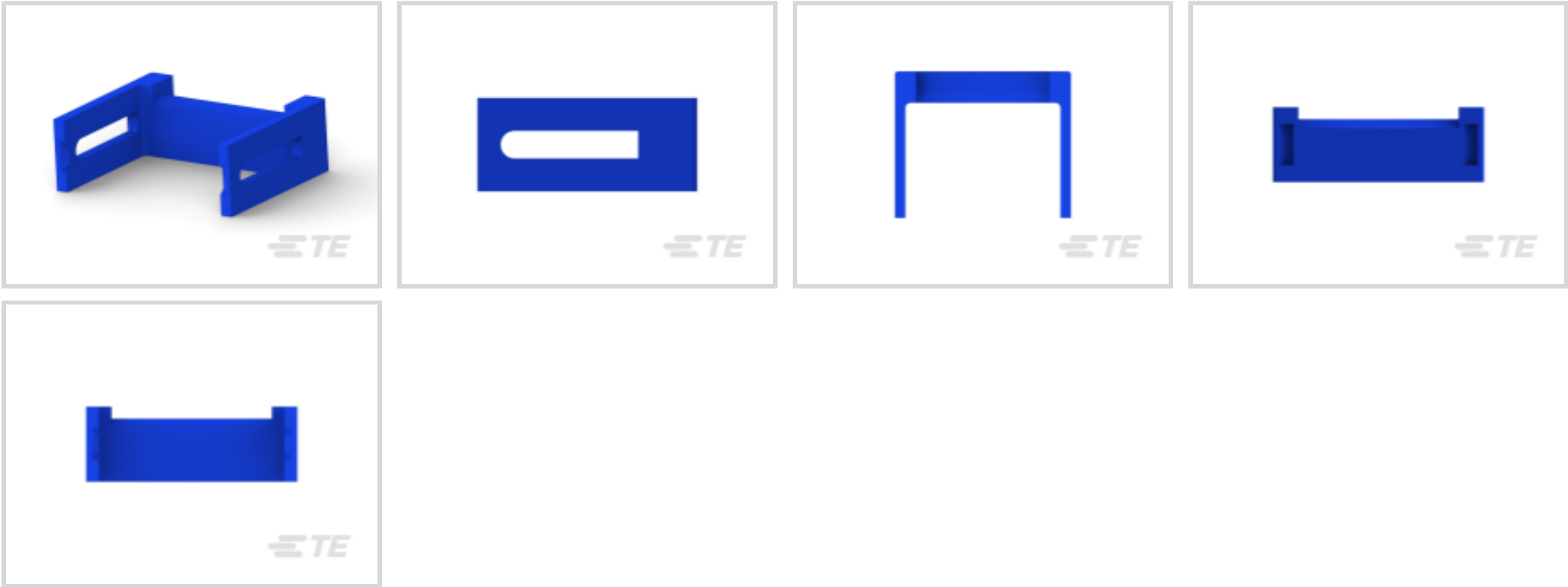

Connector Cover Type: **Strain Relief Cover**

Primary Product Color: **Blue**

Primary Product Material: **Glass-Filled Thermoplastic**

Number of Positions: **10**

EU RoHS Compliance: **Compliant**

[All Female Socket Connectors: Strain Relief \(13\)](#)

Features

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Dimensions

Product Length	17.37 mm
----------------	----------

Packaging Features

Packaging Method	Package
Packaging Quantity	50

Product Type Features

Connector Cover Type	Strain Relief Cover
----------------------	---------------------

Body Features

Primary Product Color	Blue
Primary Product Material	Glass-Filled Thermoplastic

Configuration Features

Number of Positions	10
---------------------	----



Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance


For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

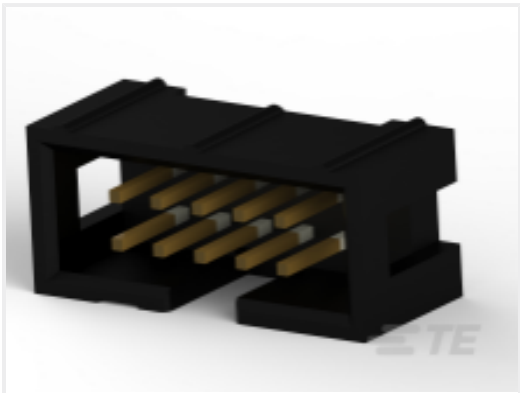


TE Part # 1761681-3
IDC LOW PRO HDR 10P VERT HT BLACK




TE Part # 1658526-4
609-1030LF FEM SOCKET,LEAD FREE

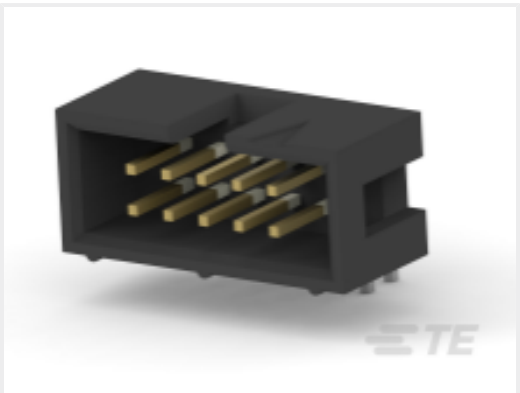


TE Part # 1761682-3
IDC LOW PRO HDR 10P RA HT BLACK

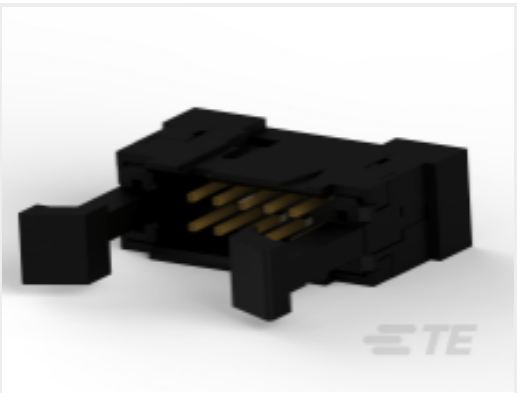

TE Part # 1-111504-4
10 UNIV I/O, NO EARS,LEAD FREE

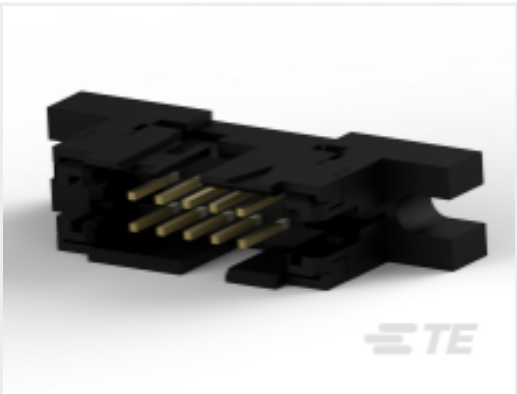


TE Part # 5111448-1
010 UNIV I/O 30DP SLOT

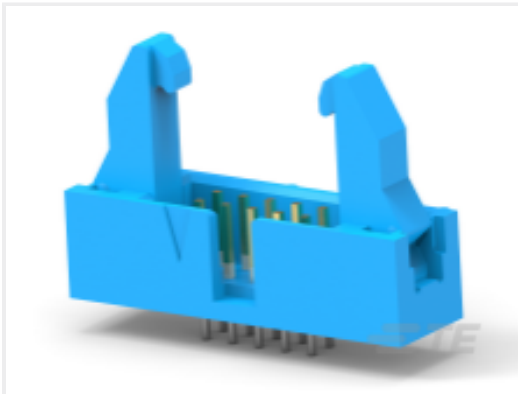

TE Part # 1761686-3
IDC LOW PRO HDR 10P VERT LG LAT




TE Part # 1-111446-4
10 UNIV I/O, NO EARS, LEAD FREE

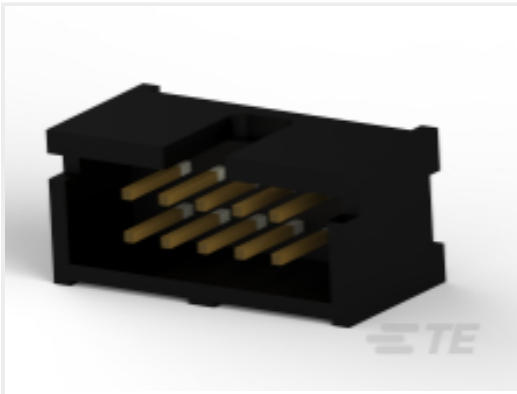


TE Part # 5103309-1
A/L LOW PRO HDR 10P VERT BLACK



TE Part # 1761606-3
IDC LOW PRO HDR 10P VERT LG LAT BLK

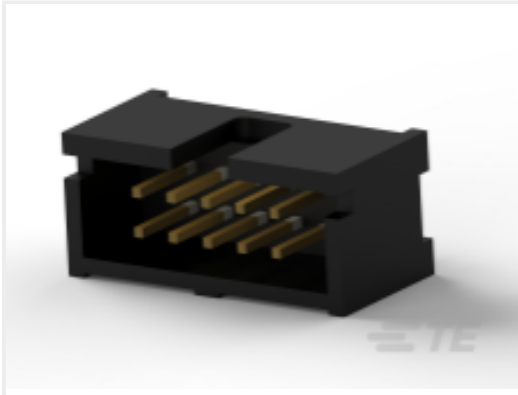


TE Part # 5103310-1
A/L LOW PRO HDR 10P RA BLACK

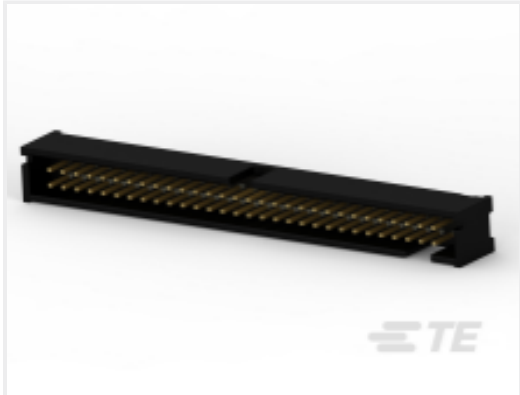


TE Part # 5103308-1
A/L LOW PRO HDR 10P VERT BLACK




TE Part # 1-111506-6
010 UNIV I/O 30DP SLOT LTCH

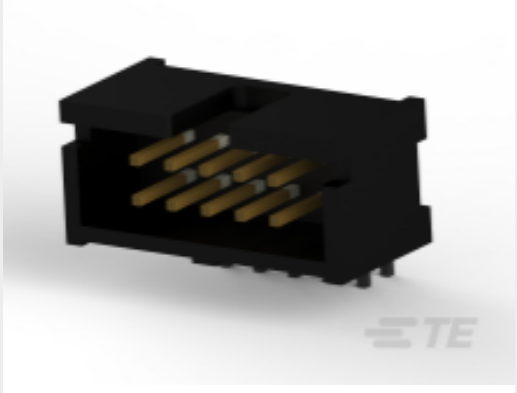


TE Part # 5103311-1
A/L LOW PRO HDR 10P RA BLACK

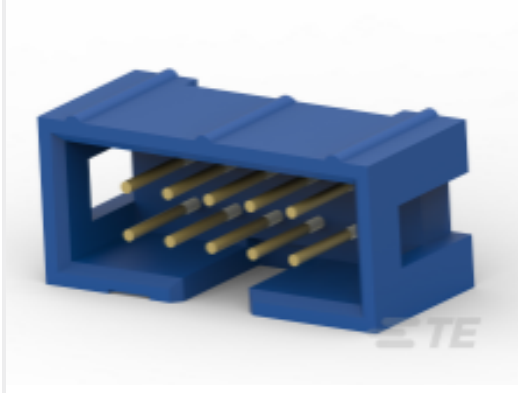


TE Part # 2-1761603-3
IDC LOW PRO HDR 10P VERT BLUE

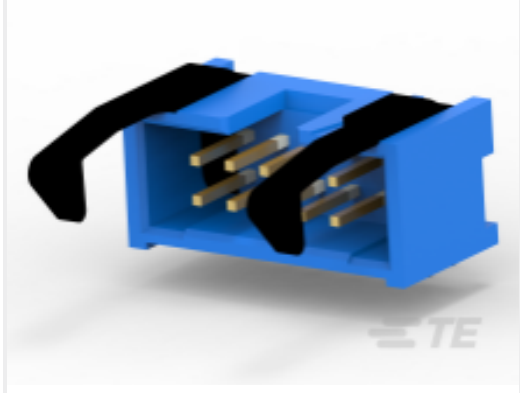

TE Part # 2-1761607-3
IDC LOW PRO HDR 10P RA LG LAT

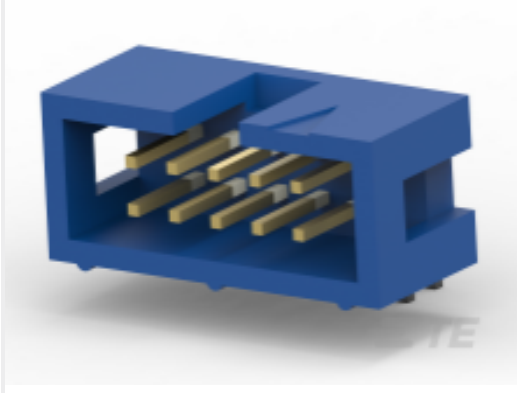


TE Part # 2-1761605-3
IDC LOW PRO HDR 10P RA BLUE

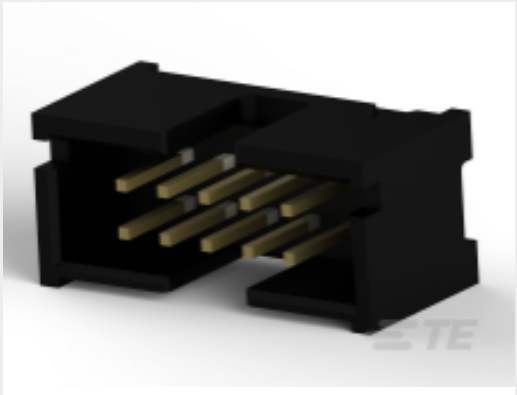

TE Part # 5104338-1
A/L LOW PRO HDR 10P VERT HT



TE Part # 5104340-1
A/L LOW PRO HDR 10P RA HT

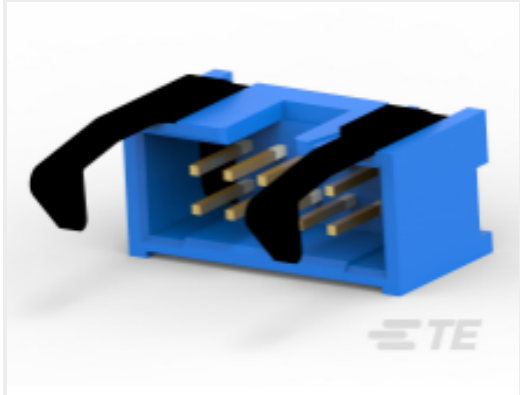


TE Part # 2-1761606-3
IDC LOW PRO HDR 10P VERT LG LAT BLUE



TE Part # 1761683-3
IDC LOW PRO HDR 10P VERT HT BLACK

Customers Also Bought

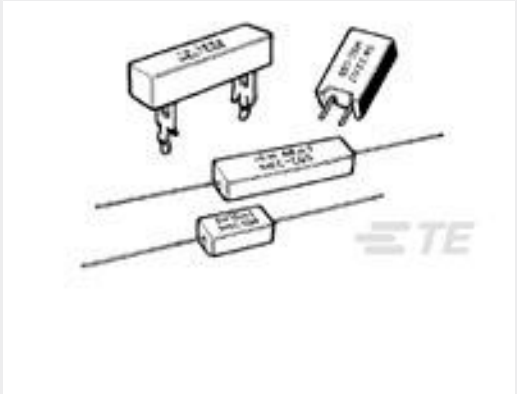

TE Part #1623790-3
SQM10S 47R 5% LP (WIRE)



TE Part #91556-1
CCII AMP EI SERIES 26-20 ASSY



TE Part #1-1437719-2
T01-0540-P05-MALE PLUG CONNECTOR-CRIMP



TE Part #52264-1
TERMINAL R PG 6 3/8




TE Part #2-338309-2
9P.HDP20 PLUG ASSY



TE Part #1367369-1
BUSBAR CONNECT W/CLINCH NUTS



TE Part #5414168-3
JACK,BULKHEAD,COM'L TNC

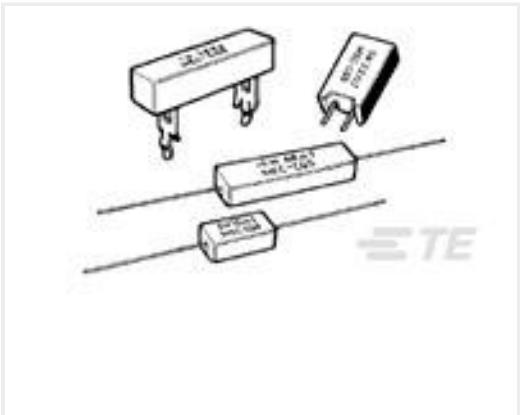

TE Part #1623804-8
SQZ10 3R3 5% WIRE



TE Part #1-794040-0
12P MINI UMNL HDR ASSY SN LF



TE Part #594752-E
STVH15 15 F ZD VV 2 EE25 4,2 * 197 E 172

Documents

Product Drawings

609-1031HD=FSKT IDC S 10 SR

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_3-1437020-7_C.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_3-1437020-7_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_3-1437020-7_C.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

Ribbon Cable Interconnect Solutions

English

Product Specifications

Product Specification

English

Female Socket Connector

English

