



Connectors > D-Shaped Connectors > D-Sub Connectors > Crimp D-Sub Connectors > D-Sub Crimp: Plug, Signal, 37 Posn, Pin Size 20, Shell Size 4



Connector & Housing Type: **Plug**  
Connector System: **Cable-to-Cable**  
Number of Positions: **37**  
Contact Size: **Size 20**  
Connector Shell Size: **4**

[All D-Sub Crimp: Plug, Signal, 37 Posn, Pin Size 20, Shell Size 4 \(6\)](#)

Features

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Termination Features

Termination Method to Wire & Cable	Crimp
------------------------------------	-------

Packaging Features

Packaging Method	Box
Packaging Quantity	250

Body Features

Shell Plating Material	Tin
Shield Plating Material	Tin
Insert Material	Thermoplastic
Shield Material	Steel

Housing Features

Shell Material	Steel
----------------	-------



Centerline (Pitch)	2.74 mm[.108 in]
Operation/Application	
Circuit Application	Signal
Shielded	Yes
Contact Features	
Contact Options	Order Separately
Contact Size	Size 20
Product Type Features	
Shell Material Configuration	Full Metal Shell
Connector & Contact Terminates To	Wire & Cable
Ground Feature Type	Grounding Indents
Connector & Housing Type	Plug
Connector System	Cable-to-Cable
Connector Shell Size	4
Sealable	No
Configuration Features	
Number of Positions	37
Mechanical Attachment	
Mating Retention	With
Mating Retention Type	Mounting Holes
Usage Conditions	
Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
Other	
EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant
Product Compliance	
For compliance documentation, visit the product page on TE.com>	
EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold



EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 66570-3  
20DF PIN CONT. LP

TE Part # CAT-035-DCPPS204  
D-Sub Crimp: Plug, Signal, 37 Posn,  
Pin Size 20, Shell Size 4

TE Part # CAT-035-DCRSS204  
D-Sub Crimp Recpt Signal 37 Posn,  
Socket Size 20, Shell Size 4

Customers Also Bought


TE Part #205209-2  
RECP ASSY SIZE 4

TE Part #207464-2  
CRIMP SNAP PLUG ASSY,SZ 3


TE Part #207463-1  
CRIMP SNAP RCPT ASSY,SZ 3

TE Part #205204-4  
CRIMP SNAP PLUG ASSY,SIZE 1






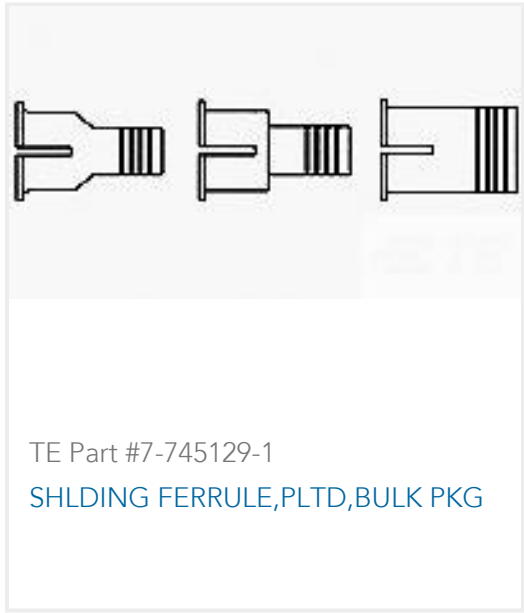
TE Part #205206-3  
CRIMP SNAP PLUG ASSY,SIZE 2




TE Part #5748677-4  
PLTD PLST CBL CLMP KIT,SZ 4



 
TE Part #2176162-9  
UPF25 0.1% 5PPM 50R



TE Part #7-745129-1  
SHLDING FERRULE,PLTD,BULK PKG



TE Part #2000314-1  
Assy, Recept, Dsub Quadrax, RtAng, 4 Pos



TE Part #AAC7456-00  
DSF104-T-BT-11E-1-B-SB-H

Documents

Product Drawings

PLUG ASSY SIZE 4

English

CAD Files

Customer View Model

ENG\_CVM\_CVM\_205210-3\_S.2d\_dxf.zip

English

3D PDF

3D

Customer View Model

ENG\_CVM\_CVM\_205210-3\_S.3d\_igs.zip

English

Customer View Model

ENG\_CVM\_CVM\_205210-3\_S.3d\_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMPLIMITE Subminiature D Connectors - Cable Connectors

English

AMPLIMITE Cable Connectors and Shielding Hardware Kits QRG

English

Product Specifications

Application Specification

English



Instruction Sheets

Instruction Sheet (U.S.)

English

Agency Approvals

CSA Certificate

English