



TE Internal #: HD34-18-8SN-059

TE Internal Description: REC,8P,AL,N, CBL CLMP BT, DRAIN, 12,S, MC

DEUTSCH HD30 Housings

[View on TE.com >](#)

All DEUTSCH HD30 Housings (358)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) SVHC > Threshold: Octamethylcyclotetrasiloxane (D4) (.4% in Component Part) Article Safe Usage Statements: Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 16-04978
GASKET, 18SZ, BLK, HD30



TE Part # 1062-12-0144
SOC, SF, SIZE 12, 12-14, AU/SN



TE Part # 1062-12-0222
SOC, SF, SIZE 12, 10, NI/NI



TE Part # 1062-12-0244
SOC, SF, SIZE 12, 10, AU/SN



TE Part # CAT-H3930-M8649
Mounting Hardware for DEUTSCH
HD30 Connectors



TE Part # CAT-H3930-RC8382
Receptacle Protective Caps -
DEUTSCH HD30



TE Part # 114010-ZZ
EXT TOOL, SIZE 12, 12 AWG, N, YEL



TE Part # CAT-D48-ST273
DEUTSCH Solid Contacts



TE Part # 1062-12-0166
SOC, SF, SIZE 12, 12-14, NI/SN



TE Part # CAT-H3930-CH8172
DEUTSCH HD30 Housings



TE Part # CAT-D48-SP729
DEUTSCH Sealing Plugs

Customers Also Bought




TE Part #CAT-H3930-CH8172
DEUTSCH HD30 Housings



TE Part #208472-1
CMC PLUG ASSEMBLY,SZ 28



TE Part #66601-1
III+ SKT,18-14,TIN-LEAD,LP

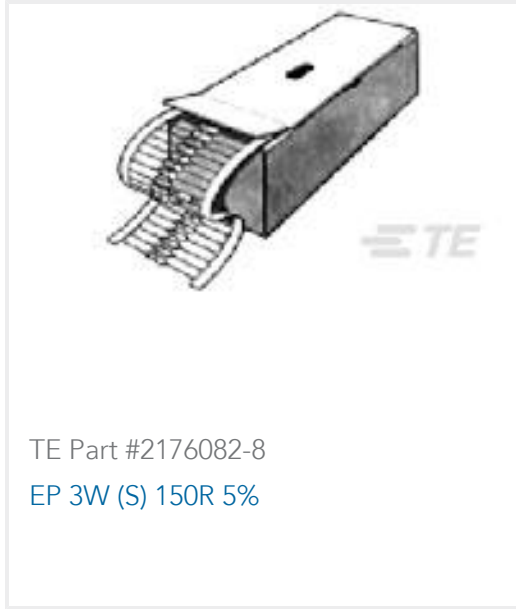

TE Part #2176082-8
EP 3W (S) 150R 5%



TE Part #HD30-18BT-90-BK
BOOT, 18SZ, RA, BLK



TE Part #1-1478966-0
SMA B/HD SKT RCPT GSS

Documents



Datasheets & Catalog Pages

CONNECTOR SELECTOR

English

Product Specifications

Application Specification

English