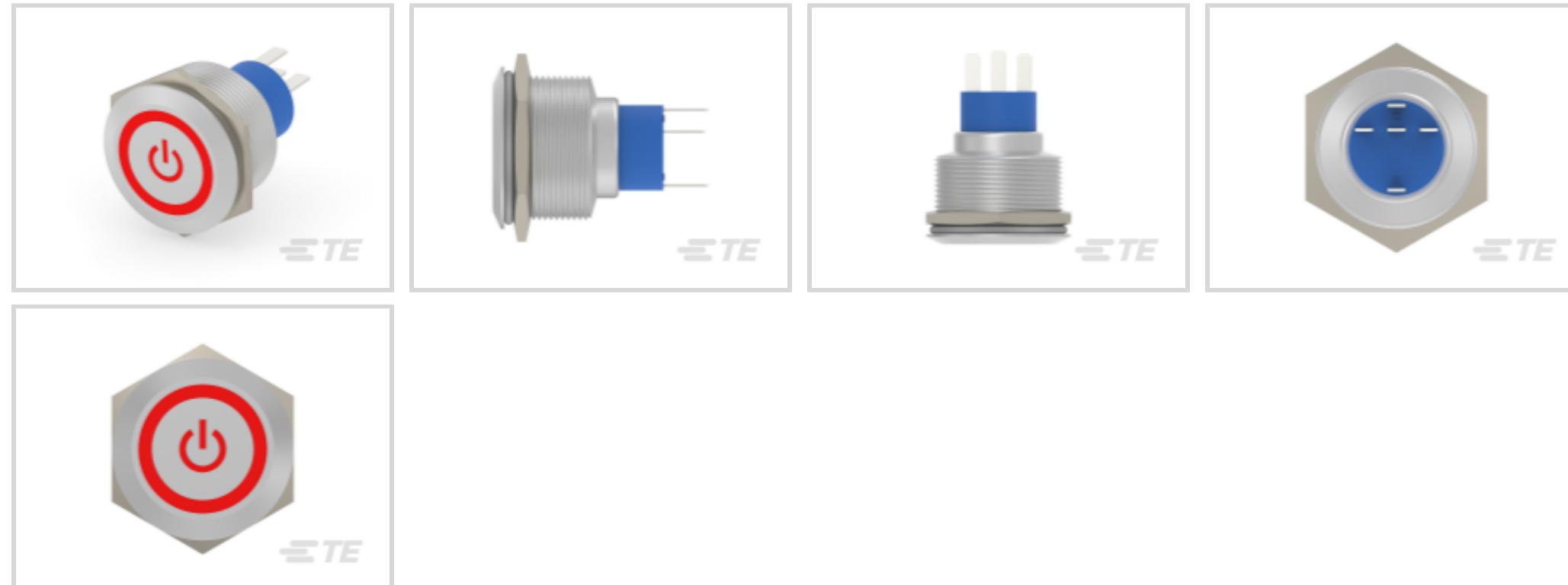


## Switches &gt; Push Button Switches

Push Button Switch Product Type: **Anti-Vandal Switch**Configuration (Pole-Throw): **Single Pole - Single Throw**Number of Actuators: **Single**Actuator Profile: **Flush**Bushing Style: **Threaded**

## Features

### Industry Standards

IP Rating	IP67
-----------	------

### Contact Features

Contact Base Material	Copper
-----------------------	--------

Switch Contact Plating Material	Silver
---------------------------------	--------

### Body Features

Case Material	PBT
---------------	-----

Product Orientation	Vertical
---------------------	----------

Actuator Force	255 g[9 oz]
----------------	-------------

Actuator Profile	Flush
------------------	-------

Bushing Style	Threaded
---------------	----------

### Product Type Features

Switch Connection Type	Wire Lugs
------------------------	-----------

Push Button Switch Product Type	Anti-Vandal Switch
---------------------------------	--------------------

Illuminated	With
-------------	------

Actuator Style

Round Actuator

**Configuration Features**

Configuration (Pole-Throw)	Single Pole - Single Throw
Number of Actuators	Single
Snap Action	Without
Support Bracket	Without
Switch Feedback Type	Auditory
Operating Function	On Off

**Electrical Characteristics**

Contact Current Rating	3 A
Operating Voltage Range	250 VAC

**Housing Features**

Process Sealed	Yes
----------------	-----

**Other**

EU RoHS Compliance	Compliant with Exemptions
EU ELV Compliance	Compliant with Exemptions

**Product Compliance**For compliance documentation, visit the product page on [TE.com](http://TE.com)>

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) SVHC > Threshold: Pb (3.7% in Component Part) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.

Halogen Content

Low Halogen - Br, Cl, F, I &lt; 900 ppm per homogenous material. Also BFR/CFR/PVC Free

Solder Process Capability

Not reviewed for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

## Compatible Parts




TE Part # 2328820-1  
AV 25 SPM 3A MOVING RING R&G  
12V

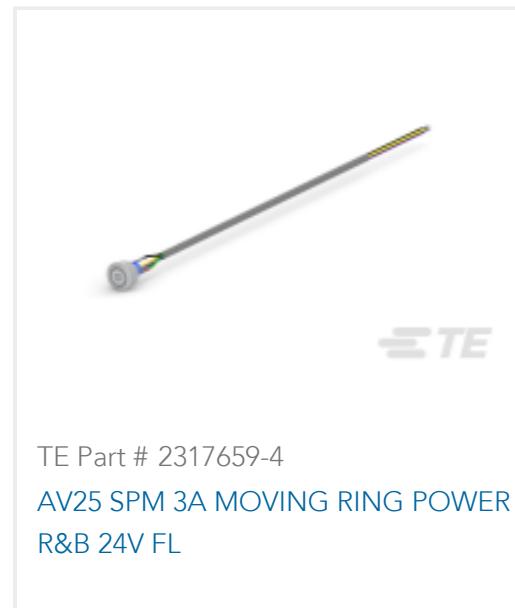

TE Part # 2317659-4  
AV25 SPM 3A MOVING RING POWER  
R&B 24V FL



 TE Part # 2317655-2  
AV25 SPL 3A NO LED FL




TE Part # 2328818-1  
AV25 SPM 3A MOVING RING WHITE  
12V




TE Part # 2317656-9  
AV25 SPM 3A MOVING RING BLUE  
12V

## Also in the Series | Alcoswitch AV25

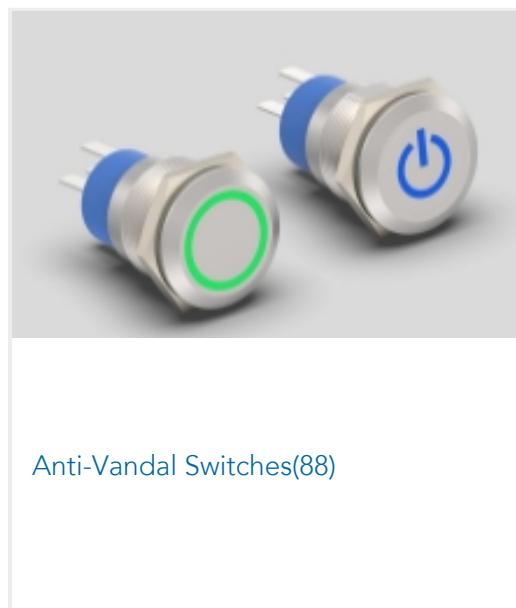

Anti-Vandal Switches(88)

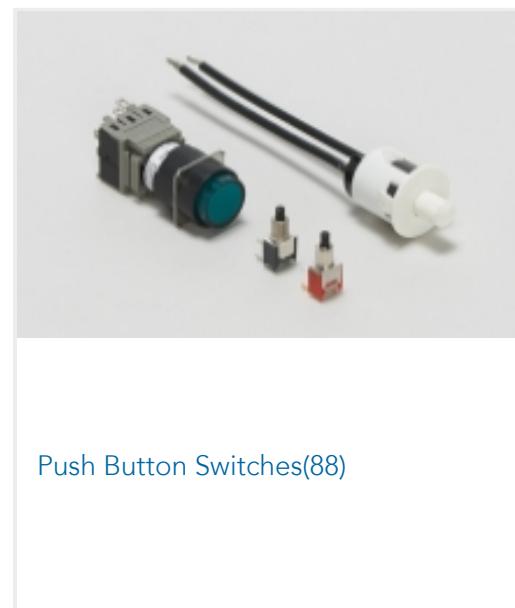

Push Button Switches(88)

## Customers Also Bought



TE Part #7-2213772-1  
AV22 DPL 3A MOVE RING LED  
YELLOW 24V

## Documents

### Product Drawings

#### AV25 SPL 3A MOVING RING POWER RED 24V

English

---

### CAD Files

#### 3D PDF

3D

Customer View Model

[ENG\\_CVM\\_CVM\\_2317658-7\\_A.2d\\_dxf.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_2317658-7\\_A.3d\\_jgs.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_2317658-7\\_A.3d\\_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

---

### Datasheets & Catalog Pages

#### ALCOSWITCH Anti-Vandal Switch

English

---

### Agency Approvals

#### UL Report

English