

HC-STA-D07-HHFS-1TGM20-PL-BK - Housing



1419255

<https://www.phoenixcontact.com/us/products/1419255>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing D7, for single locking latch, material: PA, cable outlets: 1, straight, 1x M20, height: 77.6 mm, cable gland: with, Standard

Commercial data

Item number	1419255
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF56
Product key	BF7APD
Catalog page	Page 514 (C-2-2019)
GTIN	4055626159966
Weight per piece (including packing)	25 g
Weight per piece (excluding packing)	24 g
Customs tariff number	85389099
Country of origin	CN

HC-STA-D07-HHFS-1TGM20-PL-BK - Housing



1419255

<https://www.phoenixcontact.com/us/products/1419255>

Technical data

Notes

General	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
---------	---

Product properties

Product type	Housing with locking latch
Housing type	Sleeve housing
Product family	HC-STA-D07
Series	HC-D
Application	Standard
Type	D7
No. of cable outlets	1
Type of the screw connection	1x M20
Shielded	no
Cable outlet	straight
Thread type	M20

Dimensions

Dimensional drawing	
Width	34.2 mm
Height	77.6 mm
Length	26.5 mm
Wrench size, union nut	22 mm

Material specifications

Flammability rating according to UL 94	V0 (Housing)
Housing material	PA
Locking latch material	PA

Mechanical properties

Mechanical data	
Type of the screw connection	1x M20
Locking type	Pin

Cable/line

External cable diameter Cable 1	4 mm ... 10 mm
---------------------------------	----------------

Connection data

HC-STA-D07-HHFS-1TGM20-PL-BK - Housing



1419255

<https://www.phoenixcontact.com/us/products/1419255>

External cable diameter	4 mm ... 10 mm
Tightening torque	Locking screw

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
Impact strength	IK06
Ambient temperature (operation)	-40 °C ... 125 °C

HC-STA-D07-HHFS-1TGM20-PL-BK - Housing


1419255

<https://www.phoenixcontact.com/us/products/1419255>



Drawings

Dimensional drawing

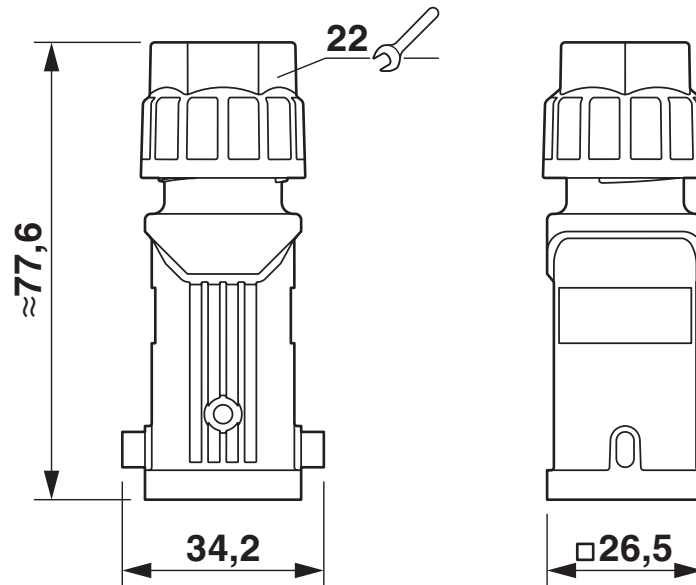

Dimensional drawing

HC-STA-D07-HHFS-1TGM20-PL-BK - Housing



1419255

<https://www.phoenixcontact.com/us/products/1419255>

Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1419255>

DNV

Approval ID: TAE000037S

HC-STA-D07-HHFS-1TGM20-PL-BK - Housing



1419255

<https://www.phoenixcontact.com/us/products/1419255>

Classifications

ECLASS

ECLASS-11.0	27440202
ECLASS-12.0	27440202
ECLASS-13.0	27440202

ETIM

ETIM 9.0	EC000437
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

HC-STA-D07-HHFS-1TGM20-PL-BK - Housing



1419255

<https://www.phoenixcontact.com/us/products/1419255>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com