



Connectors > Power Connectors > Circular Power > Circular Power Connectors



Number of Positions: 8

Connector Product Type: **Housing**

Operating Voltage: **250 VDC**

Connector System: **Wire-to-Wire**

Sealable: **No**

Features

Dimensions

Compatible Insulation Diameter Range	1.73 mm[.068 in]
--------------------------------------	------------------

Packaging Features

Packaging Quantity	100
Packaging Method	Standard

Mechanical Attachment

Mating Retention Type	Threaded Coupling
Thread Size	5/8-24 UNEF-2A
Panel Mount Feature Type	Flange
Mating Alignment Type	Keyed
Mating Alignment	With
Connector Mounting Type	Cable Mount (Free-Hanging)
Mating Retention	With
Panel Mount Feature	Without

Housing Features



Body Orientation	Straight
Housing Color	Black
Housing Material	Thermoplastic
Circular Connector Shell Size	11

Configuration Features

Reverse Numbering	Without
Number of Positions	8
Number of Power Positions	0
Number of Signal Positions	8

Product Type Features

Connector Product Type	Housing
Connector System	Wire-to-Wire
Sealable	No
Connector & Contact Terminates To	Wire & Cable
Connector & Housing Type	Receptacle
Circular Connector Shell Type	All Plastic

Electrical Characteristics

Operating Voltage	250 VAC
-------------------	---------

Contact Features

Reverse Gender	Yes
Contact Type	Socket
Contact Current Rating (Max)	7.5 A
Contact Protection	With

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
Fluid Resistance	None

Operation/Application

Circuit Application	Signal
Shielded	No

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------



Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts



TE Part # 207489-1
FLEXIBLE CABLE BOOT, SIZE 11



TE Part # 213811-1
COUPLING RING,SZ 11,CPC

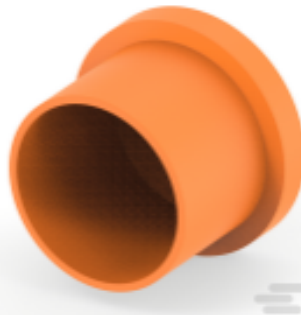

TE Part # 1-2407269-1
CAP, CPC, SIZE 11 RECP & 13 PLUG, ORANGE



TE Part # 1546347-2
R/A CABLE CLAMP KIT,SZ 11,CPC



TE Part # 206358-6
CABLE CLAMP KIT, BULK PKG

TE Part # 1-206062-4
CABLE CLAMP KIT #11

TE Part # 206434-1
CPC PLUG ASSEMBLY SIZE 11-8

TE Part # 207490-1
CABLE GRIPPER, SIZE 11

TE Part # 796379-2
R/A STRN RELIEF KIT,SZ 11,CPC

TE Part # 1-2407269-2
CAP, CPC, SIZE 11 RECP & 13 PLUG, BLACK

TE Part # 207299-1
PLUG MTG. FLANGE NO 11 CPC

TE Part # 1-206062-7
CABLE CLAMP KIT, BULK PKG

TE Part # 206358-5
CABLE CLAMP ASY, SIZE 11

Also in the Series | AMP CPC

Connector Backshells(1)

Connector Caps & Covers(16)

Connector Contacts(6)

Connector Seals & Cavity Plugs(35)

Connector Strain Relief(60)

Insertion & Extraction Tools(1)

Power Contacts(6)

Customers Also Bought



TE Part #3-640440-9
09P MTA100 CONN ASSY 22AWG RED



TE Part #1658538-3
SOCKET CONT DUPL PLT STRIP HD-



TE Part #205838-1
CPC PLUG ASSEMBLY SIZE 11-8



TE Part #206516-1
CPC PLUG ASSEMBLY SIZE 11-4



TE Part #1-206062-6
CABLE CLAMP KIT #11



TE Part #1-206062-4
CABLE CLAMP KIT #11



TE Part #1617151-3
JMGSP-5P = M39016/41-041P



TE Part #CAT-P592-R2456
PIDG Rectangular Tongue Terminals



TE Part #02560231-160
R30A 10KHZ +/- 60

Documents

Product Drawings

CPC RECPT ASSEMBLY SIZE 11-8

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_206433-2_U.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_206433-2_U.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_206433-2_U.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



AMP Circular Connectors for Commercial Signal & Power Applications

English

Instruction Sheets

Instruction Sheet (U.S.)

English

Agency Approvals

CSA Certificate

English

CSA Certificate

English