



Connectors > Power Connectors > Circular Power > Circular Power Connectors



Number of Positions: 28

Connector Product Type: Housing

Operating Voltage: 250 VDC

Connector System: Wire-to-Panel

Sealable: No

Features

Dimensions

Compatible Insulation Diameter Range	1.73 mm[.068 in]
--------------------------------------	------------------

Packaging Features

Packaging Quantity	100
Packaging Method	Bag

Mechanical Attachment

Mating Retention Type	Threaded Coupling
Thread Size	15/16-20 UNEF – 2A
Panel Mount Feature Type	Flange with Mounting Holes
Mating Alignment Type	Keyed
Mating Alignment	With
Connector Mounting Type	Panel Mount
Mating Retention	With
Panel Mount Feature	With

Housing Features



Body Orientation	Straight
Housing Color	Black
Housing Material	Thermoplastic
Circular Connector Shell Size	17

Configuration Features

Reverse Numbering	Without
Number of Positions	28
Number of Power Positions	0
Number of Signal Positions	28

Product Type Features

Connector Product Type	Housing
Connector System	Wire-to-Panel
Sealable	No
Connector & Contact Terminates To	Wire & Cable
Connector & Housing Type	Receptacle
Circular Connector Shell Type	All Plastic

Electrical Characteristics

Operating Voltage	250 VAC
-------------------	---------

Contact Features

Reverse Gender	No
Contact Type	Pin
Contact Current Rating (Max)	7.5 A
Contact Protection	With

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
Fluid Resistance	None

Operation/Application

Circuit Application	Signal
Shielded	No

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------



Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts




TE Part # 207387-1
CABLE GRIP, SZ 17, CPC



TE Part # 1-206070-0
CABLE CLAMP KIT, BULK PKG



TE Part # 796381-2
R/A STRN RELIEF KIT, SZ 17, CPC

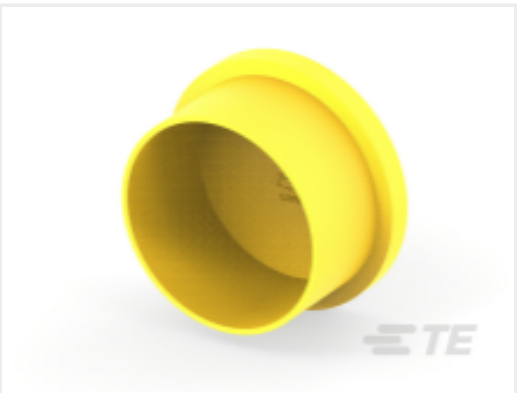

TE Part # 4-2407269-4
CAP, CPC, SIZE 17 RECP, YELLOW






TE Part # 213810-1
CPC COUPLING RING SIZE 17



TE Part # 205839-3
CPC PLUG ASSEMBLY SIZE 17-28



TE Part # 4-2407269-3
CAP, CPC, SIZE 17 RECP, RED

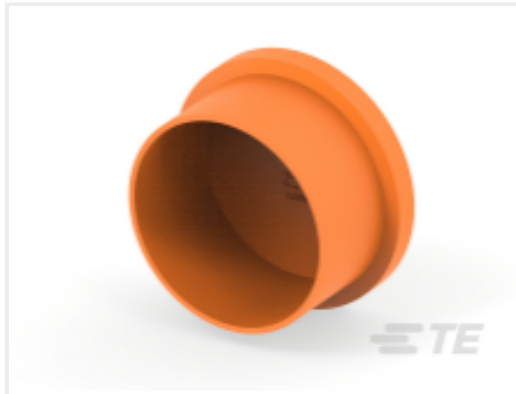

TE Part # 4-2407269-1
CAP, CPC, SIZE 17 RECP, ORANGE



TE Part # 1-206322-0
CABLE CLAMP KIT, BULK PKG



TE Part # 206322-9
CABLE CLAMP SIZE 17



TE Part # 1546349-2
R/A CABLE CLAMP KIT, SZ 17, CPC



TE Part # 207387-2
CABLE GRIP, SZ 17, CPC




TE Part # 207241-1
CABLE BOOT, SZ 17, CPC



TE Part # 206070-8
CABLE CLAMP KIT #17



TE Part # 207299-3
FLANGE PLUG MOUNT CPC

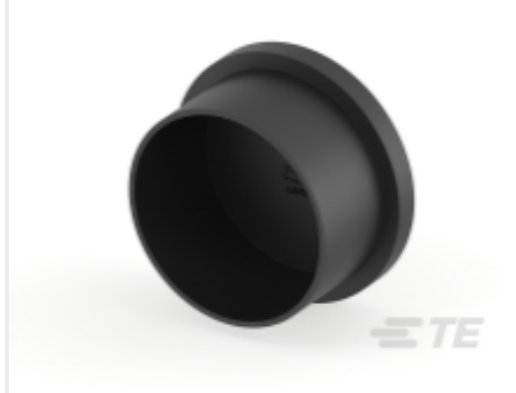

TE Part # 4-2407269-2
CAP, CPC, SIZE 17 RECP, BLACK

Also in the Series | AMP CPC



Circular Connector Backshells & Clamps(1)



Circular Power Connectors(423)




Connector Contacts(6)



Connector Hardware(12)




Power Contacts(6)

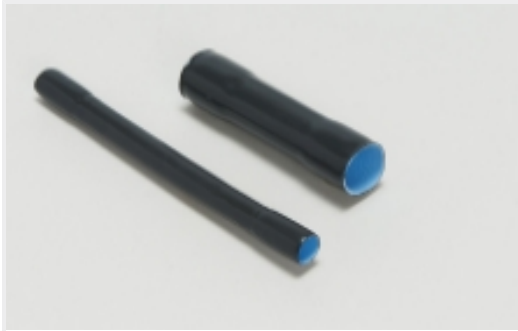

Sealing Sleeves(2)

Customers Also Bought



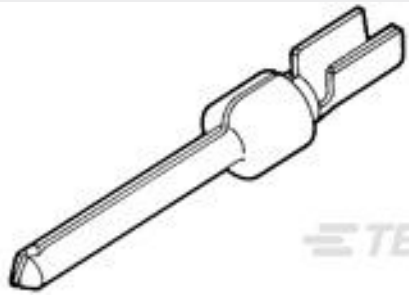


TE Part #205202-2
20DF PIN CONTACT, PLATED



TE Part #206486-1
CPC RECPT ASSEMBLY SIZE 11-9




TE Part #206070-8
CABLE CLAMP KIT #17

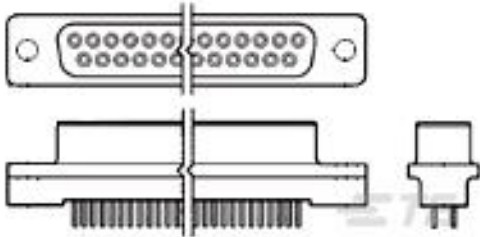

TE Part #5207828-3
HD-20 RCPT 25P VERT



TE Part #1367369-1
BUSBAR CONNECT W/CLINCH NUTS

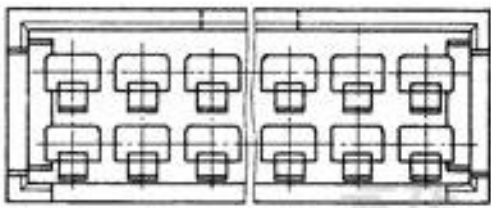

TE Part #280640
MOD II HSG



TE Part #1-1437558-3
MTA106EPC=(MSTA) SW TOG P/C TE

TE Part #1-1437627-7
C109=C-10 WHITE

TE Part #1-1437627-1
C102-AG=C-10 RED

TE Part #86455-000
FFCS-05 FLOW SWITCH

Documents

Product Drawings

CPC RECPT ASSEMBLY SIZE 17-28

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_205840-3_P.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_205840-3_P.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_205840-3_P.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



AMP Circular Connectors for Commercial Signal & Power Applications

English

Product Specifications

Connector, Circular Plastic

English

Product Specification

English

Product Specification

English

Instruction Sheets

Instruction Sheet (U.S.)

English

Agency Approvals

UL Report

English