



Connectors > Terminal Blocks & Strips > Terminal Block & Strip Accessories > Terminal Block & Strip Marking Accessories



Marking Product Type: **Label Protection Cap**

Primary Product Color: **Clear**

Operating Temperature Range: **-55 – 110 °C [-67 – 230 °F]**

UL Flammability Rating: **UL 94V-0**

EU RoHS Compliance: **Compliant**

Features

Configuration Features

Number of Cards per Package	20
-----------------------------	----

Dimensions

Product Width	8 mm[.315 in]
Product Depth	2.4 mm
Product Length	2.4 mm[.094 in]
Product Height	12 mm[.472 in]

Usage Conditions

Installation Temperature Range	-5 – 40 °C[23 – 104 °F]
Operating Temperature Range	-55 – 110 °C[-67 – 230 °F]

Body Features

Product Weight	1 g[.035 oz]
Primary Product Material	Polycarbonate
Primary Product Color	Clear

Product Type Features

Marking Product Type	Label Protection Cap
----------------------	----------------------

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------



Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1SNK708414R0000
ZK4-S-R3



TE Part # 1SNK510150R0000
ZS16-PE




TE Part # 1SNK710020R0000
ZK10-BL



TE Part # 1SNK512010R0000
ZS25



TE Part # 1SNK516151R0000
ZS50-PE

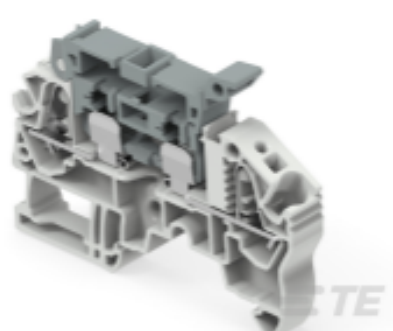


TE Part # 1SNK708410R0000
ZK4-SF1



TE Part # 1SNK708150R0000
ZK6-PE




TE Part # 1SNK536060R0000
ZS240-YL

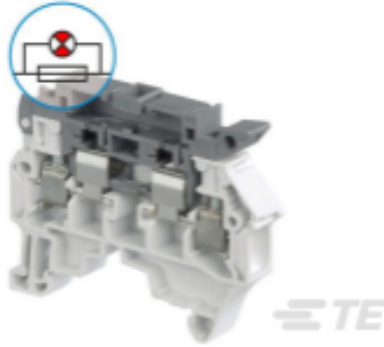

TE Part # 1SNK508414R0000
ZS4-SF1-R3



TE Part # 1SNK710150R0000
ZK10-PE

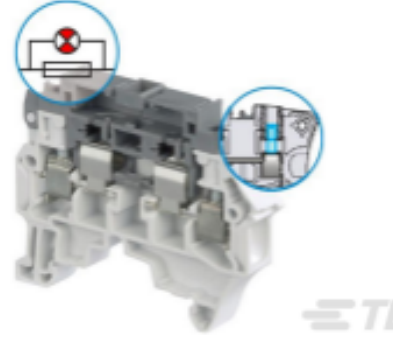

TE Part # 1SNK508415R0000
ZS4-SF1-R4



TE Part # 1SNK531060R0000
ZS150-YL




TE Part # 1SNK516064R0000
ZS50-BK



TE Part # 1SNK522020R0000
ZS70-BL



TE Part # 1SNK512020R0000
ZS25-BL

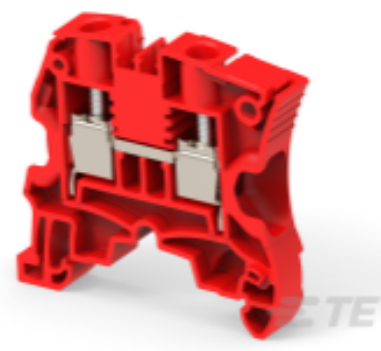

TE Part # 1SNK508062R0000
ZS10-RD




TE Part # 1SNK708066R0000
ZK6-BK



TE Part # 1SNK508315R0000
ZS10-S




TE Part # 1SNK508020R0000
ZS10-BL

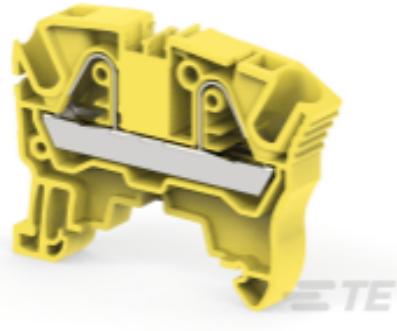

TE Part # 1SNK708030R0000
ZK6-OR


Also in the Series | ENTRELEC HTP600

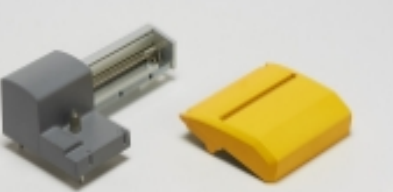

Printer Accessories(13)




Printer Ribbons(4)

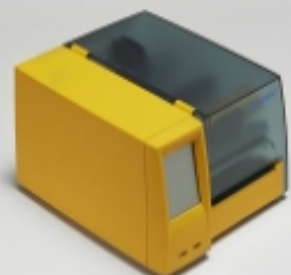

Printers(1)



Terminal Block & Strip Insulating
Accessories(3)

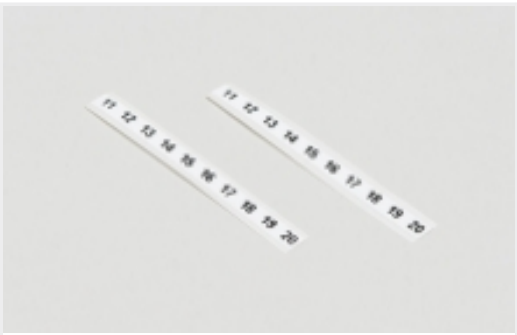

Terminal Block & Strip Marking Accessories(113)

Customers Also Bought



TE Part #DT04-2P
REC, 2P, GRY, N



TE Part #DT06-2S
PLG, 2P, GRY, N



TE Part #CAT-D487-W416
Wedgelocks: DEUTSCH DT




TE Part #CAT-D48-ST273
DEUTSCH Solid Contacts



TE Part #CAT-AM71-CH8172
AMP SUPERSEAL 1.5MM,
CONNECTOR HOUSING



TE Part #206070-8
CABLE CLAMP KIT #17

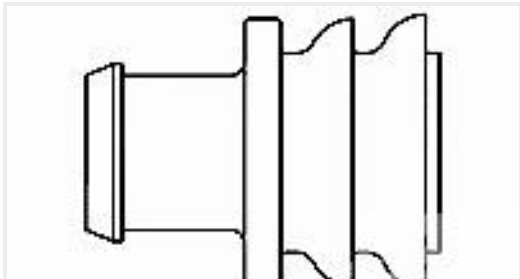

TE Part #281934-2
SINGLE WIRE SEAL

Documents

Product Drawings

PROCAP8

French

Datasheets & Catalog Pages

PROCAP8

English

ENTRELEC Terminal Blocks Catalogue (RUS)