



Terminals & Splices > Terminal Housings, Insulation Sleeves & Blocks > Crimp Terminal Housings



Terminal Type: **Tab**
Connector & Housing Type: **Tab Housing**
Number of Positions: **8**
Terminal Orientation: **Straight**
Primary Product Color: **Brown**

Features

Dimensions

Product Length	35 mm[1.38 in]
----------------	----------------

Packaging Features

Packaging Quantity	800
Packaging Method	Carton

Mechanical Attachment

Mating Retention Type	Latch
Mating Alignment	With
Connector Mounting Type	Cable Mount (Free-Hanging)

Product Type Features

Sealable	No
Connector & Housing Type	Tab Housing

Configuration Features

Number of Positions	8
---------------------	---



Body Features

Primary Product Color	Brown
-----------------------	-------

Contact Features

Terminal Type	Tab
Terminal Orientation	Straight
Contact Mating Retention	With

Housing Features

Housing Material	PBT
Centerline (Pitch)	6 mm[.236 in]

Usage Conditions

Operating Temperature Range	-40 – 105 °C[-40 – 221 °F]
-----------------------------	----------------------------

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


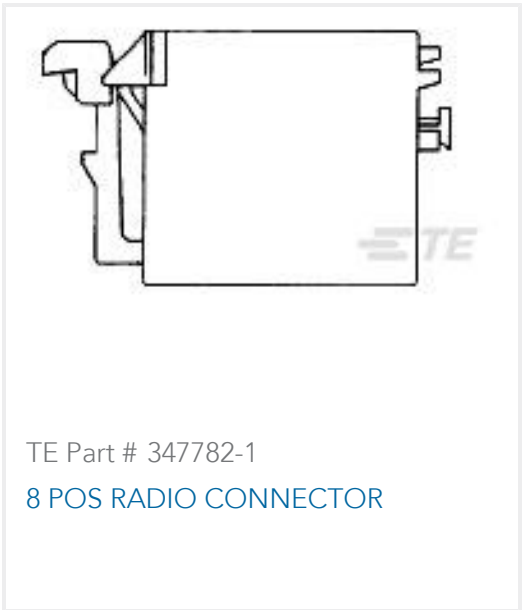
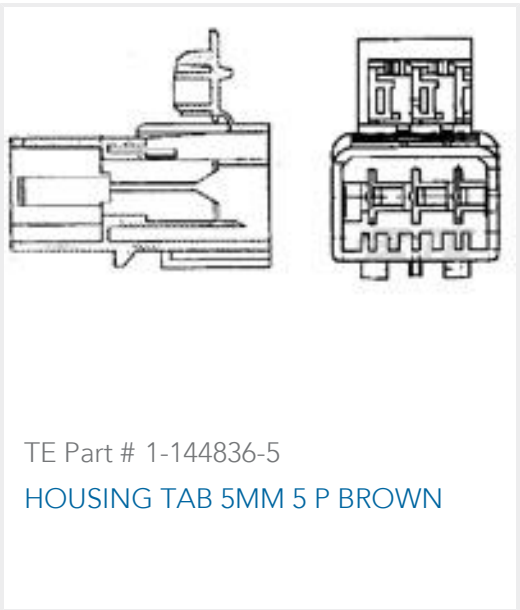




Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits








as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

			
TE Part # 6-316441-6 FF 187 PLUG 8P ASSY LIGHT GRAY	TE Part # 347782-1 8 POS RADIO CONNECTOR	TE Part # 1-144836-5 HOUSING TAB 5MM 5 P BROWN	TE Part # 338696-1 FASTIN FASTON (FF) HOUSING TAB
			
TE Part # 9-144836-5 DOUBLE LOCKING 5 MM HOUSING TAB PA66	TE Part # 964473-1 FF 110 TAB HSG 10P PBT BLACK	TE Part # 5-144835-3 HOUSING TAB 5MM 3 P GREEN	

Also in the Series | FASTIN-FASTON 110

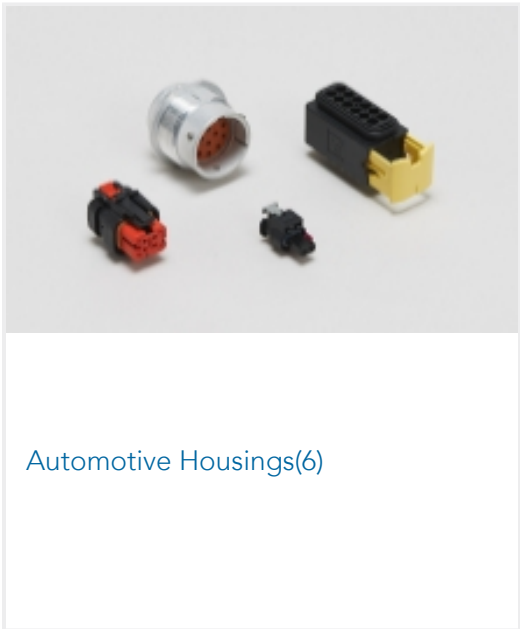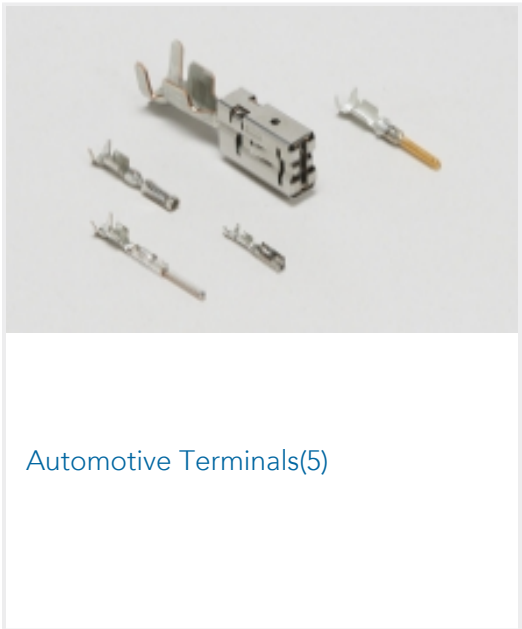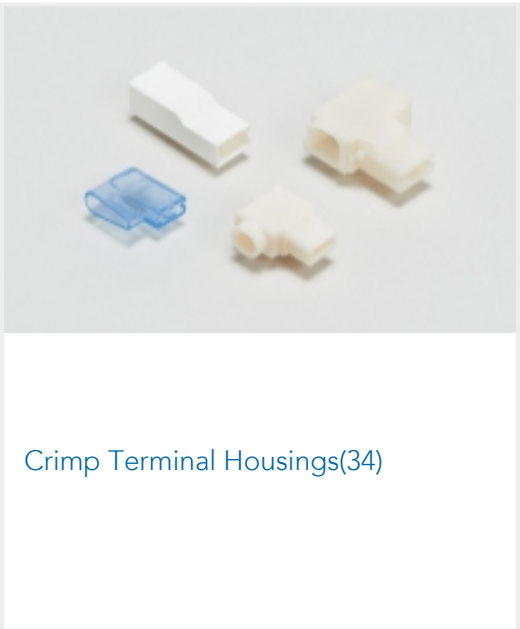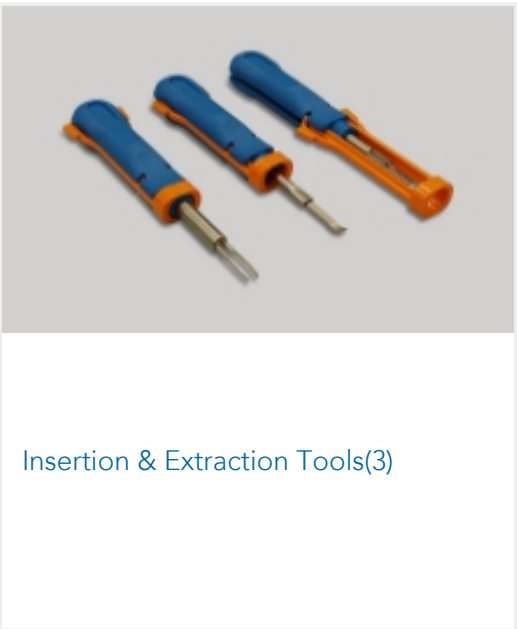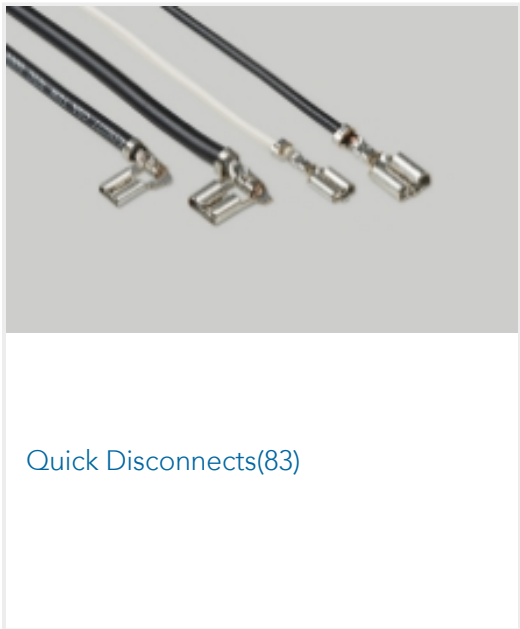			
Automotive Housings(6)	Automotive Terminals(5)	Crimp Terminal Housings(34)	Insertion & Extraction Tools(3)
			
Quick Disconnects(83)			

Customers Also Bought



TE Part #1745000-3
8POS MQS REC



TE Part #5747842-2
25 MSFL PLUG RA 318 (FM,BL)



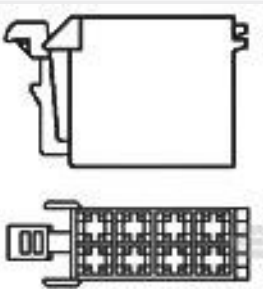
TE Part #2119118-1
SDE Commercial Tool & Die



TE Part #1-1969597-0
10P RCPT VAL-U-LOK V2



TE Part #1969597-4
4P RCPT VAL-U-LOK V2



TE Part #962191-1
8P JUNIOR-TIMER HSG



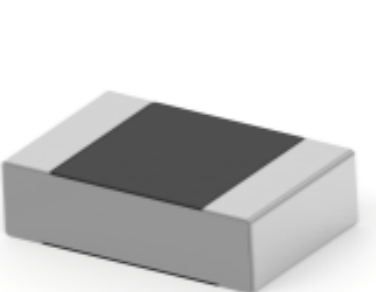
TE Part #963709-1
SPT REC 6.3 Contact SRC Sn



TE Part #160743-4
110 FASTIN FASTON, TAB, 20-16 AWG, PTBR



TE Part #926471-3
1P UNIV MNL ST GEH



TE Part #7-1614883-3
CPF 0805 7K5 0.1% 25PPM 5K RL

Documents

Product Drawings

FF 110 PLUG HSG 8P.

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_106455-4_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_106455-4_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_106455-4_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



White Paper: Nylon Discoloration

English

Product Specifications

Application Specification

English