


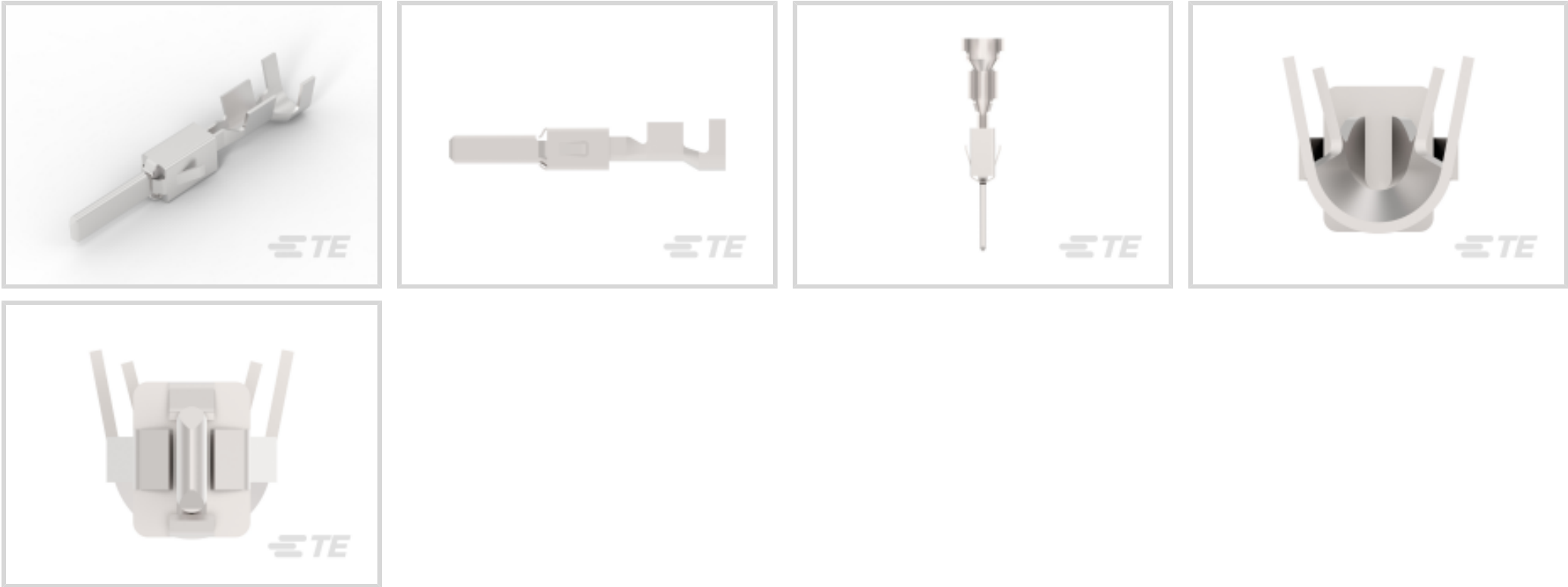

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Wave solder capable to 240°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1-1579007-6
EXTRACTION TOOL



TE Part # 2063490-2
SDE TAB 0.5-2.5mm2 DIE SET



TE Part # 4-1579007-3
EXTRACTION TOOL KIT



TE Part # 2063490-1
SDE TAB 0.5-2.5mm2 ASSY

Customers Also Bought



TE Part #964203-5
STD PW TIMER CONTACT



TE Part #1-1337551-0
FME Str Jk Hex Nickel Pltd RG174A/U, 188



TE Part #1-2176507-0
CJP 200W 3R3 5% Lead



TE Part #967631-1
2. KONT-SICHERUNG 9P



TE Part #1-965641-1
FLACH-STE-GEH2,8 6P



TE Part #2-1670894-1
8POS,AMP MCP2.8,REC HSG,ASSY



TE Part #K1153628
Push button switch TS-211-GE132



TE Part #9-1241961-8
STANDARD TIMER MARK II HOUSING



TE Part #1-963746-1
SPECIAL TERMINAL 17-13 AWG PTPB LP



TE Part #1-963745-1
SPECIAL TERMINAL 20-17 AWG PTPB LP

Documents

Product Drawings

TAB TAB 1.0-2.5 MM2 SIPPHBZ

English

CAD Files

Customer View Model

ENG_CVM_CVM_1-963749-2_E.2d_dxf.zip

English

3D PDF



3D

Customer View Model

[ENG_CVM_CVM_1-963749-2_E.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1-963749-2_E.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[HDSCS Catalog](#)

English

[CONNECTOR SELECTOR](#)

English

Product Specifications

[Application Specification](#)

English