



Connectors > Connector Accessories > Connector Strain Relief



Strain Relief Accessory Type: **Cable Clamp Kit**
Primary Product Material: **Thermoplastic**
Primary Product Color: **Black**
Compatible With Connector Shell Size: **13**
Cable Entry Diameter: **17.86 mm [.703 in]**

Features

Housing Features

Compatible With Connector Shape	Circular
Body Orientation	Straight

Product Type Features

Strain Relief Accessory Type	Cable Clamp Kit
------------------------------	-----------------

Body Features

Primary Product Material	Thermoplastic
Primary Product Color	Black

Operation/Application

Compatible With Connector Shell Size	13
Shielded	No

Dimensions

Cable Entry Diameter	17.86 mm[.703 in]
----------------------	-------------------

Mechanical Attachment

Thread Size	3/4-20 UNEF-2B
-------------	----------------



Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Method	Bulk
Packaging Quantity	100

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>





EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

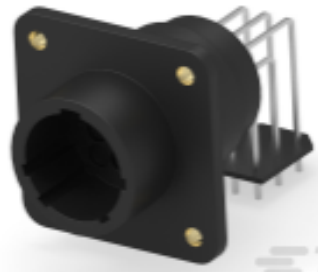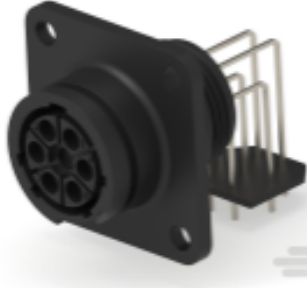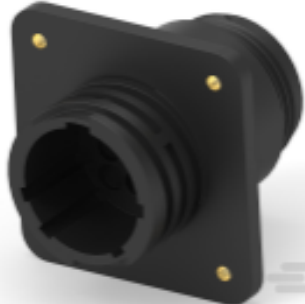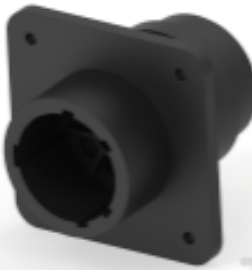

 TE Part # 788157-2 SLD CPC PLUG ASSY,13-9,STD SEX	 TE Part # 211400-1 CPC PLUG ASSEMBLY SIZE 13-7	 TE Part # 206705-2 CPC 13-9 FREE HANGING RECPT	 TE Part # 206708-1 CPC PLUG ASSEMBLY SIZE 13-9
 TE Part # 1-796433-1 CPC POSTED RCPT,13-7 LF	 TE Part # 211398-4 CPC RECPT. SIZE 13-7,THRD INST	 TE Part # 208223-9 CPC RECPT ASSEMBLY SIZE 13-9	 TE Part # 1-208223-0 CPC RCPT ASSEMBLY SIZE 13-9
 TE Part # 1977884-1 SLD CPC PLUG ASSY,13-9,STD SEX, UV RESIS	 TE Part # 1-796375-2 CPC PSTD RCPT,13-9,R/A LF	 TE Part # 211398-2 CPC RECPT. SIZE 13-7	 TE Part # 211401-1 RECEPT,SZ 13-7,CPC
 TE Part # 1-796500-1 CPC PSTD RCPT,13-7,R/A LF	 TE Part # 207008-5 CABLE CLAMP, SIZE 13	 TE Part # 211398-1 CPC RECPT. SIZE 13-7	 TE Part # 208131-1 CPC RECPT ASSEMBLY,SIZE 13-9
 TE Part # 211401-4 RECEPT,SZ 13-7,CPC	 TE Part # 206705-1 CPC RECPT. ASY SIZE 13-9	 TE Part # 1776903-1 CPC POSTED RCPT,13-7,R/A	 TE Part # 1-796435-2 CPC PSTD RCPT,13-7,R/A LF

Also in the Series | [AMP CPC](#)



Circular Connector Backshells & Clamps(1)



Circular Power Connectors(423)




Connector Contacts(6)



Connector Hardware(12)



Power Contacts(6)

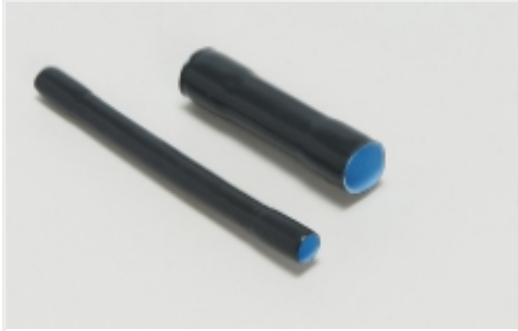

Sealing Sleeves(2)

Customers Also Bought




TE Part #206708-1
CPC PLUG ASSEMBLY SIZE 13-9



TE Part #1393114-1
KUEP-3D15-24=KU-



TE Part #1393114-2
KUEP-3D15-48=KU

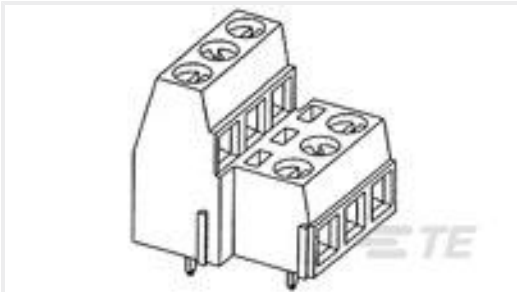


TE Part #796692-6
TERMI-BLOK PCB MOUNT 1&2 6P.5




TE Part #5645945-2
SKT,MIN-SPR B-N SN-AU SER-1.5



 
TE Part #AAF2404-00
BTH3-09-04-1-B-SE




TE Part #6450813-2
MBXL VERT HDR 6 LP

 

TE Part #9062290001
RPS-8-4/2.0-S1-9

 

TE Part #397293-000
SHRINKMARK-10-2-9-1K

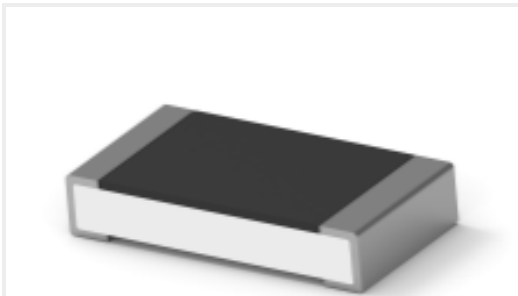

TE Part #2-2176389-1
RQ 1206 174R 0.1% 10PPM 5K RL

Documents



Product Drawings

CABLE CLAMP KIT, BULK PKG

English

CAD Files

Customer View Model

ENG_CVM_CVM_207008-6_M.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_207008-6_M.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_207008-6_M.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMP Circular Connectors for Commercial Signal & Power Applications

English

Agency Approvals

CSA Certificate

English

CSA Certificate

English