

RP73PF2A1K0BTDF

✓ ACTIVE

Holsworthy | Holsworthy RP73

TE Internal #: 1-2176092-8

Surface Mount Precision Resistor, Thin Film, 0805, .25 W, 1K ohm, .1 %, ±25 ppm/°C, Solder, 2 Terminations, Height .55 mm [.022 in], Holsworthy RP73

[View on TE.com >](#)



Passive Components > Resistors > Surface Mount Resistors



Resistor Type: Precision Resistor

Element Type: Thin Film

Package Size Code: 0805

Power Rating: .25 W

Resistance Value: 1K Ω

Features

Industry Standards

Moisture Sensitivity Level	1
----------------------------	---

Electrical Characteristics

Operating Voltage	150 V
Power Rating	.25 W
Resistance Value	1K Ω
Resistance Class	1kΩ – 1MΩ
Passive Component Tolerance	.1 %

Product Type Features

Resistor Type	Precision Resistor
Element Type	Thin Film
Package Size Code	0805

Configuration Features

Number of Resistors	1
---------------------	---

Termination Features

Surface Mount Resistor Termination Type	Solder
Number of Terminations	2

Dimensions



Product Height	.55 mm[.022 in]
Product Length	2 mm[.079 in]
Product Width	1.25 mm[.049 in]

Usage Conditions

Temperature Coefficient	±25 ppm/°C
-------------------------	------------

Packaging Features

Packaging Method	Taped & Reeled
------------------	----------------

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Reflow solder capable to 260°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

RP73PF2A1K0BTDF


Surface Mount Precision Resistor, Thin Film, 0805, .25 W, 1K ohm, .1 %, ±25 ppm/°C, Solder, 2 Terminations, Height .55 mm [.022 in], Holsworthy RP73




TE Part # 2176088-4
RP 1J 0.166W 806R 0.1% 25PPM 1K RL

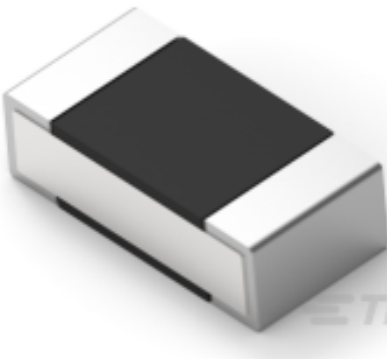

TE Part # 2176308-1
RP 1E 0.1W 133K 0.1% 25PPM 5K RL

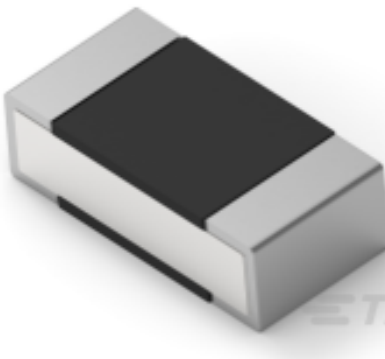

TE Part # 2176313-7
RP 1E 0.1W 154K 0.1% 25PPM 1K RL

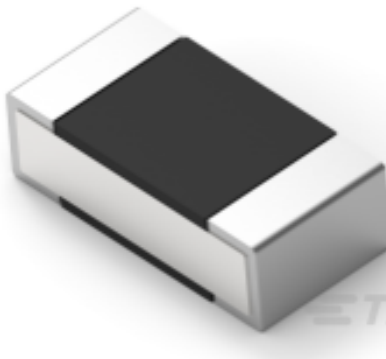


TE Part # 2176308-7
RP 1E 0.1W 154K 0.1% 25PPM 5K RL




TE Part # 2176087-2
RP 1J 0.166W 69R8 0.1% 25PPM 1K RL



TE Part # 2176091-7
RP 2A 0.25W 66R5 0.1% 25PPM 1K RL

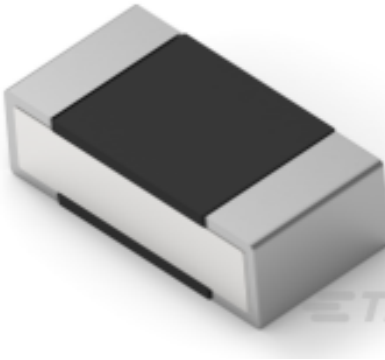


TE Part # 2176313-8
RP 1E 0.1W 158K 0.1% 25PPM 1K RL

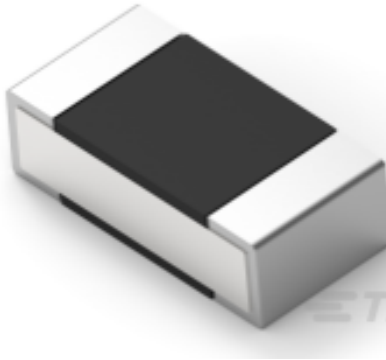


TE Part # 2176309-1
RP 1E 0.1W 10R 0.1% 25PPM 1K RL




TE Part # 2176087-4
RP 1J 0.166W 73R2 0.1% 25PPM 1K RL

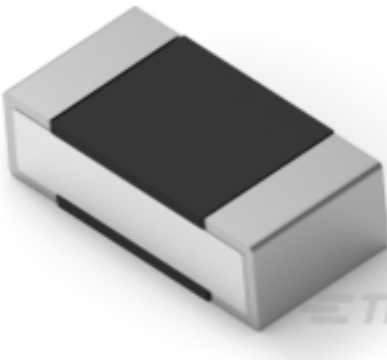


TE Part # 2176313-9
RP 1E 0.1W 162K 0.1% 25PPM 1K RL

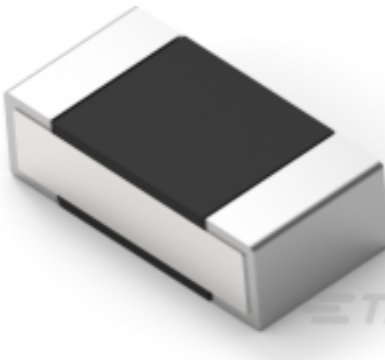

TE Part # 2176306-7
RP 1E 0.1W 1K33 0.1% 25PPM 5K RL

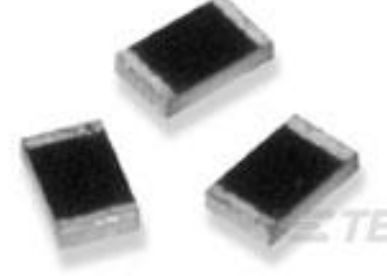

TE Part # 1625868-6
RP 2A 0.25W 200R 0.1% 25PPM 1K RL

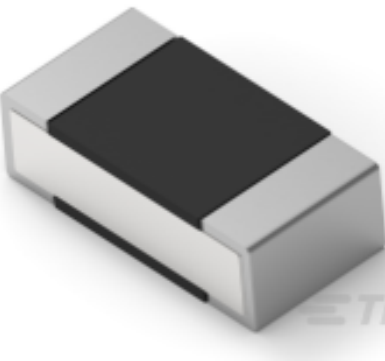

TE Part # 2-2176312-9
RP 1E 0.1W 24K3 0.1% 25PPM 1K RL



TE Part # 2-2176088-8
RP 1J 0.166W 1K47 0.1% 25PPM 1K RL



TE Part # 2-2176091-6
RP 2A 0.25W 105R 0.1% 25PPM 1K RL



TE Part # 4-2176087-2
RP 1J 0.166W 182R 0.1% 25PPM 1K RL




TE Part # 4-2176093-6
RP 2A 0.25W 28K7 0.1% 25PPM 1K RL



TE Part # 4-2176090-0
RP 1J 0.166W 332K 0.1% 25PPM 1K RL




TE Part # 4-1625867-2
RP 1J 0.166W 16R5 0.1% 25PPM 1K RL

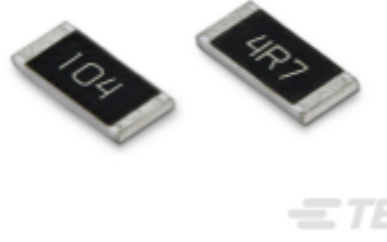

TE Part # 4-2176094-2
RP 2A 0.25W 324K 0.1% 25PPM 1K RL

Also in the Series | [Holsworthy RP73](#)

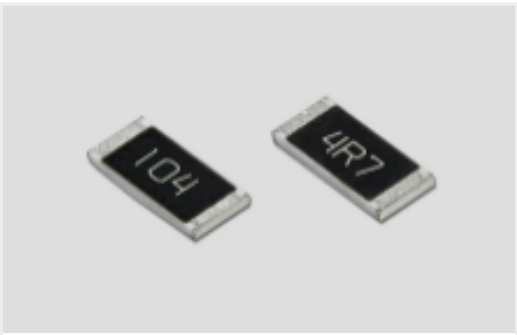

Surface Mount Resistors(4227)

Customers Also Bought



TE Part #MS580302BA01-00
MS5803-02BA01 DIGIT PRESSURE
SENSOR TUBE



TE Part #5050863-5
SOCKET,MIN-SPR SN-AU SER-2



TE Part #2-332095-2
SOCKET,MIN-SPR W/KO AU SER-1




TE Part #9-1625868-4
RP 2A 0.25W 49R9 0.1% 25PPM 1K RL



TE Part #2342838-1
AVP16M H. FLAT AIO NL 500MM/2X3



TE Part #4-2176327-1
CRGP 0805 22K 1%

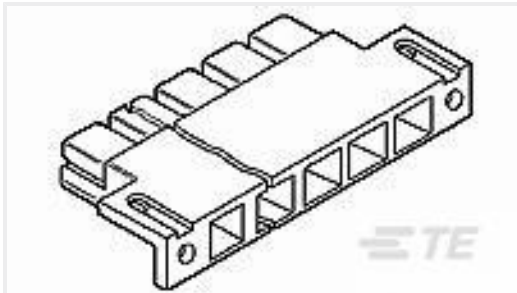


TE Part #54489-4
HSG ASSY,PWR LK,SRS1,4POS,FLNG



TE Part #5747497-4
50 PLUG RA/MS STD (SL)



 TE Part #2343428-1
HD+ CE, RA, CRPS



TE Part #3782608661
Speed sen DSL 1210.02 A1HV EEG56A

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-2176092-8_BA.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-2176092-8_BA.3d_igs.zip

RP73PF2A1K0BTDF

Surface Mount Precision Resistor, Thin Film, 0805, .25 W, 1K ohm, .1 %, ±25 ppm/°C, Solder, 2 Terminations, Height .55 mm [.022 in], Holsworthy RP73



English

Customer View Model

[ENG_CVM_CVM_1-2176092-8_BA.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[RP73-0915](#)

English