


PX0911/05/S Datasheet

Product Name // Flex Cable Connector PX0911 Series 5
Contact Socket 13mm-15mm Cable (Yellow Gland)

 [View Product Page](#)

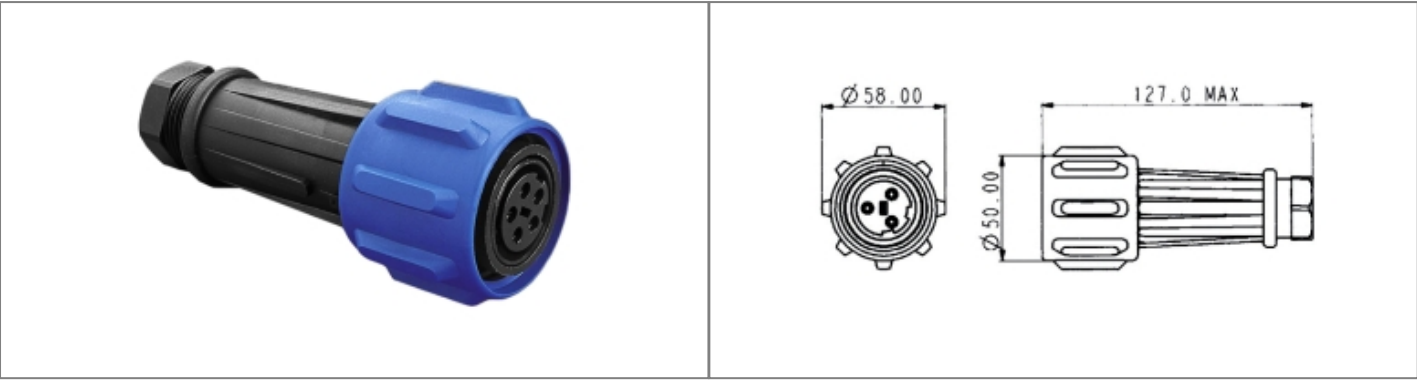

// Product Description:	
- Flex Cable Connectors - Water and dustproof to IP68 when mated with compatible connector - Positive fast-acting locking ring - can be turned with a gloved hand - Plug or Socket 2, 3, 4, 5, 7, 10 Contact with leading Earth on 3, 4, 5, 7 Contact versions, trailing Neutral on 5 Contact version - Screw Terminals	- Choice of cable acceptance 7mm-22mm diameter depending on part code (see data for details): - PX09 part codes 7mm-15mm diameter - PXA9 part codes (large cable version with strain relief clamp) 14mm-22mm diameter - Packs of Cable Glands for differing cable diameters available separately (PX0980, PXA980) - PX0960/PX0990 Sealing Caps available separately to maintain IP rating of unmated connectors - Mate with PX09 or PXA9 Series Flex and Panel Mount Connectors, as appropriate

// General Information:	
Product Display Title: Product Family: Product Series: Approvals: Body Material: Body Material Type: Contact Type: Coupling Type: Current Max: Diameter Over Coupling Ring Mm: Flamability Rating: Function: Ip Rating: Max Cable Entry Size: Min Cable Entry Size: Max Contact Accomodation Awg: Min Contact Accomodation Awg: Max Contact Accomodation Mm2: Min Contact Accomodation Mm2: Max Operating Temperature: Min Operating Temperature: Number Of Contacts: Voltage Max:	Flex Cable Connectors Circular Power Connectors 900 Series Buccaneer UL Polyamide (PA) Plastic Body Socket Contact Screw 32A 58mm UL94V-0 Flex Cable Connector IP68 15mm 13mm 13AWG 10AWG 4mm2 2.6mm2 +85°C -40°C 5 Contacts 600V

// Product PDF Links

 900 Series power connectors...

 900 Series power connectors wiring...

// Product 3D CAD Model Links

 PX0911/05/S3D CAD Model