



Connectors > Power Connectors > Circular Power > Circular Power Connectors



Number of Positions: 9

Connector Product Type: **Housing**

Operating Voltage: **600 VDC**

Connector System: **Wire-to-Wire**

Sealable: **Yes**

Features

Dimensions

Compatible Insulation Diameter Range	1.65 – 3.05 mm[.065 – .12 in]
--------------------------------------	-------------------------------

Packaging Features

Packaging Quantity	1
Packaging Method	Package

Mechanical Attachment

Mating Retention Type	Threaded Coupling
Thread Size	3/4 - 20 UNEF-2A
Polarization Code	A
Mating Alignment Type	Keyed
Mating Alignment	With
Mating Retention	With
Panel Mount Feature	Without

Housing Features

Body Orientation	Straight
------------------	----------



Housing Color	Black
Housing Material	Nylon
Circular Connector Shell Size	13

Product Type Features

Connector Seal & Plug Type	Peripheral, Wire Entry Seal
Connector Product Type	Housing
Connector System	Wire-to-Wire
Sealable	Yes
Connector & Contact Terminates To	Wire & Cable
Connector & Housing Type	Receptacle
Circular Connector Shell Type	All Plastic

Configuration Features

Reverse Numbering	With
Number of Positions	9
Number of Power Positions	0
Number of Signal Positions	9

Electrical Characteristics

Operating Voltage	600 VAC
-------------------	---------

Contact Features

Reverse Gender	No
Contact Type	Pin
Contact Protection	With

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
Fluid Resistance	Immersion

Operation/Application

Circuit Application	Signal
Shielded	No

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Other

--	--



EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 788157-2
SLD CPC PLUG ASSY,13-9,STD SEX



TE Part # 2-2407269-2
CAP, CPC, SIZE 13 RECP, BLACK




TE Part # 213485-1
CPC SEALING CAP ASSY SIZE 13



TE Part # 81665-4
ECONOSEAL, FLANGE GASKET



TE Part # 208337-1
SEAL PROTECTOR PIN

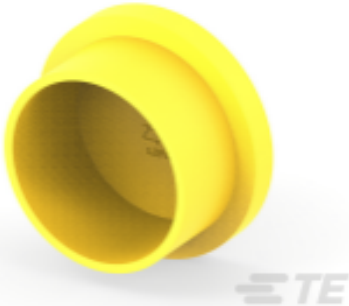

TE Part # 2-2407269-4
CAP, CPC, SIZE 13 RECP, YELLOW



TE Part # 788157-1
SLD CPC 13-9 PLUG,STD,SM INS



TE Part # 211870-2
SEALING CAP ASSY,SZ 13,CPC



TE Part # 2-2407269-3
CAP, CPC, SIZE 13 RECP, RED



TE Part # 54123-1
CPC,13 LONG TUBE

Also in the Series | AMP CPC



Circular Connector Backshells & Clamps(1)



Circular Power Connectors(423)



Connector Contacts(6)



Connector Hardware(12)



Power Contacts(6)




Sealing Sleeves(2)

Customers Also Bought



TE Part #1879073-1
THS10 R05 5%

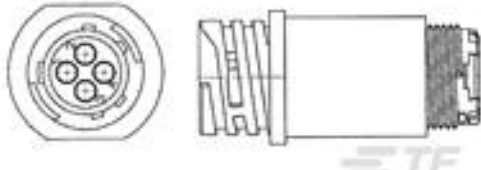

TE Part #796096-2
SLD CPC RCPT ASY,11-4,STD SEX



TE Part #927892-1
FF 110 TAB 0.5-1 MM2 PTP CUSN30



TE Part #5-160303-2
110 FASTON REC 22-20 AWG TPBR



TE Part #1622461-1
LR1 1% 3K3

TE Part #K1129928
Relay 29-112-11-928

TE Part #3-967644-1
2POS MQS REC SEALED COD C

TE Part #1466287-1
031-0003-0001

TE Part #1466328-1
132-0115-0002=PLUG,STR GC-50

TE Part #ASA151N00410235000
623 PLUG

Documents

Product Drawings

SLD CPC RCPT ASSY,13-9,STD SEX

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_788159-2_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_788159-2_A.3d_igs.zip

English

Customer View Model

ENG_CVM_788159-2_A.3d_stp.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_788159-2_C.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_788159-2_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_788159-2_C.3d_stp.zip

English



By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages
AMP Circular Connectors for Commercial Signal & Power Applications
English

Agency Approvals
UL Report
English