



Connectors > Connector Accessories > Connector Strain Relief



Strain Relief Accessory Type: **Cable Clamp Kit**

Primary Product Material: **Thermoplastic**

Primary Product Color: **Black**

Compatible With Connector Shell Size: **23**

Cable Entry Diameter: **28.58 mm [1.125 in]**

Features

Housing Features

Compatible With Connector Shape	Circular
Body Orientation	Straight

Product Type Features

Strain Relief Accessory Type	Cable Clamp Kit
------------------------------	-----------------

Body Features

Primary Product Material	Thermoplastic
Primary Product Color	Black

Operation/Application

Compatible With Connector Shell Size	23
Shielded	No

Dimensions

Cable Entry Diameter	28.58 mm[1.125 in]
----------------------	--------------------

Mechanical Attachment

Thread Size	1-3/8-18 UNEF-2B
-------------	------------------



Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Method	Bulk
Packaging Quantity	75

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 213866-1
23-24 RCPT HSG,STD SEX,CPC



TE Part # 213860-1
23-37 RCPT HSG,STD SEX,CPC



TE Part # 213853-1
CPC PLUG ASSEMBLY SIZE 23-19



TE Part # 211770-2
CPC PLUG ASSEMBLY SIZE 23-19



TE Part # 213782-4
CPC RECPT ASSEMBLY SIZE 23-19



TE Part # 206306-1
23-37 RECEPT REV SEX




TE Part # 205843-2
CPC RECPT ASSEMBLY SIZE 23-63



TE Part # 206438-2
CPC RECPT ASSEMBLY SIZE 23-57



TE Part # 206137-5
23-7 RECEPT STD SEX

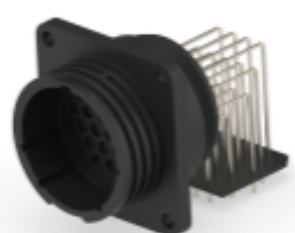


TE Part # 1-796387-2
CPC PSTD RCPT,23-24,R/A LF



TE Part # 2-208224-1
CPC RECPT ASSEMBLY SIZE 23-37



TE Part # 796188-1
SLD CPC PLUG ASSY,23-24,STD SX

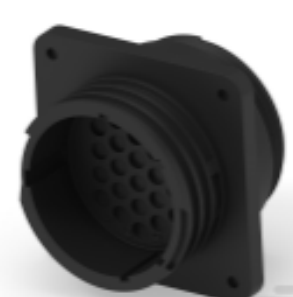

TE Part # 211839-1
CPC RCPT SZ 23-24 W/THRD INSRT



TE Part # 1-796406-1
CPC PSTD RCPT,23-37,R/A LF



TE Part # 206136-1
CPC PLUG ASSEMBLY SIZE 23-7



TE Part # 206226-1
CPC PLUG ASSEMBLY SIZE 23-7



TE Part # 206227-2
CPC RECPT ASSEMBLY SIZE 23-7



TE Part # 211773-1
23-19 CPC RECEPT REV SEX



TE Part # 213864-1
23-37 RCPT HSG,REV SEX,CPC



TE Part # 213851-1
CPC PLUG ASSEMBLY SIZE 23-24

Also in the Series | [AMP CPC](#)



Connector Backshells(1)



Connector Caps & Covers(16)



Connector Contacts(6)



Connector Seals & Cavity Plugs(35)



Connector Strain Relief(60)



Insertion & Extraction Tools(1)



Power Contacts(6)

Customers Also Bought



TE Part #2325098-4
MNTG CLIP,ENETSEAL PLUS



TE Part #66105-3
III+ SKT,24-20,15AU/FL,LP




TE Part #103946-1
8X2 MTE SHRD PIN SR POL .100CL



TE Part #2176513-9
CJP 1000W 10R 5% Lead



TE Part #1587335-1
BASE ASSEMBLY, 40 POSITION

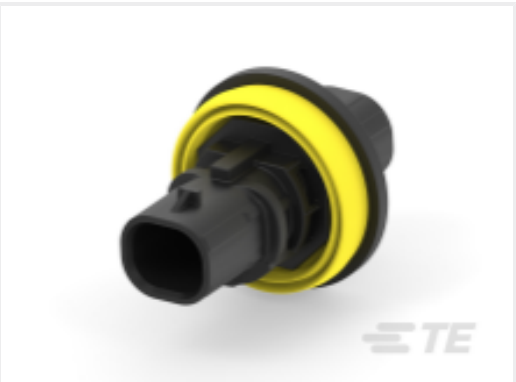

TE Part #2325106-1
ADAPTER,2POS,1.2X0.6,PIN HSG ASSY



TE Part #91523-1
CCII TYPE III+ PIN SKT 24-16 ASSY



TE Part #61276-2
.058 DIA RECPT LP 24-20



TE Part #2317204-5
5P,2MM,REC,IDC,PLAIN,26-30,STRIP, Au0.1



TE Part #2317204-9
9P,2MM,REC,IDC,PLAIN,26-30,STRIP, Au0.1

Documents



Product Drawings

LARGE CABLE CLAMP KIT,BULK PKG

English

CAD Files

Customer View Model

ENG_CVM_CVM_206512-6_K.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_206512-6_K.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_206512-6_K.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMP Circular Connectors for Commercial Signal & Power Applications

English

Agency Approvals

CSA Certificate

English

CSA Certificate

English