



TH/.025 Connector System

TE Internal #: 2005499-2

TE Internal Description: 025 JOINT 30P ASSY BLK

TH/.025 CONNECTOR SYSTEM, HOUSING

[View on TE.com >](#)



All TH/.025 Connector System, Housing (177)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts



TE Part # 2005319-3
025 JOINT 30P COVER HSG GRY



TE Part # 2005319-2
025 JOINT 30P COVER HSG BLK



TE Part # 2005319-1
025 JOINT 30P COVER HSG NAT




TE Part # 2005319-4
025 JOINT 30P COVER HSG BRN



TE Part # 2005097-1
025 RECEPTACLE CONTACT

Also in the Series | TH/.025 Connector System

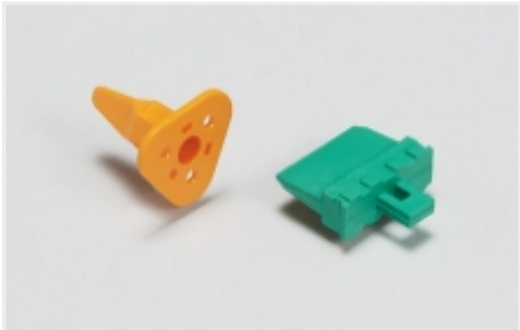

Automotive Connector Locks & Position Assurance(1)



Automotive Headers(7)




Automotive Housings(62)




Automotive Terminals(8)




Insertion & Extraction Tools(4)

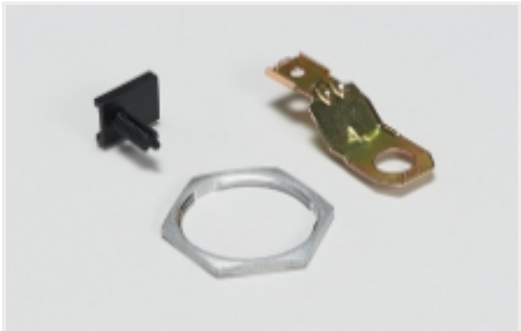

Other Automotive Connector Accessories(1)

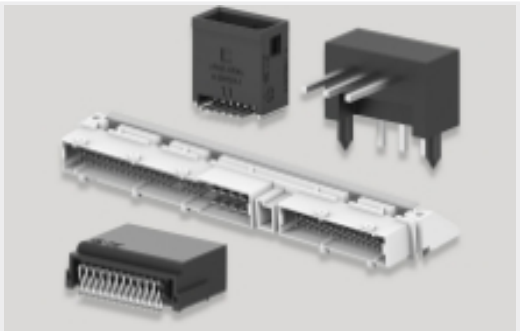

PCB Headers & Receptacles(7)

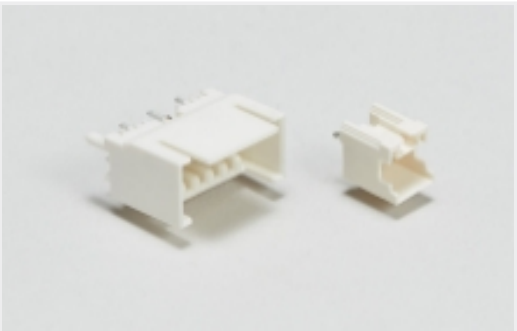

Wire-to-Board Headers & Receptacles (7)

Customers Also Bought






TE Part #1743350-2
MT-II/JPT SLD 16P PLUG ASSY




TE Part #1-2203773-3
Plug Ass'y, 4P Sealed, Key C, CPA



TE Part #1473288-1
MICRO TIMER II 6POS SECONDARY

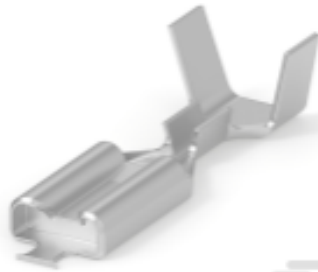


TE Part #1897537-1
187 FASTON REC CONT

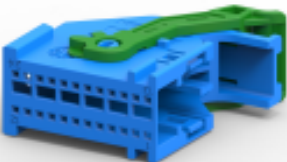

TE Part #2209954-4
AIRBAG 24P COVER ASSY



TE Part #2324321-1
025 REC CONTACT

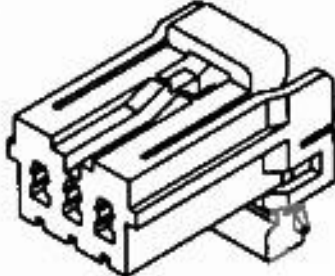

TE Part #368502-1
070 MLC PLUG HSG 6P SGL

TE Part #1813018-5
MINI FUSE RECEPTACLE

TE Part #2304945-1
PULLER



TE Part #2322347-1
12POS, HYBRID, REC HSG, UNSLD, COD 1

Documents

Product Drawings
025 JOINT 30P ASSY BLK

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2005499-2_C.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_2005499-2_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2005499-2_C.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.

Product Specifications



Product Specification

English

Instruction Sheets

Instruction Sheet (non U.S.)

English