



Connectors > Connector Accessories > Connector Strain Relief



Strain Relief Accessory Type: **Cable Clamp Kit**

Primary Product Material: **Thermoplastic**

Primary Product Color: **Black**

Compatible With Connector Shell Size: **17**

Cable Entry Diameter: **11.51 mm [.453 in]**

Features

Housing Features

Compatible With Connector Shape	Circular
Body Orientation	Right Angle

Product Type Features

Strain Relief Accessory Type	Cable Clamp Kit
------------------------------	-----------------

Body Features

Primary Product Material	Thermoplastic
Primary Product Color	Black

Operation/Application

Compatible With Connector Shell Size	17
Shielded	No

Dimensions

Cable Entry Diameter	11.51 mm[.453 in]
----------------------	-------------------

Mechanical Attachment

Thread Size	15/16-20 UNEF-2B
-------------	------------------



Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Method	Package
Packaging Quantity	1

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts



TE Part # 1776904-1
CPC POSTED RCPT,17-16,R/A



TE Part # 211766-1
CPC PLUG ASSEMBLY SIZE 17-9

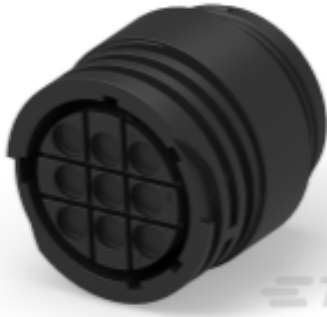

TE Part # 211769-3
17-9 CPC RECEPT REV SEX




TE Part # 211767-1
17-9 CPC RECEPT




TE Part # 206038-1
CPC RECPT ASSEMBLY SIZE 17-28



TE Part # 206039-1
CPC PLUG ASSEMBLY SIZE 17-28

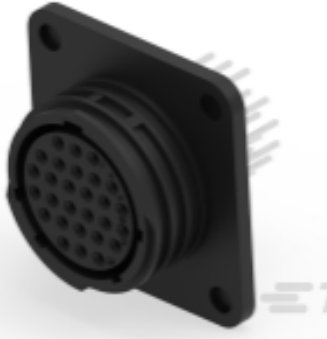

TE Part # 1-207216-7
CPC RECEPT ASSEMBLY SIZE 17-28

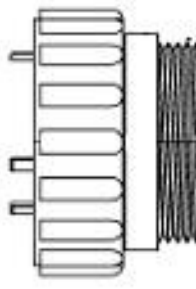

TE Part # 206554-1
CPC PLUG ASSEMBLY SIZE 17-16



TE Part # 213729-6
CPC RCPT ASSY,SZ 17-14,W/INSRT



TE Part # 211103-1
CPC RECPT ASSEMBLY 17-14



TE Part # 213855-3
CPC RECPT ASSEMBLY SIZE 17-16



TE Part # 206043-1
RECEPT,SZ 17-14 CPC




TE Part # 1-207303-3
CPC RECPT ASSEMBLY SIZE 17-16



TE Part # 1-207303-4
CPC RECPT ASSM SIZE 17-16



TE Part # 206425-1
17-3 RECPT. REV SEX

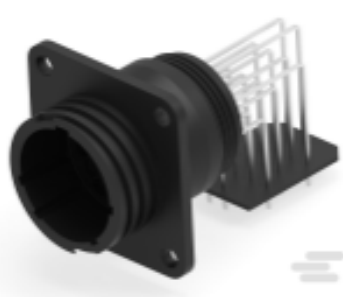

TE Part # 1-796404-1
CPC PSTD RCPT,17-16,R/A LF



TE Part # 206126-1
CPC PLUG ASSEMBLY SIZE 17-28



TE Part # 796449-1
PLUG ASSY,CPC,17-14,REV SEX



TE Part # 211769-1
17-9 CPC RECEPT REV SEX



TE Part # 1-213825-7
CPC POSTED RECEPTACLE ASSY

Also in the Series | [AMP CPC](#)



Connector Backshells(1)



Connector Caps & Covers(16)



Connector Contacts(6)



Connector Seals & Cavity Plugs(35)



Connector Strain Relief(60)



Insertion & Extraction Tools(1)



Power Contacts(6)

Customers Also Bought



TE Part #6609037-9
20EP1=F7773 S0



TE Part #5530841-5
CONN SEC II 25 POS 100C/L



TE Part #2-208224-1
CPC RECPT ASSEMBLY SIZE 23-37



TE Part #GA10K3A11B
DISCRETE 10K OHMS, +/-0.2C FROM
0C TO 70C



TE Part #770022-1
12P UMNLII IN-LNE PLUG HSG KIT




TE Part #41333
RING 18-14 AWG TPBR




TE Part #66429-4
III+ PIN,30-26,30AU/FL,LP



TE Part #770253-4
UMNL II SOK SNAUNIPHBZ LP24-18

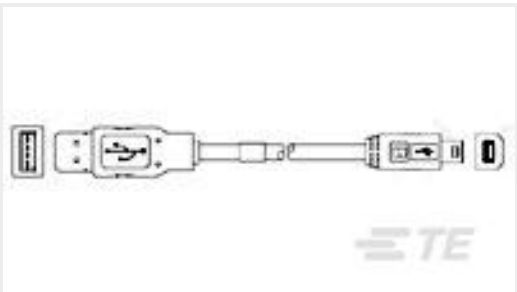

 TE Part #1487597-2
USB, A-B, 25/22, BLACK, 2.5M



TE Part #HPP805D033
HTM1735LF RH/T MODULE

Documents



Product Drawings

R/A CABLE CLAMP KIT,SZ 17,CPC

English

CAD Files

Customer View Model

ENG_CVM_CVM_1546349-2_B1.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1546349-2_B1.3d_stp.zip

English

Customer View Model

ENG_CVM_CVM_1546349-2_B1.2d_dxf.zip

English

3D PDF

3D

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMP Circular Connectors for Commercial Signal & Power Applications

English