


PX0931/10/S Datasheet

**Product Name // Panel Mount Connector PX0931 Series 10
Contact Socket**

 [View Product Page](#)

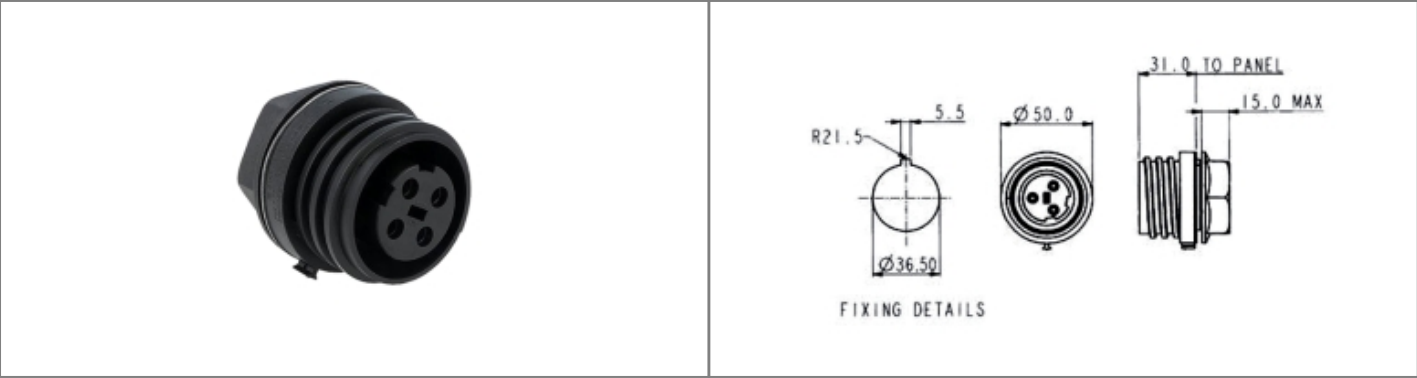

// Product Description:

- Panel Mount Connector
- Water and dustproof to IP68 when mated with compatible connector
- Positive fast-acting locking ring - can be turned with a gloved hand
- Plug or Socket
- 2, 3, 4, 5, 7, 10 Contact with leading Earth on 3, 4, 5, 7 Contact versions, trailing Neutral on 5 Contact version
- Single hole fitting, anti-rotation key
- Panel thickness 3mm-7mm
- Supplied with high grade sealing gasket
- PX0970/PX0992 Sealing Cap available separately to maintain IP rating of unmated connectors
- Mate with PX0911 and PXA911 Series Flex Connectors

// General Information:

Product Display Title:	Panel Mount Connector
Product Family:	Circular Power Connectors
Product Series:	900 Series Buccaneer
Approvals:	CSA
Body Material:	Polyamide (PA)
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	10A
Diameter Over Coupling Ring Mm:	58mm
Flamability Rating:	UL94V-0
Function:	Front Panel Mount Connector
Ip Rating:	IP68
Max Operating Temperature:	+85°C
Min Operating Temperature:	-40°C
Number Of Contacts:	10 Contacts
Voltage Max:	250V

// Product PDF Links

 [900 Series power connectors...](#)

 [900 Series power connectors wiring...](#)

// Product 3D CAD Model Links

 [PX0931/10/S3D CAD Model](#)