




Connectors > Lighting Connectors > Street Lighting Controls > Street Lighting Connectors

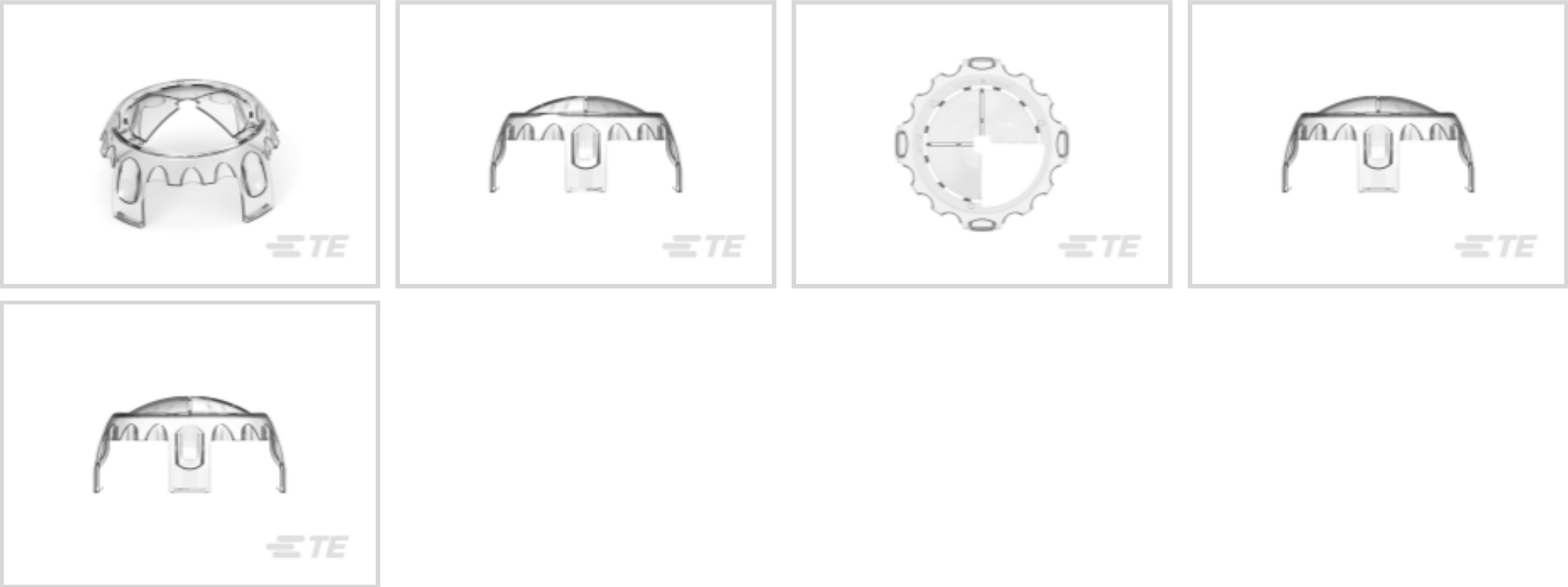

Lighting Product Type: **Accessory**
Primary Product Color: **Clear**
Product Height: **41.6 mm [1.63 in]**
Compatible With Agency/Standards Products: **Zhaga**
Operating Temperature Range: **-40 – 85 °C [-40 – 185 °F]**

Features

Product Type Features

Lighting Product Type	Accessory
-----------------------	-----------

Body Features

Primary Product Color	Clear
-----------------------	-------

Dimensions

Product Height	41.6 mm[1.63 in]
----------------	------------------

Industry Standards

Compatible With Agency/Standards Products	Zhaga
---	-------

Usage Conditions

Operating Temperature Range	-40 – 85 °C[-40 – 185 °F]
-----------------------------	---------------------------

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance



For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) SVHC > Threshold: UV-329 (1% in Component Part) Article Safe Usage Statements: Wash thoroughly after handling. Do not handle until all safety precautions have been read and understood. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Low Bromine/Chlorine - Br and Cl < 900 ppm per homogenous material. Also BFR /CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts




TE Part # 2388426-1
ASSEMBLY, SENSOR LUMAWISE MOTION



TE Part # 2396399-1
MASK, STREET LIGHTING MOTION SENSOR

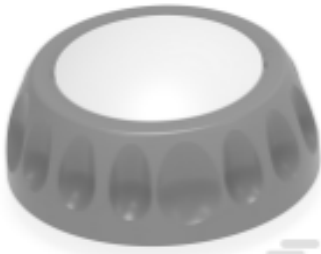


TE Part # 2445583-1
LUMAWISE MOTION - LOGIC OUTPUT, RECT.

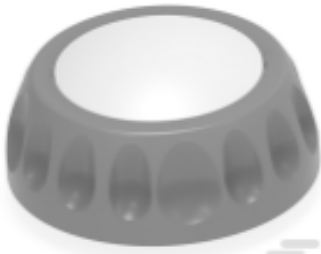

TE Part # 1-2445583-1
LUMAWISE MOTION - LOGIC OUTPUT, CIRC.

Also in the Series | LUMAWISE Endurance S

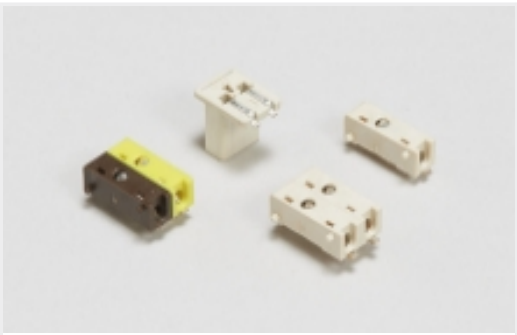

Poke-In Connectors(1)



Street Lighting Connectors(47)



Street Lighting Power Management(5)

Customers Also Bought



TE Part #2213600-2
COOLSPICE LW 12/14 TO 16/18
AWG, SEAL



TE Part #1-2834049-3
REC MOD, 2P LATCHED POKE-IN
WTW CONN.OR



TE Part #2213858-1
RECEPTACLE ASSEM., LUMAWISE
ENDURANCE S



TE Part #2834048-1
PLUG, 2P LATCHED POKE-IN WTW
CONN.NL



TE Part #2213795-1
SEALING CAP, RCPT, LUMAWISE
ENDURANCE S



TE Part #2213831-2
BASE ASSY, 80MM, VENTED, SEALED



TE Part #2388426-1
ASSEMBLY, SENSOR LUMAWISE
MOTION



TE Part #2444029-1
LUMAWISE MOTION Sensor,
Program, Rect.



TE Part #3-2444029-1
LUMAWISE MOTION Sensor,
Program, Circ.



TE Part #ANT-LTE-WS-SMA
Antenna Blade NBIOT LTE-M Swivel
SMA

Documents

Product Drawings

MASK, STREET LIGHTING MOTION SENSOR

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2396399-1_1.2d_dxf.zip



English

Customer View Model

[ENG_CVM_CVM_2396399-1_1.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2396399-1_1.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

Datasheet - LUMAWISE Motion

English

[Datasheet - LUMAWISE Motion](#)

[Datasheet - LUMAWISE Motion](#)

[Datasheet - LUMAWISE Motion](#)

German

[Datasheet - LUMAWISE Motion](#)

Product Specifications

Application Specification

English