




Connectors > Connector Accessories > Connector Caps & Covers

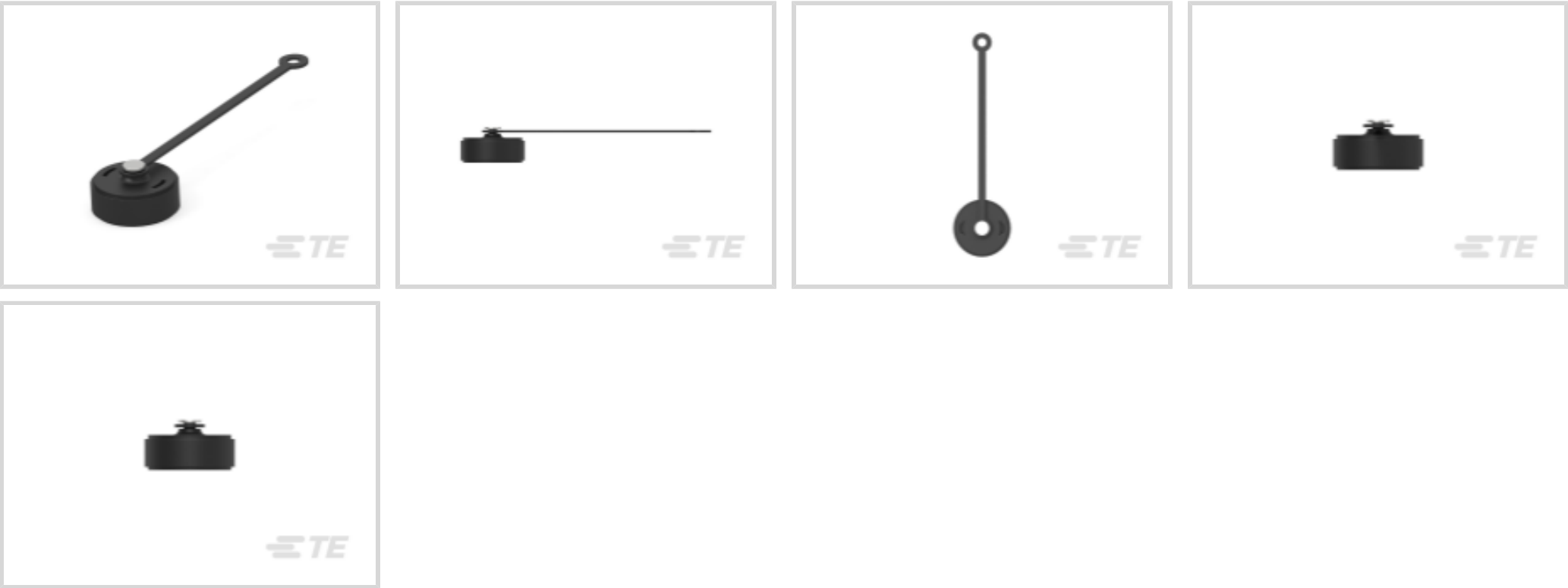

Connector Cover Type: **Sealing Cap**
Primary Product Color: **Black**
Primary Product Material: **Thermoplastic**
Operating Temperature (Max): **105 °C [221 °F]**
Operating Temperature Range: **-55 – 105 °C [-67 – 221 °F]**

Features

Housing Features

Compatible With Connector Shape	Circular
---------------------------------	----------

Mechanical Attachment

Component Retention Feature	Plastic Strap
-----------------------------	---------------

Operation/Application

Compatible With Connector Shell Size	11
--------------------------------------	----

Packaging Features

Packaging Method	Bag
Packaging Quantity	100

Body Features

Primary Product Plating Material	Zinc Plate With Non-Hexavalent Chromate
Seal Material	Polychloroprene
Primary Product Color	Black
Primary Product Material	Thermoplastic

Product Type Features

--	--



Sealable	Yes
Connector Cover Type	Sealing Cap

Usage Conditions

Operating Temperature (Max)	105 °C[221 °F]
Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]

Other

EU RoHS Compliance	Compliant
EU ELV Compliance	Compliant

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 788155-2
SLD CPC RCPT ASSY, 11-4, REV SEX

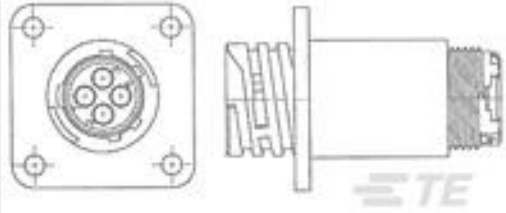

TE Part # 788154-2
SLD CPC RCPT ASSY, 11-4, REV SEX



TE Part # 206434-1
CPC PLUG ASSEMBLY SIZE 11-8



TE Part # 206061-2
CPC RECPT ASSEMBLY SIZE 11-4




TE Part # 206060-1
CPC PLUG ASSEMBLY SIZE 11-4



TE Part # 788153-2
SLD CPC PLUG ASSY, 11-4, REV SEX



TE Part # 1977880-1
SLD CPC RCPT ASSY, 11-4, REV SEX,
UV RESIS

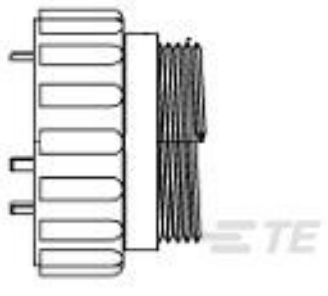

TE Part # 206516-1
CPC PLUG ASSEMBLY SIZE 11-4



TE Part # 205838-1
CPC PLUG ASSEMBLY SIZE 11-8



TE Part # 1977878-1
SLD CPC PLUG ASY, 11-4, STD SEX, UV
RESIST



TE Part # 206430-3
CPC RECPT ASSEMBLY SIZE 11-4



TE Part # 796095-2
SLD CPC RCPT ASY, 11-4, STD SEX



TE Part # 796096-2
SLD CPC RCPT ASY, 11-4, STD SEX



TE Part # 796094-2
SLD CPC PLUG ASY, 11-4, STD SEX



TE Part # 1977876-1
SLD CPC RCPT ASY, 11-4, STD SEX, UV
RESIST



TE Part # 206153-2
CPC RECPT ASSEMBLY SIZE 11-4



TE Part # 206485-1
CPC PLUG ASSEMBLY SIZE 11-9



TE Part # 206429-1
CPC PLUG ASSY, 11-4, REV SEX

Also in the Series | [AMP CPC](#)




Circular Connector Backshells & Clamps(1)



Circular Power Connectors(423)




Connector Contacts(6)

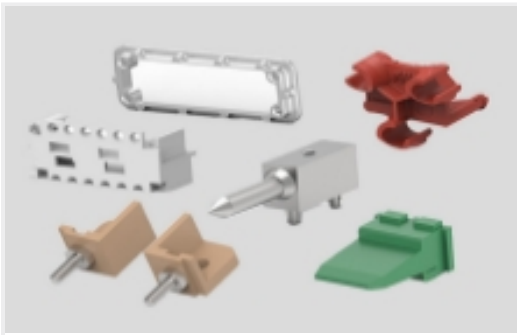

Connector Hardware(12)



Power Contacts(6)

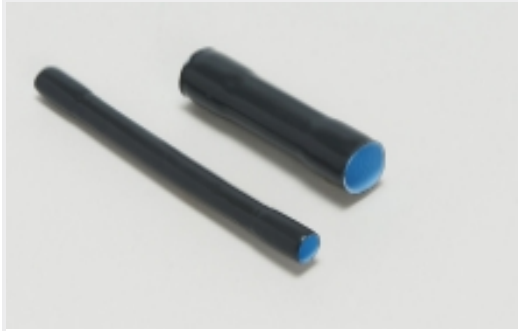

Sealing Sleeves(2)


Customers Also Bought



TE Part #206150-1
CPC PLUG ASSEMBLY SIZE 23-37



TE Part #206306-5
CPC RECEPT ASSEMBLY SIZE 23-37

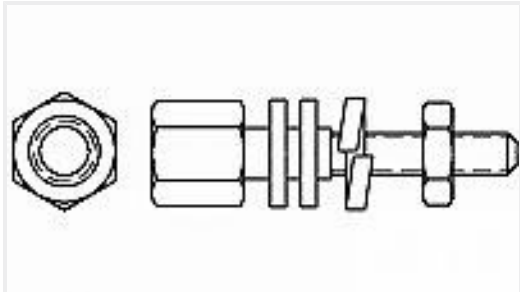

TE Part #5747223-3
AMPLI FEM S'LOCK KIT



TE Part #207360-1
PLUG HSG,3 POSN,METRIC



TE Part #66105-1
III+ SKT,24-20,30AU>10,LP




TE Part #5747100-1
CABLE CLAMP KIT,SZ 4



TE Part #5645945-2
SKT,MIN-SPR B-N SN-AU SER-1.5



TE Part #201328-1
CONTACT SOCKET ASSY.

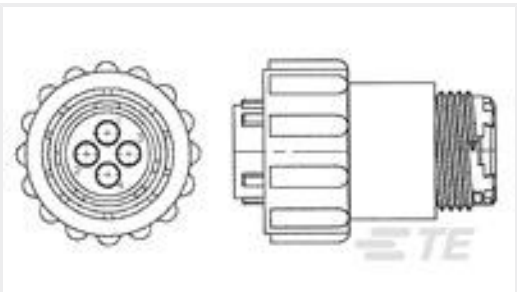

TE Part #1977881-1
SLD CPC PLUG ASSY,11-4,REV SEX, UV RESIS



TE Part #211686-2
CR 120 POS RECPT KIT

Documents



Product Drawings

SEALING CAP ASSY,SZ 11,CPC

English

CAD Files

Customer View Model

ENG_CVM_CVM_206903-2_L.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_206903-2_L.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_206903-2_L.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

1-1773902-9_CPC_Catalog

English

1-1773902-9_CPC_Catalog

1-1773902-9_CPC_Catalog

German

1-1773902-9_CPC_Catalog

Japanese