


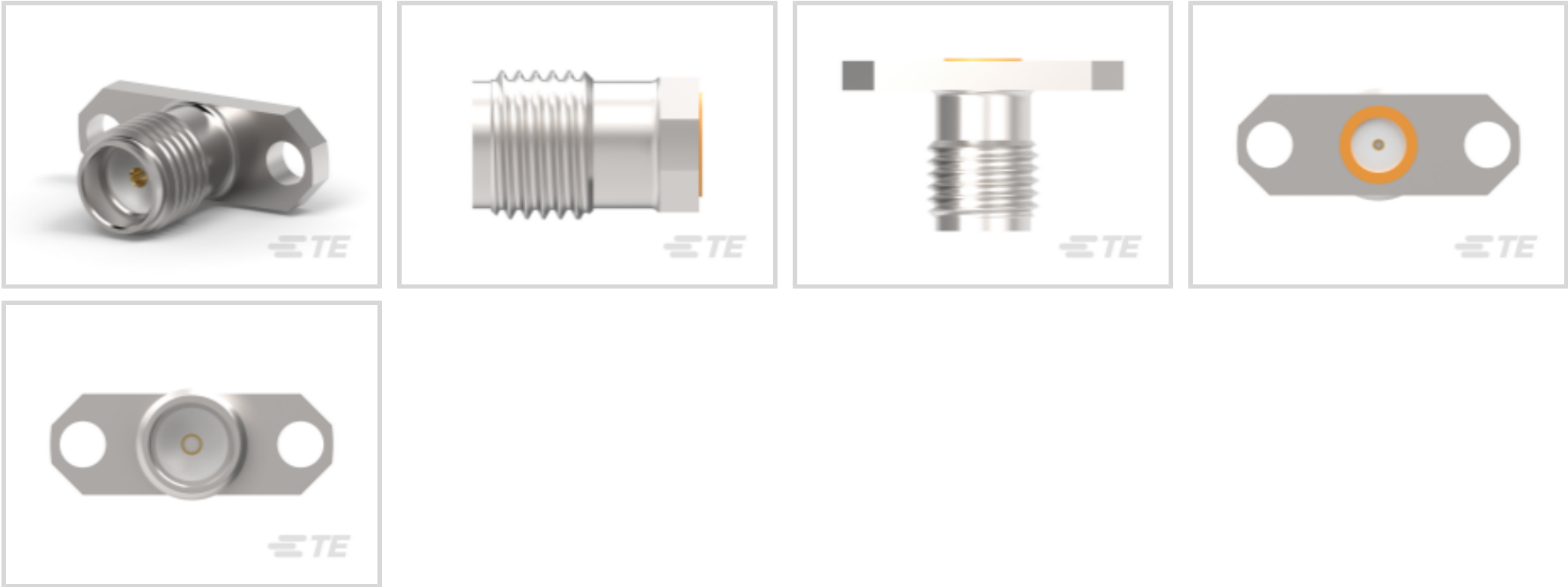

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)



EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUL 2021 (219) SVHC > Threshold: Pb (.6% in Component Part) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Low Bromine/Chlorine - Br and Cl < 900 ppm per homogenous material. Also BFR /CFR/PVC Free
Solder Process Capability	Pin-in-Paste capable to 260°C

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>




Compatible Parts

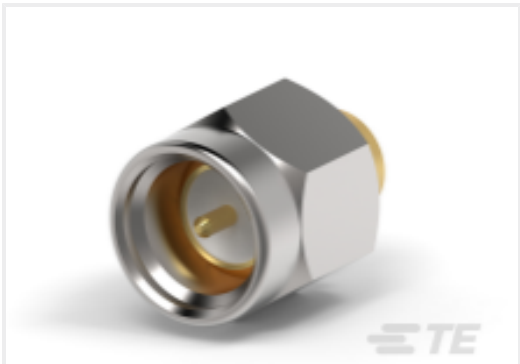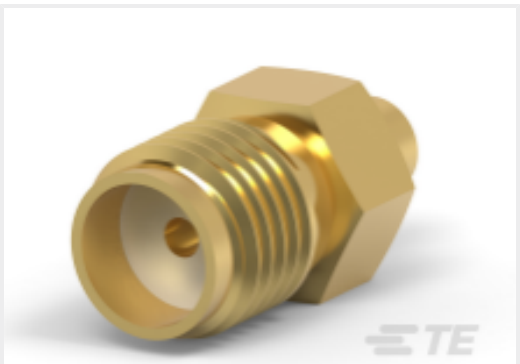 TE Part # 1051664-1 2031 5012 00	 TE Part # 1052075-1 2037 5008 00,SMA RA CABLE PLUG	 TE Part # 1050548-1 2001 5032 02	 TE Part # 1050598-1 SMA Cable Plug 2001 5385 02
 TE Part # 1050720-1 2001 7188 00	 TE Part # 1050524-1 2001 5003 00,SMA CABLE PLUG	 TE Part # 1051110-1 2007 5054 02	 TE Part # 1052098-1 2037 5100 02
 TE Part # 1050525-1 2001 5003 02,SMA CABLE PLUG	 TE Part # 1050602-1 2001 5395 02	 TE Part # 1052066-1 2037 5006 00,SMA RA CABLE PLUG	 TE Part # 1050547-1 2001 5032 00
 TE Part # 1056456-1 2837 7316 02	 TE Part # 1056462-1 2837 7388 02	 TE Part # 1050859-1 2002 5016 00	

Also in the Series | SMA

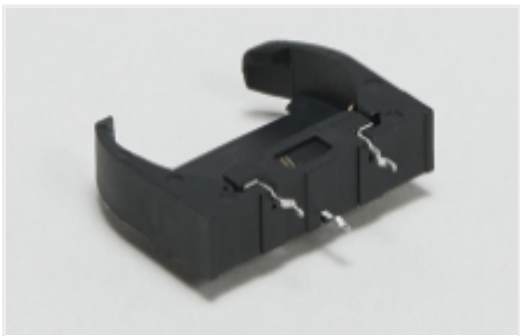 Battery Holders(1)	 Connector Adapters & Connector Savers(8)	 Connector Caps & Covers(3)	 Connector Strain Relief(1)
---	--	---	---

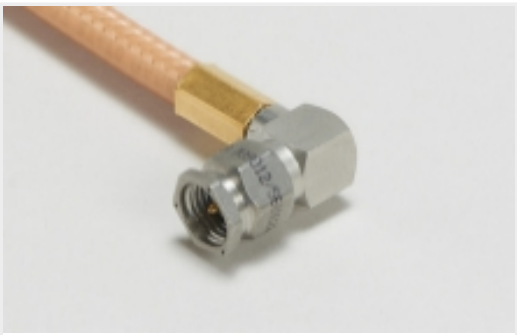

RF Cable Assemblies(2)


Customers Also Bought



TE Part #5-146281-2
02 MODII HDR SRST B/A LF



TE Part #CONBNC004
BNC Jack 50 Ohm Panel Mount

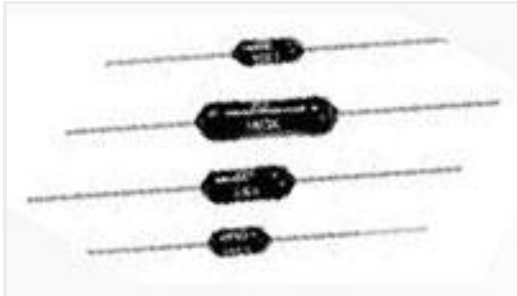


TE Part #1-1879643-8
H8 3M3 0.5% 50PPM




TE Part #YDTS26F19-11PNV001
PLUG ASSY




TE Part #207378-7
METRIMATE PIN HEADER ASSY,6P

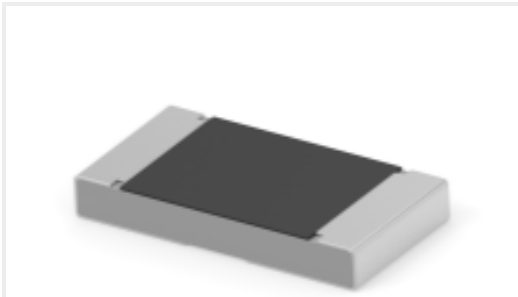


TE Part #3-2176526-8
3503G 2B 124R 1% 5K RL

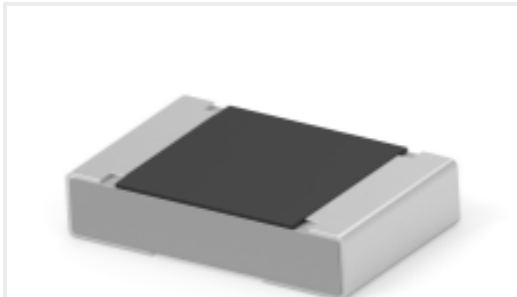


TE Part #3-2176523-8
3503G 2B 124R 1% 1K RL

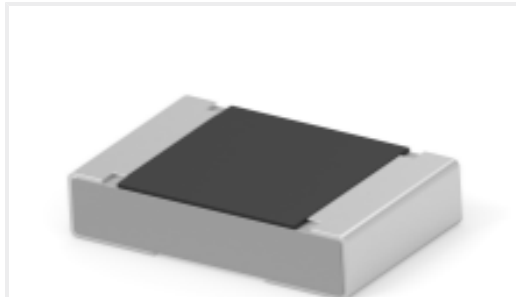

TE Part #4-2176523-6
3503G 2B 150R 1% 1K RL

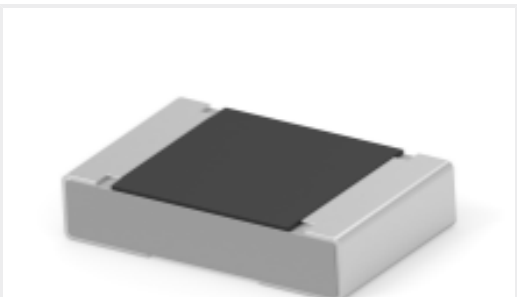

TE Part #4-2176523-7
3503G 2B 154R 1% 1K RL

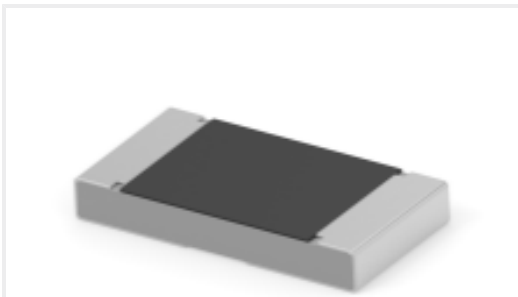

TE Part #6-2176526-7
3503G 2B 249R 1% 5K RL

Documents

Product Drawings

2052 3502 02,SMA JACK RECPT

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1052689-1_A.2d_dxf.zip



English

Customer View Model

[ENG_CVM_CVM_1052689-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1052689-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[SMA Connectors](#)

English